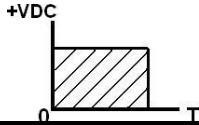
 


# 1. SPECIFICATION

AX-1005-1C




ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5.0	
02	Operating Voltage	V	3.0 ~ 6.0	
03	Consumption Current	mA (Max)	35	Rated Voltage
04	Resonant Frequency	Hz	2700± 300	Rated Voltage
05	Response times	ms	≥ 100	
06	Sound pressure level	dB(A) Min.	80	Distance at 10cm Rated Voltage / Resonant Frequency
07	Operating Temp.	℃	-30 ~ +70	
08	Storage Temp.	℃	-40 ~ +85	
09	Weight	g	1.1±0.3	

REV NO.

REVISION NOTE

APPROVAL

DATE

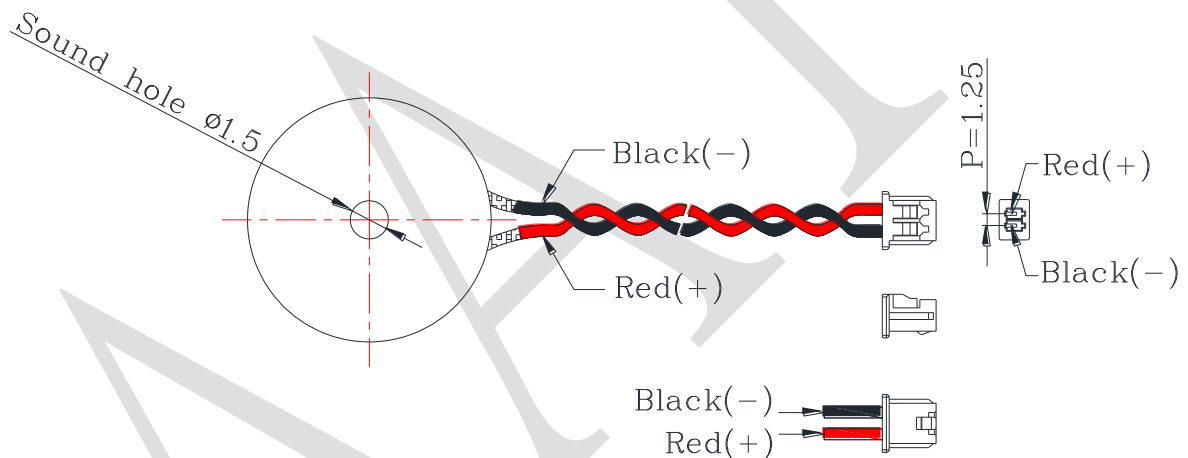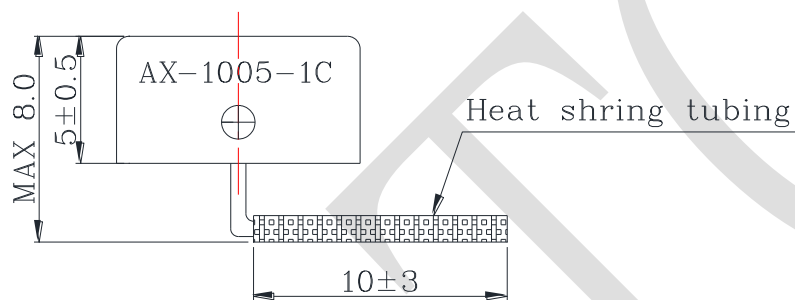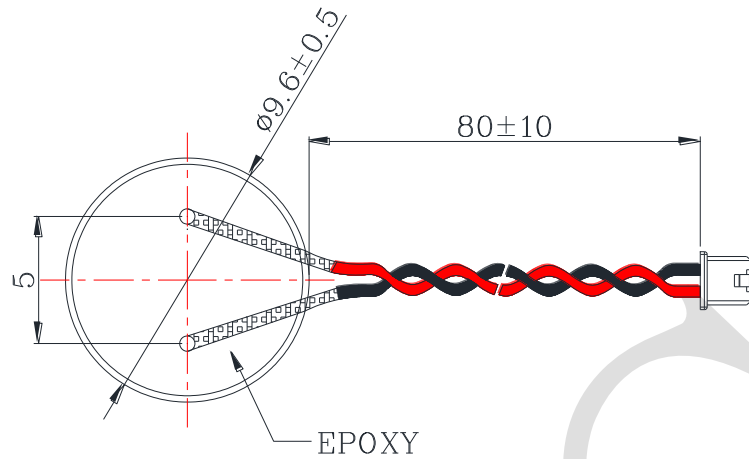

Wire: UL 1571.AWG30#

Connector: Equivalent to Molex 51021-0200

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Moose

2018-06-13

SCALE: 4:1 SHEET: 1 of 1

PART NO. AX-1005-1C

DESIGNED: R&amp;D OF AAT

UNITS: mm

DWG NO. UGCM0905XPWC80-Z

CHECKED:

TOLERANCE  $\pm 0.5$ 

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

REV

MATERIAL: PBT

ONE PLACE DECIMAL  $\pm$  \*\*\*TWO PLACE DECIMAL  $\pm$  \*\*\*THREE PLACE DECIMAL  $\pm$  \*\*\*

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AX-1005-1C](#)