


Single-Pole BMC 075 (Medium)

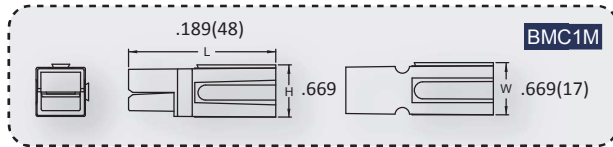



Single-Pole BMC 075 (Medium) Housing & Accessories

Item No.	Description	Housing Colors	Quantity
BMC1M	1-Pole 075 (Medium) Housing	BK BL GR RD WH YW	50 Box
BMC1M-LK	1-Pole 075 (Medium) Housing (Locking Slot)	BK BL GR RD WH YW	50 Box
BMC1MRC-BK	1-Pole 075 (Medium) Housing (Chemical Resistant)	BK BL GR RD WH	50 Box
K7-4.97*15.5	1-Pole 075 (Medium) Housing Pin-lock	NA	1000 Box
BMC1M-SMTL	1-Pole 075 (Medium) Housing SMT Seat	NA	100 Box

Single-Pole BMC 075 (Medium) Contacts

Item No.	Description	Contact Barrel Size AWG (mm ²)	Current Rating (Amps)	Max. Wire Insulation Dia. (mm)	Quantity
BMC5AG	1-Pole 075 Contact 050A	12-10 (3.0-6.0)	50	11	500 Box
BMC8AG	1-Pole 075 Contact 060A	8 (8)	60	11	500 Box
BMC14AG	1-Pole 075 Contact 075A	6 (13)	75	11	500 Box

Single-Pole BMC 120 (Medium-Large) & 180 (Large)

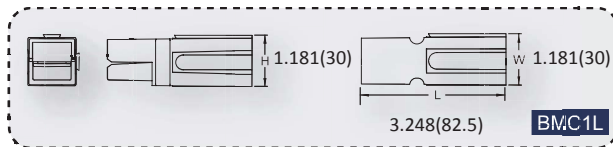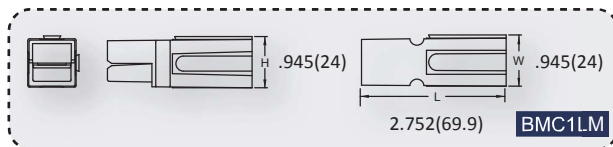

Single-Pole BMC 120 (Medium-Large) & 180 (Large) Housing & Accessories

Item No.	Description	Housing Colors	Quantity
BMC1LM	1-Pole 120 (Medium-Large) Housing	BK BL GR RD WH YW	25 Box
K7-4.97*25.4	1-Pole 120 (Medium-Large) Housing Pin-lock	NA	1000 Box
BMC1L	1-Pole 180 (Large) Housing	BK BL GR RD WH	25 Box
K7-4.97*31.5	1-Pole 180 (Large) Housing Pin-lock	NA	1000 Box

Single-Pole BMC 120 (Medium-Large) & 180 (Large) Contacts

Item No.	Description	Contact Barrel Size AWG (mm ²)	Current Rating (Amps)	Max. Wire Insulation Dia. (mm)	Quantity
BMCMS14AG	1-Pole 120 Contact 080A	6 (13)	80	14.6	100 Box
BMCMS22AG	1-Pole 120 Contact 100A	4 (21)	100	14.6	100 Box
BMCMS38AG	1-Pole 120 Contact 120A	2 (34)	120	14.6	100 Box
BMCM14AG	1-Pole 180 Contact 080A	6 (13)	80	14.6	100 Box
BMC22AG	1-Pole 180 Contact 125A	4 (21)	125	19.05	100 Box
BMC38AG	1-Pole 180 Contact 150A	2 (34)	150	19.05	100 Box
BMC60AG	1-Pole 180 Contact 175A	1/0 (60)	175	19.05	50 Box

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[KS Terminals:](#)

[BMCMS14AG](#) [BMCMS22AG](#)