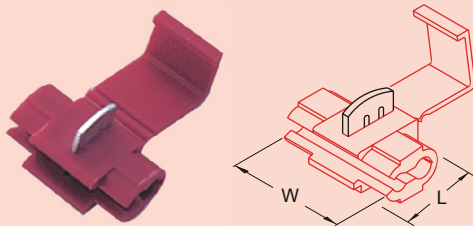
 
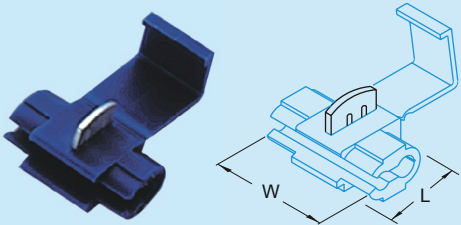
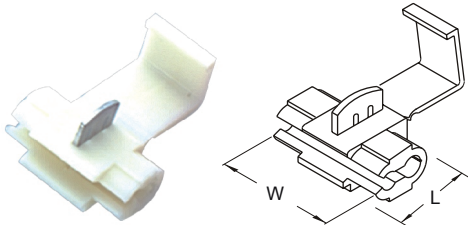
 
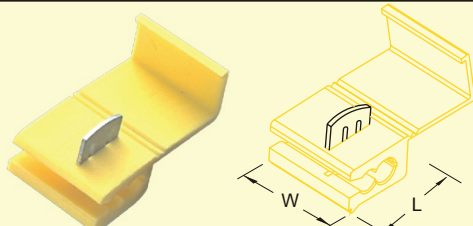
 


QUICK SPLICE CONNECTORS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	9	12	17	18	30	35	50

MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.
INSULATION MATERIAL: P.P.
TERMINAL MATERIAL: BRASS

ITEM NO.	WIRE RANGE A.W.G. mm ²	W inch mm	L inch mm	COLOR	FIGURE	TYPE CONNECTOR	Q'TY BOX
878100	22-18 A.W.G. 0.5-0.75 mm ²	.787 20.0	.465 11.8	RED			500
878100-V0							
878100-V2							
878100N							
878101	18-14 A.W.G. 0.75-2.5 mm ²	.772 19.6	.472 12.0	BLUE			500
878101 -WHITE	18-14 A.W.G. 0.75-2.5 mm ²	.772 19.6	.472 12.0	WHITE			500
878201	12-10 A.W.G. 4-6 mm ²	.807 20.5	.598 15.2	YELLOW			200

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[KS Terminals:](#)

[878100](#) [878100N](#) [878101](#) [878101-WHITE](#) [878201](#)