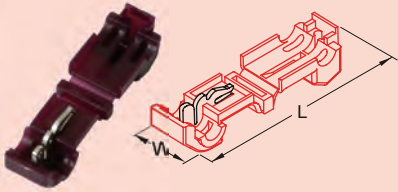
 
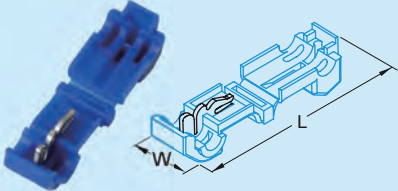
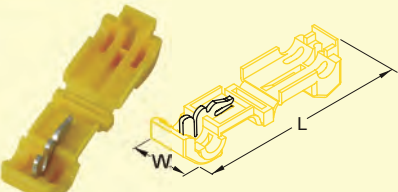
 


QUICK SPLICE CONNECTORS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12
AMP.	9	12	17	18	30	35

MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.
INSULATION MATERIAL: NYLON
TERMINAL MATERIAL: BRASS

ITEM NO.	WIRE RANGE A.W.G. mm ²	Suggested Mate With Male Tab (ThicknessXWidth)	W inch mm	L inch mm	COLOR	FIGURE	TYPE CONNECTOR	Q'TY BOX
878006	22-18 A.W.G. 0.5-0.75 mm ²	MDFNY1-250 (.032X.250)	.386 9.8	1.457 37.0	RED			500
878106	18-14 A.W.G. 0.75-2.5 mm ²	MDFNY2-250 (.032X.250)	.386 9.8	1.457 37.0	BLUE			500
878206	12 A.W.G. 4 mm ²	MDFNY5-250 (.032X.250)	.386 9.8	1.457 37.0	YELLOW			500

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[KS Terminals:](#)

[878006](#) [878106](#) [878206](#)