

DIN 46237

VINYL-INSULATED SPADE TERMINALS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	9	12	17	18	30	35	50


MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.

INSULATION MATERIAL: VINYL

INSULATION COLOR:

22-16 A.W.G.: RED 16-14 A.W.G.: BLUE 12-10 A.W.G.: YELLOW

TERMINAL MATERIAL: COPPER

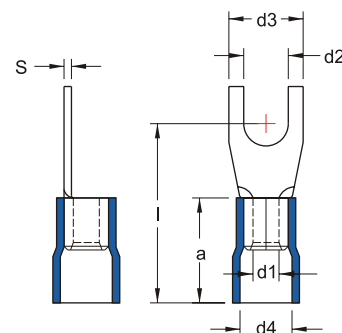

WIRE RANGE A.W.G. mm ²	ITEM NO.		STUD SIZE		DIMENSION mm						CRIMPING TOOL	Q'TY BOX
	BRAZED SEAM	BUTTED SEAM	d2		d3	I	d1	d4	a	S		
22-16 A.W.G. 0.5-1.5 mm ²	DSVB3-1	DSV3-1	#4	3.2	6.0	16.0	1.6	4.0	10.0	0.8	IZUMI MODEL 34 WITH DIE INDEX COLOR:RED OR K.S. MODEL KST2000A HRI-126J KSTLY-2004 KSTLY-2005 WITH DIE INDEX COLOR:RED	1000
	DSVB3.5-1	DSV3.5-1	#6	3.7								1000
	DSVB4-1	DSV4-1	#8	4.3	6.8	17.0						1000
	DSVBL4-1	DSVL4-1	#8	4.3	8.0							1000
	DSVB5-1	DSV5-1	#10	5.3	10.0	18.0						1000
	DSVB6-1	DSV6-1	1/4	6.5	11.0	20.0						1000
16-14 A.W.G. 1.5-2.5 mm ²	DSVB3-2.5	DSV3-2.5	#4	3.2	5.5	18.0	2.3	4.5	10.0	0.8	IZUMI MODEL 34 WITH DIE INDEX COLOR:BLUE OR K.S. MODEL KST2000A HRI-126J KSTLY-2004 KSTLY-2005 WITH DIE INDEX COLOR:BLUE	1000
	DSVB3.5-2.5	DSV3.5-2.5	#6	3.7	6.0	16.0						1000
	DSVB4-2.5	DSV4-2.5	#8	4.3	6.8	17.0						1000
	DSVBL4-2.5	DSVL4-2.5	#8	4.3	8.0							1000
	DSVB5-2.5	DSV5-2.5	#10	5.3	10.0	19.0						1000
	DSVB6-2.5	DSV6-2.5	1/4	6.5	11.0	21.0						1000
12-10 A.W.G. 2.5-6 mm ²	DSVB4-6	DSV4-6	#8	4.3	8.0	21.0	3.6	6.3	13.0	1.0	IZUMI MODEL 5 WITH DIE INDEX COLOR:YELLOW OR K.S. MODEL KST2000A HRI-126J KSTLY-2004 KSTLY-2005 WITH DIE INDEX COLOR:YELLOW	500
	DSVB5-6	DSV5-6	#10	5.3	10.0	22.0						500
	DSVB6-6	DSV6-6	1/4	6.5	11.0	23.0						500
	DSVB8-6	DSV8-6	5/16	8.4	14.0	26.0						500
	DSVB10-6	DSV10-6	3/8	10.5	18.0	28.0						500

UL cUL ALL LISTED

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

KS Terminals:

[DSV4-2.5](#) [DSV4-6](#) [DSV5-1](#) [DSV5-2.5](#) [DSV6-1](#) [DSV6-2.5](#) [DSV6-6](#) [DSV8-6](#)