

VINYL-FULLY INSULATED DOUBLE CRIMP FEMALE DISCONNECTORS


MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	3	4	7	10	15	20	24

MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.
INSULATION MATERIAL: VINYL TERMINAL MATERIAL: BRASS
INSULATION COLOR:

 22-16 A.W.G.: RED ■ 16-14 A.W.G.: BLUE ■ 12-10 A.W.G.: YELLOW ■
DOUBLE CRIMP: WITH COPPER SLEEVE ON BARREL
TERMINAL BARREL I.D.:

22-16 A.W.G.: C=1.7mm 16-14 A.W.G.: C=2.3mm 12-10 A.W.G.: C=3.4mm

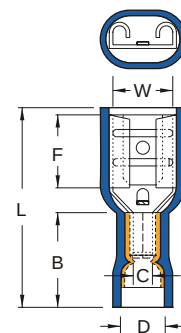

WIRE RANGE A.W.G. mm ²	ITEM NO.	NEMA TAB	DIMENSION ^{inch} mm						CRIMPING TOOL	Q'TY BOX
			W	F	L	B	D	T		
22-16 A.W.G. 0.5-1.5 mm ²	FDFD1-110(5)	.020×.110 (0.5×2.8)	.126 3.2	.256 6.5	.748 19.0	.413 10.5	.157 4.0	.012 0.3	IZUMI MODEL 34 WITH DIE INDEX COLOR:RED OR K.S. MODEL KST2000A WITH DIE INDEX COLOR:RED	1000
	FDFD1-110(8)	.032×.110 (0.8×2.8)								1000
	FDFD1-187(5)	.020×.187 (0.5×4.75)	.197 5.0	.252 6.4	.807 20.5			.014 0.35		1000
	FDFD1-187(8)	.032×.187 (0.8×4.75)								1000
	FDFD1-205(5)	.020×.205 (0.5×5.2)	.224 5.7	.228 5.8	.795 20.2			.016 0.4		1000
	FDFD1-205(8)	.032×.205 (0.8×5.2)								1000
	FDFD1-250	.032×.250 (0.8×6.35)	.260 6.6	.295 7.5	.858 21.8			1000		
16-14 A.W.G. 1.5-2.5 mm ²	FDFD2-110(5)	.020×.110 (0.5×2.8)	.126 3.2	.256 6.5	.748 19.0	.413 10.5	.185 4.7	.012 0.3	IZUMI MODEL 34 WITH DIE INDEX COLOR:BLUE OR K.S. MODEL KST2000A WITH DIE INDEX COLOR:BLUE	1000
	FDFD2-110(8)	.032×.110 (0.8×2.8)								1000
	FDFD2-187(5)	.020×.187 (0.5×4.75)	.197 5.0	.252 6.4	.795 20.2			.014 0.35		1000
	FDFD2-187(8)	.032×.187 (0.8×4.75)								1000
	FDFD2-205(5)	.020×.205 (0.5×5.2)	.224 5.7	.228 5.8	.795 20.2			.016 0.4		1000
	FDFD2-205(8)	.032×.205 (0.8×5.2)								1000
	FDFD2-250	.032×.250 (0.8×6.35)	.260 6.6	.295 7.5	.874 22.2			1000		
12-10 A.W.G. 4-6 mm ²	FDFD5-250	.032×.250 (0.8×6.35)	.260 6.6	.295 7.5	.953 24.2	.492 12.5	.244 6.2	.016 0.4	IZUMI MODEL 5 WITH DIE INDEX COLOR:YELLOW OR	500
FDFD5-375	.047×.370 (1.2×9.4)	.394 10.0						.472 12.0	1.201 30.5	.020 0.5



ALL LISTED

©: NOT UL AND C-UL LISTED

*: ADDITIONAL CERTIFIED

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

KS Terminals:

[FDFD1-110\(5\)](#) [FDFD1-110\(8\)](#) [FDFD1-187\(5\)](#) [FDFD1-187\(8\)](#) [FDFD1-205\(5\)](#) [FDFD1-205\(8\)](#) [FDFD1-250](#) [FDFD2-110\(5\)](#) [FDFD2-110\(8\)](#) [FDFD2-187\(5\)](#) [FDFD2-187\(8\)](#) [FDFD2-205\(5\)](#) [FDFD2-250](#) [FDFD5-250](#)