



PE-HEAT SHRINKABLE-SPADE TERMINALS “HB” (BRAZED TYPE)

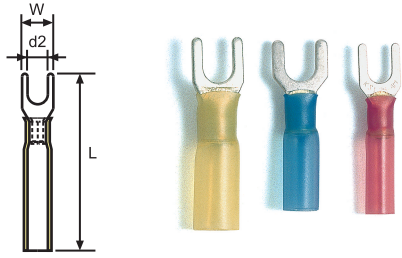

WIRE RANGE A.W.G. / MM ²	ITEM NO.	DIMENSION (mm)			INSULATED COLOR
		d2	W	L	
22-16 / 0.5-1.5	SHBL1-3.7	3.7	6.4	29.3	RED
	SHBM1-4	4.3	7.2	29.6	
	SHBL1-5	5.3	9.5	30.0	
16-14 / 1.5-2.5	SHBL2-3.7	3.7	6.0	28.5	BLUE
	SHBM2-4	4.3	7.2	29.5	
	SHBL2-5	5.3	9.3	30.5	
12-10 / 4-6	SHBL5-4	4.3	9.0	33.5	YELLOW
	SHB5-5	5.3			
	SHBL5-6	6.4			


PE-HEAT SHRINKABLE-SPADE TERMINALS “HD” (DOUBLE CRIMP TYPE)

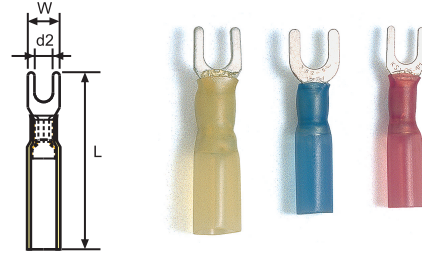

WIRE RANGE A.W.G. / MM ²	ITEM NO.	DIMENSION (mm)			INSULATED COLOR
		d2	W	L	
22-16 / 0.5-1.5	SHDL1-3.7	3.7	6.4	33.0	RED
	SHDM1-4	4.3	7.2		
	SHDL1-5	5.3	9.5		
16-14 / 1.5-2.5	SHDL2-3.7	3.7	6.0	33.5	BLUE
	SHDM2-4	4.3	7.2		
	SHDL2-5	5.3	9.3		
12-10 / 4-6	SHDL5-4	4.3	9.0	38.0	YELLOW
	SHD5-5	5.3			
	SHDL5-6	6.4			


⬆ Above terminals also available in NYLON material , item numbers please add suffix “-NY”. ⬆

PE-HEAT SHRINKABLE-FEMALE DISCONNECTS “HD” (DOUBLE CRIMP TYPE)

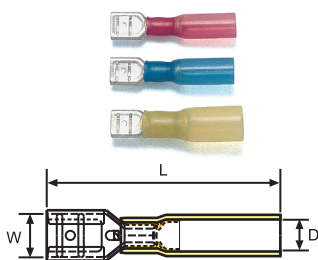


WIRE RANGE A.W.G. / MM ²	ITEM NO.	NEMA TAB IN mm	W	D	L	INSULATED COLOR
22-16 / 0.5-1.5	FDHD 1-250	.032 x .250 0.8 x 6.35	6.6	5.5	34.0	RED
16-14 / 1.5-2.5	FDHD 2-250			6.0		BLUE
12-10 / 4-6	FDHD 5-250			8.1	35.0	YELLOW

PE-HEAT SHRINKABLE-MALE DISCONNECTS “HD” (DOUBLE CRIMP TYPE)

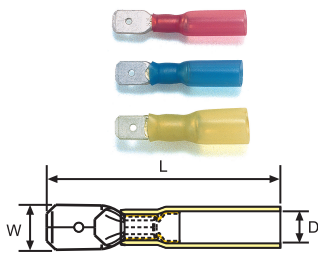

WIRE RANGE A.W.G. / MM ²	ITEM NO.	NEMA TAB IN mm	W	D	L	INSULATED COLOR
22-16 / 0.5-1.5	MDHD 1-250	.032 x .250 0.8 x 6.35	6.35	5.5	34.0	RED
16-14 / 1.5-2.5	MDHD 2-250			6.0		BLUE
12-10 / 4-6	MDHD 5-250			8.1	35.0	YELLOW

PE-HEAT SHRINKABLE-FULLY INSULATED FEMALE DISCONNECTS “HD” (DOUBLE CRIMP TYPE)

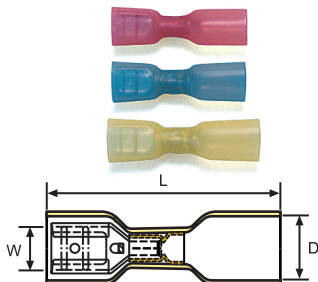

WIRE RANGE A.W.G. / MM ²	ITEM NO.	NEMA TAB IN mm	W	D	L	INSULATED COLOR
22-16 / 0.5-1.5	FDFHD 1-250	.032 x .250 0.8 x 6.35	6.6	6.5	28.0	RED
16-14 / 1.5-2.5	FDFHD 2-250					BLUE
12-10 / 4-6	FDFHD 5-250			7.5		YELLOW

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[KS Terminals:](#)

[FDHD1-250](#) [FDHD2-250](#) [FDHD5-250](#)