

NYLON-INSULATED DOUBLE CRIMP FEMALE DISCONNECTORS


MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	3	4	7	10	15	20	24

MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.
INSULATION MATERIAL: NYLON **TERMINAL MATERIAL: BRASS**
INSULATION COLOR:

 22-16 A.W.G.: RED 16-14 A.W.G.: BLUE 12-10 A.W.G.: YELLOW
DOUBLE CRIMP: WITH COPPER SLEEVE ON BARREL
TERMINAL BARREL I.D.:

22-16 A.W.G.: C=1.7mm 16-14 A.W.G.: C=2.3mm 12-10 A.W.G.: C=3.4mm

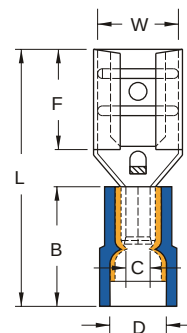

WIRE RANGE A.W.G. mm ²	ITEM NO.	NEMA TAB	DIMENSION ^{inch} mm						CRIMPING TOOL	Q'TY BOX	
			W	F	L	B	D	T			
22-16 A.W.G. 0.5-1.5 mm ²	FDNYD1-110(5)	.020×.110 (0.5×2.8)	.126 3.2	.256 6.5	.772 19.6	.433 11.0	.157 4.0	.012 0.3	IZUMI MODEL 34 WITH DIE INDEX COLOR:RED OR K.S. MODEL KST2000A WITH DIE INDEX COLOR:RED	1000	
	FDNYD1-110(8)	.032×.110 (0.8×2.8)								1000	
	FDNYD1-187(5)	.020×.187 (0.5×4.75)	.197 5.0	.252 6.4	.787 20.0			.014 0.35		1000	
	FDNYD1-187(8)	.032×.187 (0.8×4.75)								1000	
	FDNYD1-205(5)	.020×.205 (0.5×5.2)	.224 5.7	.228 5.8	.768 19.5			.016 0.4		1000	
	FDNYD1-205(8)	.032×.205 (0.8×5.2)								1000	
	FDNYD1-250	.032×.250 (0.8×6.35)	.260 6.6	.295 7.5	.846 21.5			1000			
	FDNYD1-312 [⊙]	.032×.315 (0.8×8.0)	.323 8.2	.394 10.0	.992 25.2			1000			
16-14 A.W.G. 1.5-2.5 mm ²	FDNYD2-110(5)	.020×.110 (0.5×2.8)	.126 3.2	.256 6.5	.772 19.6	.433 11.0	.197 5.0	.012 0.3	IZUMI MODEL 34 WITH DIE INDEX COLOR:BLUE OR K.S. MODEL KST2000A WITH DIE INDEX COLOR:BLUE	1000	
	FDNYD2-110(8)	.032×.110 (0.8×2.8)								1000	
	FDNYD2-187(5)	.020×.187 (0.5×4.75)	.197 5.0	.252 6.4	.787 20.0			.014 0.35		1000	
	FDNYD2-187(8)	.032×.187 (0.8×4.75)								1000	
	FDNYD2-205(5)	.020×.205 (0.5×5.2)	.224 5.7	.228 5.8	.768 19.5			.016 0.4		1000	
	FDNYD2-205(8)	.032×.205 (0.8×5.2)								1000	
	FDNYD2-250	.032×.250 (0.8×6.35)	.260 6.6	.295 7.5	.846 21.5			1000			
	FDNYD2-312 [⊙]	.032×.315 (0.8×8.0)	.323 8.2	.394 10.0	.992 25.2			1000			
	FDNYD2-375 [⊙]	.047×.370 (1.2×9.4)	.394 10.0	.472 12.0	1.043 26.5			.020 0.5		1000	
12-10 A.W.G. 4-6 mm ²	FDNYD5-110(5) [⊙]	.020×.110 (0.5×2.8)	.126 3.2	.256 6.5	.866 22.0	.512 13.0	.256 6.5	.014 0.35	IZUMI MODEL 5 WITH DIE INDEX COLOR:YELLOW OR K.S. MODEL KST2000A WITH DIE INDEX COLOR:YELLOW	500	
	FDNYD5-110(8) [⊙]	.032×.110 (0.8×2.8)								500	
	FDNYD5-187(5)	.020×.187 (0.5×4.75)	.197 5.0					.925 23.5		.016 0.4	500
	FDNYD5-187(8)	.032×.187 (0.8×4.75)									500
	FDNYD5-250	.032×.250 (0.8×6.35)	.260 6.6	.295 7.5	500						
	FDNYD5-375 [⊙]	.047×.370 (1.2×9.4)	.394 10.0	.472 12.0	1.122 28.5			.020 0.5		500	


 ALL LISTED
 © : NOT UL AND C-UL LISTED

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

KS Terminals:

[FDNYD1-110\(5\)](#) [FDNYD1-110\(8\)](#) [FDNYD1-187\(5\)](#) [FDNYD1-187\(8\)](#) [FDNYD1-205\(5\)](#) [FDNYD1-205\(8\)](#) [FDNYD1-250](#) [FDNYD2-110\(5\)](#) [FDNYD2-110\(8\)](#) [FDNYD2-187\(5\)](#) [FDNYD2-187\(8\)](#) [FDNYD2-205\(8\)](#) [FDNYD2-250](#) [FDNYD5-187\(5\)](#) [FDNYD5-187\(8\)](#) [FDNYD5-250](#)