

VINYL-INSULATED FLANGE SPADE TERMINALS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	9	12	17	18	30	35	50


MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.

INSULATION MATERIAL: VINYL

INSULATION COLOR:

22-16 A.W.G.: RED 16-14 A.W.G.: BLUE 12-10 A.W.G.: YELLOW

TERMINAL MATERIAL: COPPER

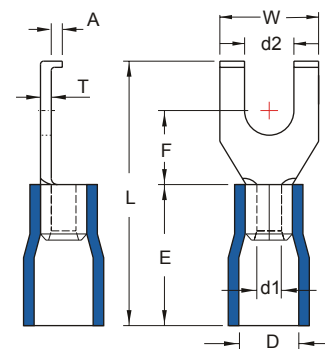

WIRE RANGE A.W.G. mm ²	ITEM NO.		STUD SIZE		DIMENSION inch mm								CRIMPING TOOL	Q'TY BOX
	BRAZED SEAM	BUTTED SEAM	d2		W	F	L	E	D	d1	A	T		
22-16 A.W.G. 0.5-1.5 mm ²	FSVBS1-2	FSVS1-2	#2	.087 2.2	.252 6.4	.205 5.2							IZUMI MODEL 34 WITH DIE INDEX COLOR:RED OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:RED	1000
	FSVB1-3.2	FSV1-3.2	#4	.126 3.2	.295 7.5									1000
	FSVBS1-3.2	FSVS1-3.2	#4	.126 3.2	.252 6.4									1000
	FSVB1-3.7	FSV1-3.7	#6	.146 3.7	.295 7.5									1000
	FSVBS1-3.7	FSVS1-3.7	#6	.146 3.7	.252 6.4									1000
	FSVBL1-3.7	FSVL1-3.7	#6	.146 3.7	.335 8.5	.283 7.2	.965 24.5							1000
	FSVB1-4	FSV1-4	#8	.169 4.3	.295 7.5	.201 5.1	.748 19.0							1000
	FSVBL1-4	FSVL1-4	#8	.169 4.3	.335 8.5	.283 7.2	.965 24.5							1000
	FSVB1-5	FSV1-5	#10	.209 5.3	.295 7.5	.201 5.1	.748 19.0							1000
	FSVBL1-5	FSVL1-5	#10	.209 5.3	.335 8.5	.283 7.2	.965 24.5							1000
16-14 A.W.G. 1.5-2.5 mm ²	FSVB2-3.7	FSV2-3.7	#6	.146 3.7	.295 7.5	.205 5.2	.748 19.5						IZUMI MODEL 34 WITH DIE INDEX COLOR:BLUE OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:BLUE	1000
	FSVBL2-3.7	FSVL2-3.7	#6	.146 3.7	.335 8.5	.283 7.2	.906 23.0							1000
	FSVB2-4	FSV2-4	#8	.169 4.3	.295 7.5	.205 5.2	.768 19.5							1000
	FSVBM2-4	FSVM2-4	#8	.169 4.3	.315 8.0	.268 6.8	.925 23.5	.394 10.0	.177 4.5	.091 2.3	.059 1.5	.031 0.8		1000
	FSVBL2-4	FSVL2-4	#8	.169 4.3	.335 8.5	.283 7.2	.906 23.0							1000
	FSVB2-5	FSV2-5	#10	.209 5.3	.295 7.5	.205 5.2	.768 19.5							1000
	FSVBL2-5	FSVL2-5	#10	.209 5.3	.335 8.5	.283 7.2	.906 23.0							1000
12-10 A.W.G. 4-6 mm ²	FSVB5-3.7	FSV5-3.7	#6	.146 3.7	.335 8.5	.295 7.5	1.063 27.0						IZUMI MODEL 5 WITH DIE INDEX COLOR:YELLOW OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:YELLOW	500
	FSVBS5-3.7	FSVS5-3.7	#6	.146 3.7	.299 7.6	.244 6.2	1.004 25.5							500
	FSVB5-4	FSV5-4	#8	.169 4.3	.335 8.5	.295 7.5	1.063 27.0							500
	FSVBS5-4	FSVS5-4	#8	.169 4.3	.299 7.6	.244 6.2	1.004 25.5							500
	FSVB5-5	FSV5-5	#10	.209 5.3	.335 8.5	.295 7.5	1.063 27.0							500
	FSVBS5-5	FSVS5-5	#10	.209 5.3	.299 7.6	.244 6.2	1.004 25.5							500

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

KS Terminals:

[FSV5-3.7](#) [FSV5-4](#) [FSV5-5](#) [FSVL1-3.7](#) [FSVL2-4](#) [FSVL2-5](#) [FSVS1-3.7](#) [FSVS5-3.7](#) [FSV1-3.7](#) [FSV1-4](#) [FSV1-5](#)
[FSV2-3.7](#) [FSV2-4](#) [FSV2-5](#)