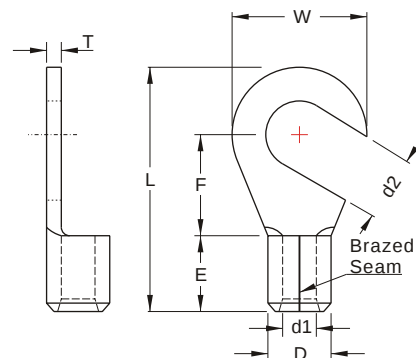


NON-INSULATED HOOK TERMINALS


MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10	8
AMP.	9	12	17	18	30	35	50	70

TERMINAL MATERIAL: COPPER

WIRE RANGE A.W.G. mm ²	ITEM NO.		STUD SIZE		DIMENSION inch mm							CRIMPING TOOL	Q'TY BOX
	BRAZED SEAM	BUTTED SEAM	d2		W	F	L	E	D	d1	T		
22-16 A.W.G. 0.5-1.5 mm ²	HNB1-3.7	HN1-3.7	#6	.146 3.7								IZUMI MODEL 5N18 WITH DIE INDEX NO:1.25 OR K.S. MODEL KST2000D-1322 LY-2045A WITH DIE INDEX NO:1.25	1000
	HNB1-4	HN1-4	#8	.169 4.3	.315 8.0	.276 7.0	.622 15.8	.189 4.8	.134 3.4	.067 1.7	.030 0.75		1000
	HNB1-5	HN1-5	#10	.209 5.3									1000
	HNB1-6	HN1-6	1/4	.252 6.4	.457 11.6	.433 11.0	.858 21.8						1000
16-14 A.W.G. 1.5-2.5 mm ²	HNB2-3.7	HN2-3.7	#6	.146 3.7								IZUMI MODEL 5N18 WITH DIE INDEX NO:2 OR K.S. MODEL KST2000D-1322 LY-2045A WITH DIE INDEX NO:2	1000
	HNB2-4	HN2-4	#8	.169 4.3	.335 8.5	.291 7.4	.661 16.8						1000
	HNB2-5	HN2-5	#10	.209 5.3	.374 9.5	.287 7.3		.189 4.8	.161 4.1	.091 2.3	.031 0.8		1000
	HNB2-6	HN2-6	1/4	.252 6.4	.472 12.0	.433 11.0	.858 21.8						1000
	HNB2-8	HN2-8	5/16	.331 8.4									1000
12-10 A.W.G. 4-6 mm ²	HNB5-3.7	HN5-3.7	#6	.146 3.7	.283 7.2	.240 6.1	.618 15.7					IZUMI MODEL 5N18 WITH DIE INDEX NO:5.5 OR K.S. MODEL KST2000D-1322 LY-2045A WITH DIE INDEX NO:5.5	1000
	HNB5-4	HN5-4	#8	.169 4.3									1000
	HNB5-5	HN5-5	#10	.209 5.3	.374 9.5	.374 9.5	.780 19.8	.236 6.0	.220 5.6	.134 3.4	.039 1.0		1000
	HNB5-6	HN5-6	1/4	.252 6.4	.472 12.0	.406 10.3	.886 22.5						1000
	HNB5-8	HN5-8	5/16	.331 8.4	.591 15.0	.531 13.5	1.063 27.0						1000
8 A.W.G. 8 mm ²	HNB8-8		5/16	.331 8.4	.591 15.0	.543 13.8	1.161 29.5	.335 8.5	.283 7.2	.177 4.5	.047 1.2	IZUMI MODEL 5N18 WITH DIE INDEX NO:8 OR K.S. MODEL KST2000D-1322 LY-2045A WITH DIE INDEX NO:8	500



ALL LISTED

⊙ : NOT UL AND C-UL LISTED

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

KS Terminals:

[HNB1-3.7](#) [HNB1-4](#) [HNB1-5](#) [HNB2-4](#) [HNB2-6](#) [HNB5-3.7](#) [HNB5-5](#) [HNB5-6](#)