

VINYL-INSULATED HOOK TERMINALS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	9	12	17	18	30	35	50


MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.

INSULATION MATERIAL: VINYL

INSULATION COLOR:

22-16 A.W.G.: RED 16-14 A.W.G.: BLUE 12-10 A.W.G.: YELLOW

TERMINAL MATERIAL: COPPER

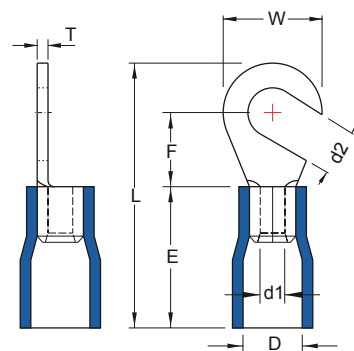

WIRE RANGE A.W.G. mm ²	ITEM NO.		STUD SIZE		DIMENSION inch mm							CRIMPING TOOL	Q'TY BOX
	BRAZED SEAM	BUTTED SEAM	d2		W	F	L	E	D	d1	T		
22-16 A.W.G. 0.5-1.5 mm ²	HVB1-3.7	HV1-3.7	#6	.146 3.7								IZUMI MODEL 34 WITH DIE INDEX COLOR:RED OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:RED	1000
	HVB1-4	HV1-4	#8	.169 4.3	.315 8.0	.276 7.0	.819 20.8						1000
	HVB1-5	HV1-5	#10	.209 5.3				.394 10.0	.157 4.0	.067 1.7	.030 0.75		1000
	HVB1-6	HV1-6	1/4	.252 6.4	.457 11.6	.433 11.0	1.055 26.8						1000
16-14 A.W.G. 1.5-2.5 mm ²	HVB2-3.7	HV2-3.7	#6	.146 3.7								IZUMI MODEL 34 WITH DIE INDEX COLOR:BLUE OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:BLUE	1000
	HVB2-4	HV2-4	#8	.169 4.3	.335 8.5	.291 7.4	.858 21.8						1000
	HVB2-5	HV2-5	#10	.209 5.3	.374 9.5	.287 7.3		.394 10.0	.177 4.5	.091 2.3	.031 0.8		1000
	HVB2-6	HV2-6	1/4	.252 6.4									1000
	HVB2-8	HV2-8	5/16	.331 8.4	.472 12.0	.433 11.0	1.055 26.8						1000
12-10 A.W.G. 4-6 mm ²	HVB5-3.7	HV5-3.7	#6	.146 3.7	.283 7.2	.240 6.1	.894 22.7					IZUMI MODEL 5 WITH DIE INDEX COLOR:YELLOW OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:YELLOW	500
	HVB5-4	HV5-4	#8	.169 4.3	.374 9.5	.374 9.5	1.055 26.8						500
	HVB5-5	HV5-5	#10	.209 5.3				.512 13.0	.252 6.4	.134 3.4	.039 1.0		500
	HVB5-6	HV5-6	1/4	.252 6.4	.472 12.0	.406 10.3	1.161 29.5						500
	HVB5-8	HV5-8	5/16	.331 8.4	.591 15.0	.531 13.5	1.339 34.0						500

UL cUL ALL LISTED

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

KS Terminals:

[HV1-3.7](#) [HV1-4](#) [HV1-5](#) [HV1-6](#) [HV2-3.7](#) [HV2-4](#) [HV2-5](#) [HV2-6](#) [HV5-4](#) [HV5-5](#) [HV5-8](#)