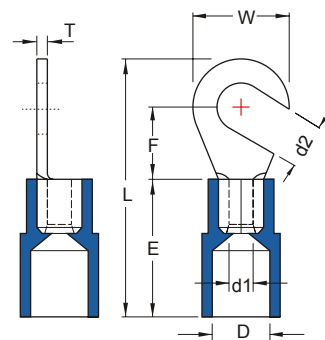


VINYL-INSULATED (MOLDED EASY ENTRY) HOOK TERMINALS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	9	12	17	18	30	35	50

MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.
INSULATION MATERIAL: VINYL
INSULATION COLOR:

 22-16 A.W.G.: RED ■ 16-14 A.W.G.: BLUE ■ 12-10 A.W.G.: YELLOW ■
TERMINAL MATERIAL: COPPER


WIRE RANGE A.W.G. mm²	ITEM NO.		STUD SIZE		DIMENSION inch mm							CRIMPING TOOL	Q'TY BOX
	BRAZED SEAM	BUTTED SEAM	d2		W	F	L	E	D	d1	T		
22-16 A.W.G. 0.5-1.5 mm²	HVYB1-3.7	HVY1-3.7	#6	.146 3.7								IZUMI MODEL 34 WITH DIE INDEX COLOR:RED OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:RED	1000
	HVYB1-4	HVY1-4	#8	.169 4.3	.315 8.0	.276 7.0	.858 21.8						1000
	HVYB1-5	HVY1-5	#10	.209 5.3				.433 11.0	.157 4.0	.067 1.7	.030 0.75		1000
	HVYB1-6	HVY1-6	1/4	.252 6.4	.457 11.6	.433 11.0	1.094 27.8						1000
16-14 A.W.G. 1.5-2.5 mm²	HVYB2-3.7	HVY2-3.7	#6	.146 3.7								IZUMI MODEL 34 WITH DIE INDEX COLOR:BLUE OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:BLUE	1000
	HVYB2-4	HVY2-4	#8	.169 4.3	.335 8.5	.291 7.4	.898 22.8						1000
	HVYB2-5	HVY2-5	#10	.209 5.3	.374 9.5	.287 7.3		.433 11.0	.177 4.5	.091 2.3	.031 0.8		1000
	HVYB2-6	HVY2-6	1/4	.252 6.4	.472 12.0	.433 11.0	1.094 27.8						1000
12-10 A.W.G. 4-6 mm²	HVYB5-3.7	HVY5-3.7	#6	.146 3.7	.283 7.2	.240 6.1	.894 22.7					IZUMI MODEL 5 WITH DIE INDEX COLOR:YELLOW OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:YELLOW	500
	HVYB5-4	HVY5-4	#8	.169 4.3									500
	HVYB5-5	HVY5-5	#10	.209 5.3	.374 9.5	.374 9.5	1.055 26.8	.512 13.0	.252 6.4	.134 3.4	.039 1.0		500
	HVYB5-6	HVY5-6	1/4	.252 6.4	.472 12.0	.406 10.3	1.161 29.5						500
	HVYB5-8	HVY5-8	5/16	.331 8.4	.591 15.0	.531 13.5	1.339 34.0						500

(UL) (UL) ALL LISTED

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[KS Terminals:](#)

[HVY1-5](#) [HVY2-4](#) [HVY2-5](#) [HVY5-5](#)