

VINYL-INSULATED (EASY ENTRY) LIPPED BLADE TERMINALS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	9	12	17	18	30	35	50


MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.

INSULATION MATERIAL: VINYL

INSULATION COLOR:

22-16 A.W.G.: RED 16-14 A.W.G.: BLUE 12-10 A.W.G.: YELLOW

TERMINAL MATERIAL: COPPER

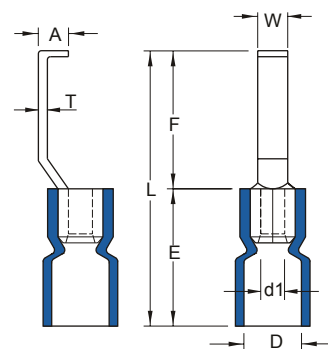

WIRE RANGE A.W.G. mm ²	ITEM NO.		DIMENSION inch mm								CRIMPING TOOL	Q'TY BOX
	BRAZED SEAM	BUTTED SEAM	W	F	L	E	D	d1	A	T		
22-16 A.W.G. 0.5-1.5 mm ²	LBVEB1-3	LBVE1-3	.118 3.0	.685 17.4	1.118 28.4	.441 11.2	.157 4.0	.067 1.7	.083 2.1	.030 0.75	IZUMI MODEL 34 WITH DIE INDEX COLOR:RED OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:RED	1000
	LBVEB1-4.6	LBVE1-4.6	.181 4.6									1000
16-14 A.W.G. 1.5-2.5 mm ²	LBVEB2-3	LBVE2-3	.118 3.0	.685 17.4	1.118 28.4	.453 11.5	.177 4.5	.091 2.3	.083 2.1	.031 0.8	IZUMI MODEL 34 WITH DIE INDEX COLOR:BLUE OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:BLUE	1000
	LBVEB2-4.6	LBVE2-4.6	.181 4.6									1000
12-10 A.W.G. 4-6 mm ²	LBVEB5-3	LBVE5-3	.118 3.0	.677 17.2	1.232 31.3	.555 14.1	.248 6.3	.134 3.4	.110 2.8	.039 1.0	IZUMI MODEL 5 WITH DIE INDEX COLOR:YELLOW OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:YELLOW	500
	LBVEB5-4.6	LBVE5-4.6	.181 4.6						.108 2.75			500

UL cUL ALL LISTED

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[KS Terminals:](#)

[LBVE1-3](#) [LBVE1-4.6](#) [LBVE2-3](#) [LBVE2-4.6](#)