

NYLON-FULLY INSULATED MALE DISCONNECTORS (A TYPE)

MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14
AMP.	3	4	7	10	15

MAXIMUM ELECTRICAL RATING: 105°C 300 VOLTS MAX.

INSULATION MATERIAL: NYLON TERMINAL MATERIAL: BRASS

INSULATION COLOR:


22-18 A.W.G.: RED

16-14 A.W.G.: BLUE

TERMINAL BARREL I.D.:

22-18 A.W.G.: C=1.7mm

16-14 A.W.G.: C=2.3mm

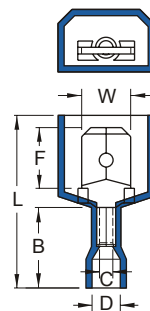

WIRE RANGE A.W.G. mm ²	ITEM NO.	NEMA TAB	DIMENSION inch mm						CRIMPING TOOL	Q'TY BOX
			W	F	L	B	D	T		
22-18 A.W.G. 0.5-0.75 mm ²	MDFNY1-250A	.032×.250 (0.8×6.35)	.250 6.35	.311 7.9	.866 22.0	.394 10.0	.142 3.6	.016 0.4	K.S. MODEL KST2000C WITH DIE INDEX COLOR:RED	500
16-14 A.W.G. 1.5-2.5 mm ²	MDFNY2-250A	.032×.250 (0.8×6.35)	.250 6.35	.311 7.9	.866 22.0	.394 10.0	.165 4.2	.016 0.4	K.S. MODEL KST2000C WITH DIE INDEX COLOR:BLUE	500

UL cUL ALL LISTED

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[KS Terminals:](#)

[MDFNY1-250A](#) [MDFNY2-250A](#)