

VINYL-INSULATED RECEPTACLE DISCONNECTORS


MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	3	4	7	10	15	20	24

MAXIMUM ELECTRICAL RATING: 75°C 600 VOLTS MAX.
INSULATION MATERIAL: VINYL **TERMINAL MATERIAL: BRASS**
INSULATION COLOR:

 22-16 A.W.G.: RED ■ 16-14 A.W.G.: BLUE ■ 12-10 A.W.G.: YELLOW ■
TERMINAL BARREL I.D.:

22-16 A.W.G.: C=1.7mm 16-14 A.W.G.: C=2.3mm 12-10 A.W.G.: C=3.4mm

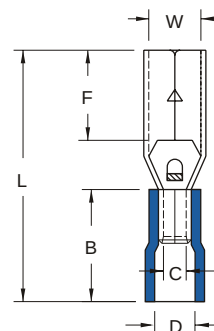

WIRE RANGE A.W.G. mm ²	ITEM NO.	DIMENSION ^{inch} mm						CRIMPING TOOL	Q'TY BOX
		W	F	L	E	D	T		
22-16 A.W.G. 0.5-1.5 mm ²	FRSV1-156	.154 3.9	.276 7.0	.846 21.5	.394 10.0	.157 4.0	.016 0.4	K.S.MODEL KST2000C WITH DIE INDEX COLOR:RED	1000
	FRSV1-180	.173 4.4	.276 7.0	.854 21.7					1000
16-14 A.W.G. 1.5-2.5 mm ²	FRSV2-156	.154 3.9	.283 7.2	.846 21.5	.394 10.0	.177 4.5	.016 0.4	K.S.MODEL KST2000C WITH DIE INDEX COLOR:BLUE	1000
	FRSV2-180	.173 4.4	.276 7.0	.854 21.7					1000
	FRSV2-195	.193 4.9	.272 6.9	.846 21.5					1000
12-10 A.W.G. 4-6 mm ²	FRSV5-195	.193 4.9	.272 6.9	.965 24.5	.512 13.0	.217 5.5	.018 0.45	K.S.MODEL KST2000C WITH DIE INDEX COLOR:YELLOW	500

VINYL-INSULATED BULLET DISCONNECTORS


MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	3	4	7	10	15	20	24

MAXIMUM ELECTRICAL RATING: 75°C 600 VOLTS MAX.
INSULATION MATERIAL: VINYL **TERMINAL MATERIAL: BRASS**
INSULATION COLOR:

 22-16 A.W.G.: RED ■ 16-14 A.W.G.: BLUE ■ 12-10 A.W.G.: YELLOW ■
TERMINAL BARREL I.D.:

22-16 A.W.G.: C=1.7mm 16-14 A.W.G.: C=2.3mm 12-10 A.W.G.: C=3.4mm

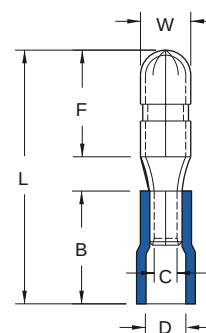

WIRE RANGE A.W.G. mm ²	ITEM NO.	DIMENSION ^{inch} mm						CRIMPING TOOL	Q'TY BOX
		W	F	L	B	D	T		
22-16 A.W.G. 0.5-1.5 mm ²	MPV1-156	.157 4.0	.335 8.5	.827 21.0	.394 10.0	.157 4.0	.016 0.4	K.S.MODEL KST2000C WITH DIE INDEX COLOR:RED	1000
	MPVL1-156		.413 10.5	.906 23.0					1000
	MPV1-180	.177 4.5	.335 8.5	.827 21.0					1000
	MPVL1-180		.425 10.8	.906 23.0					1000
16-14 A.W.G. 1.5-2.5 mm ²	MPV2-156	.157 4.0	.335 8.5	.827 21.0	.394 10.0	.177 4.5	.016 0.4	K.S.MODEL KST2000C WITH DIE INDEX COLOR:BLUE	1000
	MPVL2-156		.413 10.5	.906 23.0					1000
	MPV2-180	.177 4.5	.335 8.5	.827 21.0					1000
	MPVL2-180	.177 4.5	.425 10.8	.906 23.0					1000
	MPV2-195	.197 5.0	.335 8.5	.827 21.0					1000
12-10 A.W.G. 4-6 mm ²	MPV5-195	.197 5.0	.335 8.5	.925 23.5	.512 13.0	.217 5.5	.016 0.4	K.S.MODEL KST2000C WITH DIE INDEX COLOR:YELLOW	500

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

KS Terminals:

[MPV5-195](#) [MPVL1-156](#) [MPVL2-156](#) [MPV1-156](#) [MPV2-156](#) [MPV2-195](#)