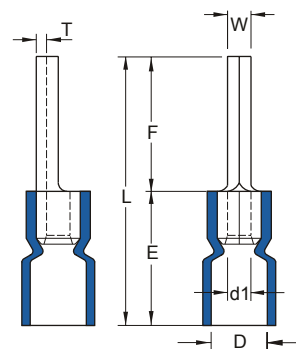


VINYL-INSULATED (EASY ENTRY) PIN TERMINALS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	9	12	17	18	30	35	50

MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.
INSULATION MATERIAL: VINYL
INSULATION COLOR:

 22-16 A.W.G.: RED ■ 16-14 A.W.G.: BLUE ■ 12-10 A.W.G.: YELLOW ■
TERMINAL MATERIAL: COPPER


WIRE RANGE A.W.G. mm ²	ITEM NO.		DIMENSION inch mm							CRIMPING TOOL	Q'TY BOX
	BRAZED SEAM	BUTTED SEAM	W	F	L	E	D	d1	T		
22-16 A.W.G. 0.5-1.5 mm ²	PTVEB1-7	PTVE1-7	.075 1.9	.276 7.0	.709 18.0	.441 11.2	.157 4.0	.067 1.7	.030 0.75	IZUMI MODEL 34 WITH DIE INDEX COLOR:RED OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:RED	1000
	PTVEB1-9	PTVE1-9		.354 9.0	.787 20.0						1000
	PTVEB1-10	PTVE1-10		.394 10.0	.827 21.0						1000
	PTVEB1-12	PTVE1-12		.472 12.0	.906 23.0						1000
	PTVEB1-13	PTVE1-13		.512 13.0	.945 24.0						1000
	PTVEB1-14	PTVE1-14		.551 14.0	.984 25.0						1000
	PTVEB1-16	PTVE1-16		.630 16.0	1.063 27.0						1000
16-14 A.W.G. 1.5-2.5 mm ²	PTVEB2-4.5	PTVE2-4.5	.075 1.9	.177 4.5	.622 15.8	.453 11.5	.177 4.5	.091 2.3	.031 0.8	IZUMI MODEL 34 WITH DIE INDEX COLOR:BLUE OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:BLUE	1000
	PTVEB2-7	PTVE2-7		.276 7.0	.720 18.3						1000
	PTVEB2-9	PTVE2-9		.354 9.0	.799 20.3						1000
	PTVEB2-10	PTVE2-10		.394 10.0	.839 21.3						1000
	PTVEB2-12	PTVE2-12		.472 12.0	.917 23.3						1000
	PTVEB2-13	PTVE2-13		.512 13.0	.957 24.3						1000
	PTVEB2-14	PTVE2-14		.551 14.0	.996 25.3						1000
12-10 A.W.G. 4-6 mm ²	PTVEB5-10	PTVE5-10	.110 2.8	.394 10.0	.988 25.1	.555 14.1	.248 6.3	.134 3.4	.039 1.0	IZUMI MODEL 5 WITH DIE INDEX COLOR:YELLOW OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:YELLOW	1000
	PTVEB5-13	PTVE5-13		.551 14.0	1.106 28.1						

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

KS Terminals:

[PTVE1-10](#) [PTVE1-12](#) [PTVE1-13](#) [PTVE1-9](#) [PTVE2-10](#) [PTVE2-12](#) [PTVE2-13](#) [PTVE2-9](#) [PTVE5-13](#)