

HEAT SHRINKABLE-RING TERMINALS "HD"(DOUBLE CRIMP TYPE)

MAXIMUM ELECTRIC CURRENT:

A.W.G.	16	14	12	10
AMP.	18	30	35	50


MAXIMUM ELECTRICAL RATING: 600 VOLTS MAX.

SHRINK TEMP.: 150°C OPERATING TEMP.: -40°C~+105°C

INSULATION MATERIAL: HIGH DENSITY PE.

INSULATION MATERIAL: WITH COPPER SLEEVE ON BARREL

TERMINAL MATERIAL: COPPER

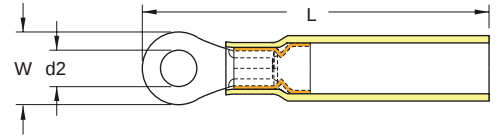

WIRE RANGE A.W.G. mm ²	ITEM NO.	DIMENSION						INSULATED COLOR	CRIMPING TOOL	Q'TY BOX
		d2		W		L				
		inch	mm	inch	mm	inch	mm			
16-14 A.W.G	RHD2-2	#2	2.2	.260	6.6	1.142	29.0	BLUE	K.S. MODEL KST2000G WITH DIE INDEX COLOR:BLUE	1000
	RHDS2-3.2	#4	3.2	.217	5.5	1.157	29.4			1000
	RHD2-3.2	#4	3.2	.260	6.6	1.134	28.8			1000
	RHDL2-3.2	#4	3.2	.335	8.5	1.094	27.8			1000
	RHDS2-3.7	#6	3.7	.260	6.6	1.220	31.0			1000
	RHDM2-3.7	#6	3.7			1.197	30.4			1000
	RHDL2-3.7	#6	3.7	.335	8.5	1.291	32.8			1000
	RHDS2-4	#8	4.3	.260	6.6	1.197	30.4			1000
	RHDL2-4	#8	4.3	.335	8.5	1.291	32.8			1000
	RHDS2-5	#10	5.3							1000
1.5-2.5 mm ²	RHDL2-5	#10	5.3	.374	9.5	1.252	31.8			1000
	RHD2-6	1/4	6.4	.472	12.0	1.476	37.5			500
	RHD2-7	5/16	7.4			1.496	38.0			500
	RHD2-8	5/16	8.4			1.417	36.0			500
	RHD2-9	5/16	9.8	.535	13.6	1.437	36.5			500
	RHD2-10	3/8	10.5			1.583	40.2			500
	RHDL2-10	3/8	10.5	.756	19.2	1.835	46.6			500
	RHD2-12	1/2	13.0			1.827	46.4			500
	RHD2-14	9/16	15.0	1.063	27.0	2.177	55.3			500
	RHD2-16	5/8	17.0							500
RHD2-20	3/4	21.0	500							

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[KS Terminals:](#)

[RHD2-10](#) [RHD2-6](#) [RHD2-8](#) [RHDL2-4](#) [RHDL2-5](#) [RHDS2-3.7](#)