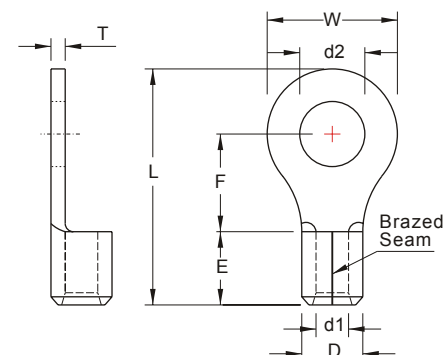


NON-INSULATED RING TERMINALS


MAXIMUM ELECTRIC CURRENT:

A.W.G.	2/0	3/0
AMP.	265	310

TERMINAL MATERIAL: COPPER
SURFACE TREATMENT: TIN PLATED

WIRE RANGE A.W.G. mm ²	ITEM NO.		STUD SIZE		DIMENSION ^{inch} mm							CRIMPING TOOL	Q'TY BOX					
	BRAZED SEAM	BUTTED SEAM	d2		W	F	L	E	D	d1	T							
2/0 A.W.G. 70 mm ²	RNB70-6		1/4	.252 6.4	.945 24.0	.787 20.0	1.969 50.0					IZUMI MODEL 9H-2 9H-150 12#A WITH DIE INDEX NO.:70 OR K.S. MODEL KH-150 WITH DIE INDEX NO.:70	100					
	RNB70-8		5/16	.331 8.4									100					
	RNB70-10		3/8	.413 10.5									100					
	RNB70-11		7/16	.453 11.5									100					
	RNB70-12		1/2	.512 13.0									100					
	RNB70-13		9/16	.551 14.0									.709 18.0	.689 17.5	.524 13.3	.079 2.0	100	
	RNB70-14		9/16	.591 15.0	1.260 32.0	1.024 26.0	2.402 61.0	100										
	RNB70-16		5/8	.669 17.0				100										
	RNB70-18		11/16	.748 19.0				100										
	RNB70-20		3/4	.827 21.0				100										
	RNB70-22		7/8	.906 23.0	100													
3/0 A.W.G. 80 mm ²	RNB80-6		1/4	.252 6.4	1.063 27.0	.815 20.7	2.134 54.2	.787 20.0	.768 19.5	.571 14.5	.091 2.3	IZUMI MODEL 9H-2 9H-150 12#A WITH DIE INDEX NO.:80 OR K.S. MODEL KH-150 WITH DIE INDEX NO.:95	50					
	RNB80-8		5/16	.331 8.4									50					
	RNB80-10		3/8	.413 10.5									50					
	RNBL80-10		3/8	.413 10.5	1.260 32.0	1.260 32.0	2.677 68.0						50					
	RNB80-11		7/16	.453 11.5	1.063 27.0	.815 20.7	2.134 54.2						50					
	RNB80-12		1/2	.512 13.0									50					
	RNBL80-12		1/2	.512 13.0	1.260 32.0	1.260 32.0	2.677 68.0						50					
	RNB80-13		9/16	.551 14.0	1.063 27.0	.815 20.7	2.134 54.2						50					
	RNB80-14		9/16	.591 15.0	1.260 32.0	1.260 32.0	2.677 68.0						50					
	RNB80-16		5/8	.669 17.0									50					
	RNB80-18		11/16	.748 19.0									50					
	RNB80-20		3/4	.827 21.0									50					
	RNB80-22		7/8	.906 23.0	50													



ALL LISTED

■ : 90D available

Products can be bend to 90-degrees angle.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

KS Terminals:

[RNB70-10](#) [RNB70-11](#) [RNB70-12](#) [RNB70-13](#) [RNB70-14](#) [RNB70-16](#) [RNB70-6](#) [RNB70-8](#) [RNB80-10](#) [RNB80-11](#)
[RNB80-12](#) [RNB80-16](#) [RNB80-20](#) [RNB80-6](#) [RNB80-8](#)