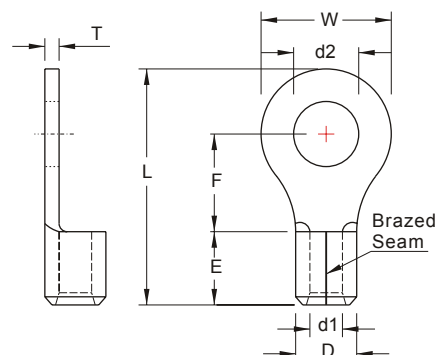


# NON-INSULATED RING TERMINALS


**MAXIMUM ELECTRIC CURRENT:**

|        |     |     |
|--------|-----|-----|
| A.W.G. | 4/0 | 250 |
| AMP.   | 360 | 405 |

**TERMINAL MATERIAL: COPPER**
**SURFACE TREATMENT: TIN PLATED**

| WIRE RANGE<br>A.W.G.<br>mm <sup>2</sup>   | ITEM NO.       |                | STUD SIZE |              | DIMENSION <sup>inch</sup><br>mm |               |               |               |               |              | CRIMPING<br>TOOL | Q'TY<br>BOX                                                                                                                                            |    |
|-------------------------------------------|----------------|----------------|-----------|--------------|---------------------------------|---------------|---------------|---------------|---------------|--------------|------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------|----|
|                                           | BRAZED<br>SEAM | BUTTED<br>SEAM | d2        |              | W                               | F             | L             | E             | D             | d1           |                  |                                                                                                                                                        | T  |
| 4/0<br>A.W.G.<br><br>360 mm <sup>2</sup>  | RNB100-6       |                | 1/4       | .252<br>6.4  | 1.122<br>28.5                   | .803<br>20.4  | 2.189<br>55.6 | .827<br>21.0  | .870<br>22.1  | .646<br>16.4 | .106<br>2.7      | IZUMI MODEL<br>9H-2<br><b>9H-150</b><br><b>12#A</b><br>WITH DIE INDEX<br>NO.:100<br><br>OR<br><br>K.S. MODEL<br>KH-150<br>WITH DIE INDEX<br>NO.:120    | 50 |
|                                           | RNB100-8       |                | 5/16      | .331<br>8.4  |                                 |               |               |               |               |              |                  |                                                                                                                                                        | 50 |
|                                           | RNB100-10      |                | 3/8       | .413<br>10.5 |                                 |               |               |               |               |              |                  |                                                                                                                                                        | 50 |
|                                           | RNBL100-10     |                | 3/8       | .413<br>10.5 | 1.260<br>32.0                   | 1.260<br>32.0 | 2.717<br>69.0 |               |               |              |                  |                                                                                                                                                        | 50 |
|                                           | RNB100-11      |                | 7/16      | .453<br>11.5 | 1.122<br>28.5                   | .803<br>20.4  | 2.189<br>55.6 |               |               |              |                  |                                                                                                                                                        | 50 |
|                                           | RNB100-12      |                | 1/2       | .512<br>13.0 |                                 |               |               |               |               |              |                  |                                                                                                                                                        | 50 |
|                                           | RNBL100-12     |                | 1/2       | .512<br>13.0 | 1.260<br>32.0                   | 1.260<br>32.0 | 2.717<br>69.0 |               |               |              |                  |                                                                                                                                                        | 50 |
|                                           | RNB100-14      |                | 9/16      | .591<br>15.0 |                                 |               |               |               |               |              |                  |                                                                                                                                                        | 50 |
|                                           | RNB100-16      |                | 5/8       | .669<br>17.0 |                                 |               |               |               |               |              |                  |                                                                                                                                                        | 50 |
|                                           | RNB100-18      |                | 11/16     | .748<br>19.0 |                                 |               |               |               |               |              |                  |                                                                                                                                                        | 50 |
|                                           | RNB100-20      |                | 3/4       | .827<br>21.0 |                                 |               |               |               |               |              |                  |                                                                                                                                                        | 50 |
|                                           | RNB100-22      |                | 7/8       | .906<br>23.0 |                                 |               |               |               |               |              |                  |                                                                                                                                                        | 50 |
| 250<br>MCM<br>125 mm <sup>2</sup>         | RNB125-10      |                | 3/8       | .453<br>10.5 | 1.181<br>30.0                   | .866<br>22.0  | 2.362<br>60.0 | .866<br>22.0  | .902<br>22.9  | .689<br>17.5 | .106<br>2.7      |                                                                                                                                                        | 50 |
|                                           | RNB125-12      |                | 1/2       | .512<br>13.0 |                                 |               |               |               |               |              |                  |                                                                                                                                                        | 50 |
|                                           | RNB125-16      |                | 5/8       | .669<br>17.0 |                                 |               |               |               |               |              |                  |                                                                                                                                                        | 50 |
| 250/300<br>MCM<br><br>150 mm <sup>2</sup> | RNB150-8       |                | 5/16      | .331<br>8.4  | 1.417<br>36.0                   | .906<br>23.0  | 2.598<br>66.0 | 1.063<br>27.0 | 1.047<br>26.6 | .768<br>19.5 | .126<br>3.2      | IZUMI MODEL<br>9H-2<br><b>9H-150</b><br><b>12#A</b><br>WITH DIE INDEX<br>NO.:150<br><br>OR<br><br>K.S. MODEL<br>KSTP-150D<br>WITH DIE INDEX<br>NO.:150 | 25 |
|                                           | RNBL150-8      |                | 5/16      | .331<br>8.4  |                                 | 1.417<br>36.0 | 3.189<br>81.0 |               |               |              |                  |                                                                                                                                                        | 25 |
|                                           | RNB150-10      |                | 3/8       | .413<br>10.5 |                                 | .906<br>23.0  | 2.598<br>66.0 |               |               |              |                  |                                                                                                                                                        | 25 |
|                                           | RNBL150-10     |                | 3/8       | .453<br>10.5 |                                 | 1.417<br>36.0 | 3.189<br>81.0 |               |               |              |                  |                                                                                                                                                        | 25 |
|                                           | RNB150-11      |                | 7/16      | .453<br>11.5 |                                 | .906<br>23.0  | 2.598<br>66.0 |               |               |              |                  |                                                                                                                                                        | 25 |
|                                           | RNB150-12      |                | 1/2       | .512<br>13.0 |                                 | .906<br>23.0  | 2.598<br>66.0 |               |               |              |                  |                                                                                                                                                        | 25 |
|                                           | RNBL150-12     |                | 1/2       | .512<br>13.0 |                                 | 1.417<br>36.0 | 3.189<br>81.0 |               |               |              |                  |                                                                                                                                                        | 25 |
|                                           | RNB150-14      |                | 9/16      | .591<br>15.0 |                                 | .906<br>23.0  | 2.598<br>66.0 |               |               |              |                  |                                                                                                                                                        | 25 |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## KS Terminals:

[RNB100-10](#) [RNB100-11](#) [RNB100-12](#) [RNB100-16](#) [RNB100-6](#) [RNB100-8](#) [RNB150-10](#) [RNB150-11](#) [RNB150-12](#)  
[RNB150-14](#) [RNB150-8](#) [RNBL150-12](#)