

NYLON-INSULATED RING TERMINALS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	8
AMP.	70


MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.

INSULATION MATERIAL: NYLON

INSULATION COLOR:

8 A.W.G.: RED ■

TERMINAL MATERIAL: COPPER

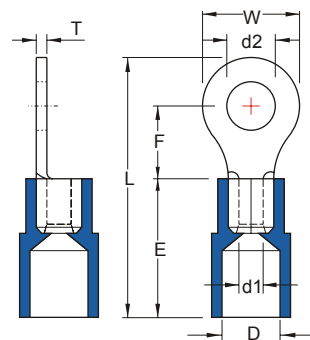

WIRE RANGE A.W.G. mm ²	ITEM NO.		STUD SIZE		DIMENSION ^{inch} mm							CRIMPING TOOL	Q'TY BOX			
	BRAZED SEAM	BUTTED SEAM	d2		W	F	L	E	D	d1	T					
8 A.W.G. 8 mm ²	RNYB8-3.7		#6	.146 3.7	.315 8.0	.366 9.3	1.142 29.0	.630 16.0	.315 8.0	.177 4.5	.047 1.2	K.S. MODEL KST-HDC38A WITH DIE INDEX :INS(mm)8	500			
	RNYBS8-4 ■		#8	.169 4.3												500
	RNYBL8-4		#8	.169 4.3									.472 12.0			500
	RNYBS8-5 ■		#10	.209 5.3	.346 8.8	.429 10.9	1.232 31.3								500	
	RNYBM8-5		#10	.209 5.3	.472 12.0	.366 9.3									500	
	RNYBL8-5		#10	.209 5.3	.591 15.0	.543 13.8	1.469 37.3								500	
	RNYBS8-6 ■		1/4	.252 6.4	.472 12.0	.366 9.3	1.232 31.3								500	
	RNYBL8-6 ■		1/4	.252 6.4											500	
	RNYB8-8		5/16	.331 8.4	.591 15.0	.543 13.8	1.469 37.3								500	
	RNYB8-10		3/8	.413 10.5											500	
	RNYB8-11		7/16	.453 11.5	.787 20.0	.591 15.0	1.614 41.0								500	
	RNYB8-12		1/2	.512 13.0											500	
	RNYB8-14		9/16	.591 15.0											500	
	RNYB8-16		5/8	.669 17.0											500	
	RNYB8-18		11/16	.748 19.0	.1244 31.6	1.008 25.6	2.244 57.0								500	
	RNYB8-20		3/4	.827 21.0											500	
	RNYB8-22		7/8	.906 23.0											500	



ALL LISTED

* : ADDITIONAL CERTIFIED

■ : 90D available

Products can be bend to 90-degrees angle.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

KS Terminals:

[RNYB8-10](#) [RNYB8-11](#) [RNYB8-12](#) [RNYB8-8](#) [RNYBL8-4](#) [RNYBL8-6](#) [RNYBM8-5](#) [RNYBS8-4](#) [RNYBS8-5](#) [RNYBS8-](#)

6