

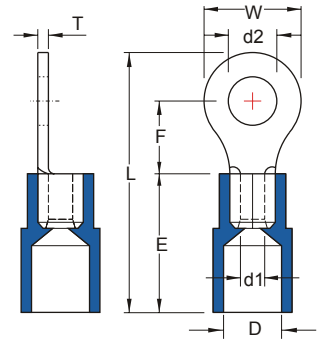
NYLON-INSULATED RING TERMINALS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	6	4
AMP.	95	125

MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.
INSULATION MATERIAL: NYLON
INSULATION COLOR:

6 A.W.G.: BLUE ■ 4 A.W.G.: YELLOW ■

TERMINAL MATERIAL: COPPER


WIRE RANGE A.W.G. mm ²	ITEM NO.		STUD SIZE	DIMENSION inch mm							CRIMPING TOOL	Q'TY BOX
	BRAZED SEAM	BUTTED SEAM		d2	W	F	L	E	D	d1	T	
6 A.W.G. 14 mm ²	RNYB14-4 ■		#8	.169 4.3	.472 12.0		1.583 40.2					250
	RNYBS14-5		#10	.209 5.3	.374 9.5		1.543 39.2					250
	RNYB14-5 ■		#10	.209 5.3	.472 12.0	.524 13.3	1.583 40.2					250
	RNYBSS14-6		1/4	.252 6.4	.374 9.5		1.543 39.2					250
	RNYBS14-6 ■		1/4	.252 6.4	.472 12.0		1.583 40.2					250
	RNYBL14-6		1/4	.252 6.4								250
	RNYB14-8 ■		5/16	.331 8.4	.630 16.0	.559 14.2	1.713 43.5	.846 21.5	.433 11.0	.228 5.8	.059 1.5	250
	RNYB14-10		3/8	.413 10.5								250
	RNYB14-11		7/16	.453 11.5	.866 22.0	.780 19.8	2.047 52.0					250
	RNYB14-12		1/2	.512 13.0								250
	RNYB14-14		9/16	.591 15.0								250
	RNYB14-16		5/8	.669 17.0	1.244 31.6	.996 25.3	2.441 62.0					250
	RNYB14-18		11/16	.748 19.0								250
	RNYB14-20		3/4	.827 21.0								250
4 A.W.G. 22 mm ²	RNYBS22-4		#8	.169 4.3								200
	RNYB22-4		#8	.169 4.3	.480 12.2	.594 15.1	1.780 45.2					200
	RNYBS22-5		#10	.209 5.3								200
	RNYBL22-5		#10	.209 5.3	.650 16.5	.531 13.5	1.791 45.5					200
	RNYBS22-6		1/4	.252 6.4	.480 12.2	.594 15.1	1.772 45.0	.945 24.0	.512 13.0	.303 7.7	.067 1.7	200
	RNYBL22-6 ■		1/4	.252 6.4	.650 16.5	.531 13.5	1.791 45.5					200
	RNYBS22-8		5/16	.331 8.4	.480 12.2	.594 15.1	1.780 45.2					200
	RNYB22-8 ■		5/16	.331 8.4	.650 16.5	.531 13.5	1.791 45.5					200
	RNYB22-10		3/8	.413 10.5								200
												200

 K.S. MODEL
KST-HDC38A
 WITH DIE INDEX
 :INS(mm)22


ALL LISTED

* : ADDITIONAL CERTIFIED

■ : 90D available

Products can be bend to 90-degrees angle.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

KS Terminals:

[RNYB14-10](#) [RNYB14-11](#) [RNYB14-12](#) [RNYB14-4](#) [RNYB14-5](#) [RNYB14-8](#) [RNYB22-10](#) [RNYB22-8](#) [RNYBL14-6](#)
[RNYBL22-6](#) [RNYBS14-6](#) [RNYBS22-5](#) [RNYBS22-6](#)