


**RoHS Compliant**

**CC-525/CC-530**

**PCI 2xRS422/485 18MBaud**

**"SERIAL CARDS ENGINEERED TO EXCEED EXPECTATIONS"**

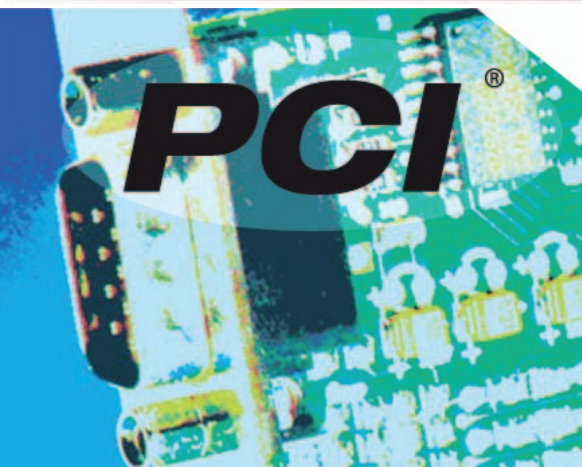

#### Features

- 2 port RS422/485
- PCI 2.3
- 128 Byte Tx and 128 Byte Rx FIFOs
- Up to 18,000,000 18 MegaBaud Baud
- DB9 connector (9 Pin Male)
- Drivers for all popular operating systems
- Sample Programs, Test & Terminal software
- Lifetime Support
- Lifetime Warranty (registration required)

#### Options



CC-525:  
PCI 2xRS422/485  
18MBaud

CC-530  
PCI 2xRS422/485  
15MBaud



#### Description

This PCI card can run at an amazing speed of up to 18,000,000 baud. It provides 2 industry standard RS422/485 serial ports for PC compatibles in a single PCI slot. The card has on-board zener diodes giving transient spike protection to the inputs - making it ideal for factory automation installations. Includes Drivers for all Windows 32 bit and 64 bit Operating Systems, including Windows 7.

Stunning ULTRA 15 or 18 megabaud data transfer rates!! And 128 byte deep FIFO guarantees uncompromising performance and fault free use.

With Brainboxes industry renowned Lifetime Warranty and 3 year Support!

#### Software

Microsoft signed drivers (easy installation & robust operation) for:

- Windows Server 2003 32 bit 64 bit Editions
- Windows XP 32 bit 64 bit editions
- Windows 2000
- 



As well as: full product documentation, a thorough troubleshooting guide and terminal software. Detailed sample source code for many popular programming languages. Further OS support on next page.



#### ORDER

Description

PCI 2xRS422/485 18MBaud

PCI 2xRS422/485 15MBaud

Code

CC-525

CC-530

## CC-525/CC-530 Full Specification

**PCI**®

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Brainboxes:

[CC-525](#) [CC-530](#)