


RoHS Compliant

UC-260/UC-271

LP uPCI 4xRS232

"SERIAL CARDS ENGINEERED TO EXCEED EXPECTATIONS"

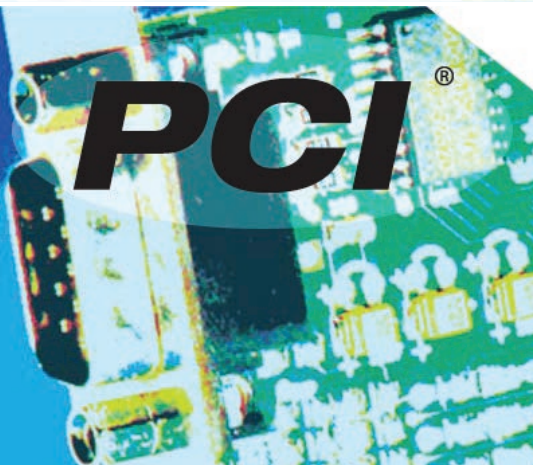

Description

Universal PCI providing four low profile RS232 serial ports 4x9 Pin connectors. Data transfer rates up to 115,200 baud rates and the 64 byte deep transmit and 64 byte receive FIFOs, coupled with 1Mbit/s line drivers deliver uncompromising performance on your PC. Includes drivers for all Windows 32 bit and 64 bit Operating Systems, including Windows 7.

With Brainboxes industry renowned Lifetime Warranty and Lifetime Support!

Features

- 4 port RS232
- PCI 3.0
- 64 Byte Tx and 64 Byte Rx FIFOs
- Up to 115,200 Baud
- DB9 connector (9 Pin Male)
- Drivers for all popular operating systems
- Sample Programs, Test & Terminal software
- Lifetime Support
- Lifetime Warranty (registration required)

Options



UC-260:
LP uPCI 4xRS232

UC-271
LP uPCI 4xRS232 DB25



Software

Microsoft signed drivers (easy installation & robust operation) for:

- Windows 7 32 bit 64 bit Editions
- Windows Server 2008 32 bit 64 bit Editions
- Windows Vista 32 bit 64 bit editions
- Windows Server 2003 32 bit 64 bit Editions

64 Bit
Driver

As well as: full product documentation, a thorough troubleshooting guide and terminal software. Detailed sample source code for many popular programming languages. Further OS support on next page.



ORDER

Description

LP uPCI 4xRS232

LP uPCI 4xRS232 DB25

Code





UC-260

UC-271



LP uPCI 4xRS232

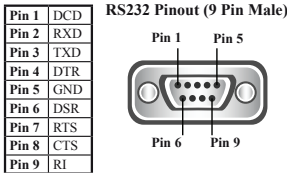UC-260/UC-271 Full Specification

Port 	Ports Connector FIFO size Operating Distance Cable	4 x RS232 DB9 Connector - 9 Pin Male 64 RX FIFO + 64 TX FIFO EIA - RS232 Standard 4 port cable 44 way D to 4x9 Pin
Port Settings 	Baud Rate Data Bits Parity Stop Bits Flow Control Tx/Rx Modes	115,200 5,6,7 or 8 Odd, Even, None, Mark or Space 1, 1.5 or 2 Point to Point
Interface 	OS Compatibility BUS	Microsoft Windows 7 32 bit 64 bit Editions Windows Server 2008 32 bit 64 bit Editions Windows Vista 32 bit 64 bit Editions Windows Server 2003 32 bit 64 bit Editions Windows XP 32 bit 64 bit Editions Microsoft Windows 2000 DOS PCI : Universal PCI is fully compatible with both 3.3Volt and 5Volt PCI slots.
Approvals	Industry Approvals Microsoft Approvals	AEO C-TPAT C-Tick Microsoft Certified Gold Partner WEEE RoHS EMC: CE TAA Windows 7 32 bit 64 bit Editions Windows Server 2008 32 bit 64 bit editions Windows Vista 32 bit 64 bit editions Windows Server 2003 32 bit 64 bit editions Windows XP 32 bit 64 bit editions
General	PCB Layers Power Consumption Weight Size	4 210mA @ 5V, 60mA @ 12V 0.067 kg 135l x 18w x 80h mm
Box Content	Packaging Card	Installation CD including manual, Microsoft signed drivers & utilities LP uPCI 4xRS232 4 port cable 44 way D to 4x9 Pin
Product Support 	Warranty Support	Lifetime (online registration required) Lifetime Web, Email and Phone Support from fully qualified, friendly staff who work in and alongside the Product Development Team
Additional 	OEM option Made In Customisable	Available for bulk buy OEM Manufactured in the UK by Brainboxes Winner 2005 European Electronics Industry Awards "Manufacturer of the Year" Brainboxes operate a "Perfect Fit Custom Design" policy for volume users. More Info: sales@brainboxes.com

Other PCI Cards: 1xRS232 | 2xRS232 | 4xRS232 | 8xRS232 | 1xRS422/485 | 2xRS422/485 | 4xRS422/485

Other Brainboxes Ranges: PCI Express | Bluetooth Serial Adapter | Ethernet to Serial Adapter | PCMCIA Serial Card | ExpressCard Serial Adapter | USB to Serial

+44(0) 151 220 2500 | sales@brainboxes.com | www.brainboxes.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Brainboxes:

UC-260