


RoHS Compliant

UC-263

LP uPCI 4xRS232 + LPT Printer Port

"SERIAL CARDS ENGINEERED TO EXCEED EXPECTATIONS"

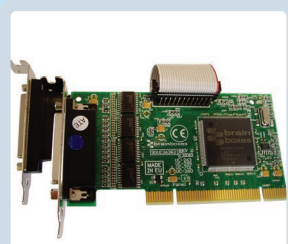

Description

Universal PCI providing four RS232 serial ports and one LPT port 4 industry standard 9 pin D RS232 ports with 25 pin D LPT port on a flylead. Data transfer rates up to 115,200 baud rates and the 64 byte deep transmit and 64 byte receive FIFOs, coupled with 1Mbit/s line drivers deliver uncompromising performance on your PC. Includes drivers for all Windows 32 bit and 64 bit Operating Systems, including Windows 7.

With Brainboxes industry renowned Lifetime Warranty and Lifetime Support!

Features

- 4 port RS232
- PCI 3.0
- 64 Byte Tx and 64 Byte Rx FIFOs
- Up to 115,200 Baud
- DB9 connector (9 Pin Male)
- Drivers for all popular operating systems
- Sample Programs, Test & Terminal software
- Lifetime Support
- Lifetime Warranty (registration required)

Software


Microsoft signed drivers (easy installation & robust operation) for:

- Windows 7 32 bit 64 bit Editions
- Windows Server 2008 32 bit 64 bit Editions
- Windows Vista 32 bit 64 bit editions
- Windows Server 2003 32 bit 64 bit Editions


64 Bit Driver

As well as: full product documentation, a thorough troubleshooting guide and terminal software. Detailed sample source code for many popular programming languages. Further OS support on next page.

Options

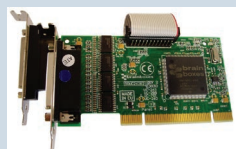

UC-263:
LP uPCI 4xRS232 + LPT
Printer Port

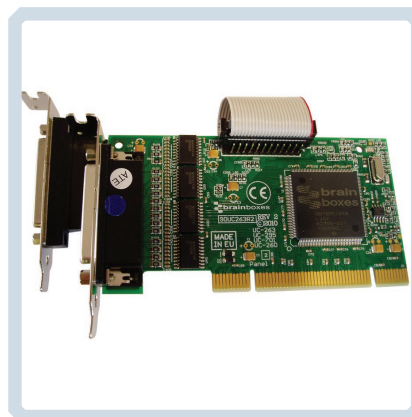


ORDER

Description

LP uPCI 4xRS232 + LPT Printer Port

Code

UC-263

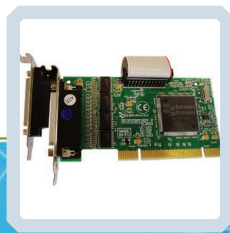

LP uPCI 4xRS232 + LPT Printer Port

UC-263 Full Specification

Port 	Ports Connector FIFO size Operating Distance Cable	4 x RS232 DB9 Connector 9 Pin Male and LPT port 25 Pin Female 64 RX FIFO + 64 TX FIFO EIA - RS232 Standard No Cable; Integrated Connector
Port Settings 	Baud Rate Data Bits Parity Stop Bits Flow Control Tx/Rx Modes	115,200 5,6,7 or 8 Odd, Even, None, Mark or Space 1, 1.5 or 2 Point to Point
Interface 	OS Compatibility BUS	Microsoft Windows 7 32 bit 64 bit Editions Windows Server 2008 32 bit 64 bit Editions Windows Vista 32 bit 64 bit Editions Windows Server 2003 32 bit 64 bit Editions Windows XP 32 bit 64 bit Editions DOS Plus Printer Port :
Approvals	Industry Approvals Microsoft Approvals	AEO C-TPAT Microsoft Certified Gold Partner WEEE RoHS EMC: CE TAA Windows 7 32 bit 64 bit Editions Windows Server 2008 32 bit 64 bit editions Windows Vista 32 bit 64 bit editions Windows Server 2003 32 bit 64 bit editions Windows XP 32 bit 64 bit editions
General	PCB Layers Power Consumption Weight Size	4 300mA @ 5V, 60mA @12V 0.069 kg 135l x 18w x 80h mm
Box Content	Packaging Card	Installation CD including manual, Microsoft signed drivers & utilities LP uPCI 4xRS232 + LPT Printer Port No Cable; Integrated Connector
Product Support 	Warranty Support	Lifetime (online registration required) Lifetime Web, Email and Phone Support from fully qualified, friendly staff who work in and alongside the Product Development Team
Additional 	OEM option Made In Customisable	Available for bulk buy OEM Manufactured in the UK by Brainboxes Winner 2005 European Electronics Industry Awards "Manufacturer of the Year" Brainboxes operate a "Perfect Fit Custom Design" policy for volume users. More Info: sales@brainboxes.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Brainboxes:

UC-263