


**RoHS Compliant**

**UC-414**

**uPCI 3+1xRS232+LPT Printer Port**

**"SERIAL CARDS ENGINEERED TO EXCEED EXPECTATIONS"**

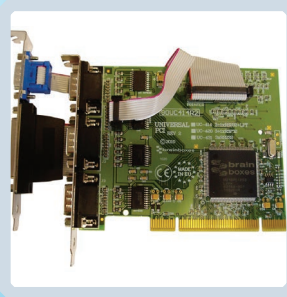

#### Description

Universal PCI providing four RS232 serial ports and one LPT port 3 industry standard 9 pin D RS232 ports on the bracket with a another 9 pin D RS232 port on a flylead. The 25pin D LPT port is also available by a flylead. Data transfer rates up to 115,200 baud rates and the 64 byte deep transmit and 64 byte receive FIFOs, coupled with 1Mbit/s line drivers deliver uncompromising performance on your PC. Includes drivers for all Windows 32 bit and 64 bit Operating Systems, including Windows 7.

With Brainboxes industry renowned Lifetime Warranty and Lifetime Support!

#### Features

- 4 port RS232
- PCI 3.0
- 64 Byte Tx and 64 Byte Rx FIFOs
- Up to 115,200 Baud
- DB9 connector (9 Pin Male)
- Drivers for all popular operating systems
- Sample Programs, Test & Terminal software
- Lifetime Support
- Lifetime Warranty (registration required)

#### Options



UC-414:  
uPCI 3+1xRS232+LPT  
Printer Port


#### Software

Microsoft signed drivers (easy installation & robust operation) for:

- Windows 7 32 bit 64 bit Editions
- Windows Server 2008 32 bit 64 bit Editions
- Windows Vista 32 bit 64 bit editions
- Windows XP 32 bit 64 bit editions



As well as: full product documentation, a thorough troubleshooting guide and terminal software. Detailed sample source code for many popular programming languages. Further OS support on next page.

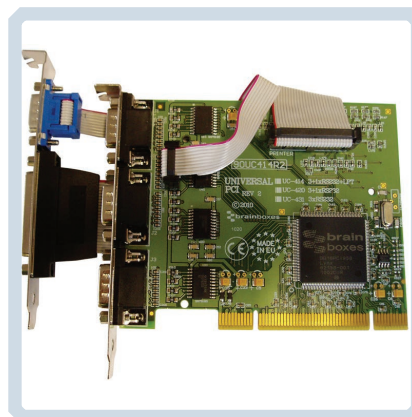


#### ORDER

Description

uPCI 3+1xRS232+LPT Printer Port

Code

UC-414

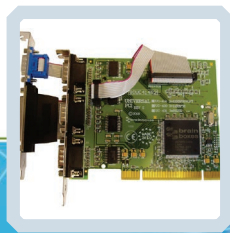

# uPCI 3+1xRS232+LPT Printer Port

## UC-414 Full Specification

<b>Port</b>  	<b>Ports</b>  Connector FIFO size Operating Distance Cable	4 x RS232  DB9 Connector 9 Pin Male and LPT port 64 RX FIFO + 64 TX FIFO EIA - RS232 Standard 1 port RS232 on fly lead
<b>Port Settings</b>  	Baud Rate  Data Bits Parity Stop Bits Flow Control Tx/Rx Modes	115,200  5,6,7 or 8 Odd, Even, None, Mark or Space 1, 1.5 or 2  Point to Point
<b>Interface</b>  	OS Compatibility         BUS	Microsoft Windows 7 32 bit 64 bit Editions Windows Server 2008 32 bit 64 bit Editions Windows Vista 32 bit 64 bit Editions Windows Server 2003 32 bit 64 bit Editions Windows XP 32 bit 64 bit Editions DOS     Plus Printer Port :
<b>Approvals</b>	Industry Approvals  Microsoft Approvals	AEO C-TPAT Microsoft Certified Gold Partner WEEE RoHS EMC: CE TAA  Windows 7 32 bit 64 bit Editions Windows Server 2008 32 bit 64 bit editions Windows Vista 32 bit 64 bit editions Windows Server 2003 32 bit 64 bit editions Windows XP 32 bit 64 bit editions
<b>General</b>	PCB Layers  Power Consumption  Weight  Size	4  300mA @ 5V, 60mA @ 12V  0.098 kg  133l x 18w x 120h mm
<b>Box Content</b>	Packaging  Card	Installation CD including manual, Microsoft signed drivers & utilities  uPCI 3+1xRS232+LPT Printer Port 1 port RS232 on fly lead
<b>Product Support</b>  	Warranty  Support	Lifetime (online registration required)  Lifetime Web, Email and Phone Support from fully qualified, friendly staff who work in and alongside the Product Development Team
<b>Additional</b>  	OEM option  Made In  Customisable	Available for bulk buy OEM  Manufactured in the UK by Brainboxes Winner 2005 European Electronics Industry Awards "Manufacturer of the Year" Brainboxes operate a "Perfect Fit Custom Design" policy for volume users. More Info: <a href="mailto:sales@brainboxes.com">sales@brainboxes.com</a>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Brainboxes:

[UC-420](#) [UC-414](#)