


RoHS Compliant

UC-607

uPCI 2xRS232 230K Baud

"SERIAL CARDS ENGINEERED TO EXCEED EXPECTATIONS"

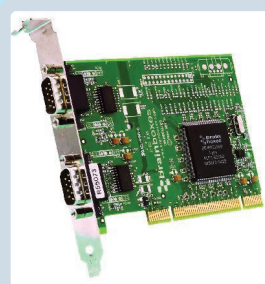

Description

Universal PCI card provides 2 industry standard 9 pin RS232 serial COM ports in a single PCI slot, capable of baud rates up to 230,400. Includes drivers for all Windows 32 bit and 64 bit Operating Systems, including Windows 7.

With Brainboxes industry renowned Lifetime Warranty and Lifetime Support!

Features

- 2 port RS232
- PCI 3.0
- 128 Byte Tx and 128 Byte Rx FIFOs
- Up to 230,400 Baud
- DB9 connector (9 Pin Male)
- Drivers for all popular operating systems
- Sample Programs, Test & Terminal software
- Lifetime Support
- Lifetime Warranty (registration required)

Options



UC-607:
uPCI 2xRS232 230K Baud


Software

Microsoft signed drivers (easy installation & robust operation) for:

- Windows 7 32 bit 64 bit Editions
- Windows Server 2008 32 bit 64 bit Editions
- Windows Vista 32 bit 64 bit editions
- Windows Server 2003 32 bit 64 bit Editions

64 Bit
Driver

As well as: full product documentation, a thorough troubleshooting guide and terminal software. Detailed sample source code for many popular programming languages. Further OS support on next page.

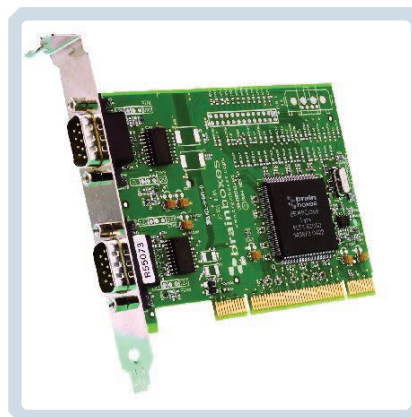


ORDER

Description

uPCI 2xRS232 230K Baud




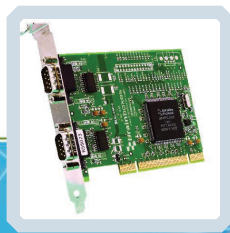

Code

UC-607

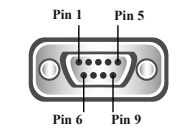

uPCI 2xRS232 230K Baud

UC-607 Full Specification

| | | |
|---|--|--|
| Port  | Ports Connector FIFO size Operating Distance Cable | 2 x RS232 DB9 Connector - 9 Pin Male 128 RX FIFO + 128 TX FIFO EIA - RS232 Standard No Cable; Integrated Connector |
| Port Settings  | Baud Rate Data Bits Parity Stop Bits Flow Control Tx/Rx Modes | 230,400 5,6,7 or 8 Odd, Even, None, Mark or Space 1, 1.5 or 2 Point to Point |
| Interface  | OS Compatibility BUS | Microsoft Windows 7 32 bit 64 bit Editions Windows Server 2008 32 bit 64 bit Editions Windows Vista 32 bit 64 bit Editions Windows Server 2003 32 bit 64 bit Editions Windows XP 32 bit 64 bit Editions Microsoft Windows 2000 DOS PCI : Universal PCI is fully compatible with both 3.3Volt and 5Volt PCI slots. |
| Approvals | Industry Approvals Microsoft Approvals | AEO C-TPAT C-Tick Microsoft Certified Gold Partner WEEE RoHS EMC: CE FCC Compliant TAA Windows 7 32 bit 64 bit Editions Windows Server 2008 32 bit 64 bit editions Windows Vista 32 bit 64 bit editions Windows Server 2003 32 bit 64 bit editions Windows XP 32 bit 64 bit editions |
| General | PCB Layers Power Consumption Weight Size | 4 200mA @ 5V, 7mA @ 12V 0.079 kg 136l x 18w x 120h mm |
| Box Content | Packaging Card | Installation CD including manual, Microsoft signed drivers & utilities uPCI 2xRS232 230K Baud No Cable; Integrated Connector |
| Product Support  | Warranty Support | Lifetime (online registration required) Lifetime Web, Email and Phone Support from fully qualified, friendly staff who work in and alongside the Product Development Team |
| Additional  | OEM option Made In Customisable | Available for bulk buy OEM Manufactured in the UK by Brainboxes Winner 2005 European Electronics Industry Awards "Manufacturer of the Year" Brainboxes operate a "Perfect Fit Custom Design" policy for volume users. More Info: sales@brainboxes.com |

Other PCI Cards: 1xRS232 | 2xRS232 | 4xRS232 | 8xRS232 | 1xRS422/485 | 2xRS422/485 | 4xRS422/485

Other Brainboxes Ranges: PCI Express | Bluetooth Serial Adapter | Ethernet to Serial Adapter | PCMCIA Serial Card | ExpressCard Serial Adapter | USB to Serial

+44(0) 151 220 2500 | sales@brainboxes.com | www.brainboxes.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Brainboxes:

UC-607