


POWERHUB 1

Lighting + Power Solution

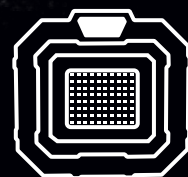

5000 Lumen
Adjustable Work Light



6× 15A 120V AC Outlets



GFCI, Surge &
Overcurrent Protection



USB-A & USB-C Outputs

**KLEIN
TOOLS®**



POWERHUB 1

Distribute power and lighting to the jobsite from a central location with the Klein Tools PowerHub 1 (Cat. No. 29610). The space saving, vertical design keeps electrical plugs off the ground by stacking six covered, surge protected 120V outlets. The built-in GFCI removes the need for additional GFCI adapters. Brighten up dimly lit areas with the adjustable, 5,000 lumen LED work light. Easily carry to any location by grabbing the rugged, exoskeleton handles that are conveniently located on the top and sides of the PowerHub 1.

INTEGRATED CORD WRAP FOR STORING POWER CORDS



KEEPS PLUGS AND CHARGING ELECTRONICS OFF THE GROUND



PORTABLE AND EASY TO CARRY



Multiple grab locations for convenient carrying

Tightening knob holds work light at perfect position

Built-In GFCI helps protect against ground faults

GFCI LED indicator to confirm operation

2x USB-C and 2x USB-A Ports for charging electronics

Rugged Exoskeleton to help protect PowerHub 1

Side Handle

6x 120V AC outlets to power 15A equipment

ETL
Intertek
5022091



Elevated adjustable, LED work light (5,000 lumens)

Illuminated 120V outlet ON/OFF switch

LEDs indicate surge protection and grounded power status



Work light ON/OFF button

3x Device shelves hold phones while charging

120V AC input to power device
*Power cord not included



For Professionals
SINCE 1857™



Cat. No.	UPC 0-92644+	Description	Lumens	USB Ports	Dimensions
29610	29610-9	PowerHub 1	5000	2x USB-C 2x USB-A	14" x 14" x 25" (35.6 x 35.6 x 63.5 cm)

Visit www.kleintools.com for warnings and instructions.

See our complete line of **Portable Power Products**
www.kleintools.com



© 2022 Klein Tools, Inc.
Lincolnshire, IL 60069
82990 Rev. 10/22 A

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Klein Tools:](#)

[29610](#)