


DUAL IR/PROBE THERMOMETER

POCKET METER FOR TEMPERATURE MEASUREMENTS **IR07**



IR Features:

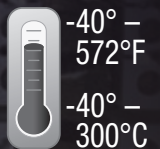

IR (Infrared) thermometer accurately measures surface temperature, -40 to 572°F (-40 to 300°C), with a Distance-to-Spot ratio 8:1

Includes a target laser, which can also be used as a laser pointer



Probe Features:



Probe accurately measures air, liquid, and surface temperatures, -40 to 572°F (-40 to 300°C)

Nub makes it easy to open and avoids heat transfer from having to touch the probe



Convenient hook for hands-free Indoor Air Quality Measurements

DUAL IR/PROBE THERMOMETER

The IR07, Dual IR/Probe Thermometer is a rugged pocket size tool for temperature measurements of -40 to 572°F (-40 to 300°C). It features a backlit display with Hold, Max/Min, Auto Power Off, and Low battery functions. Quickly calculate differential temperature (T1-T2) for both IR and probe temperatures.



CAUTION: Reflective materials may be hotter than indicated. Laser radiation-Do NOT stare into beam. Class 2 laser product.

Thermometer is NOT intended for use on people or animals.

Cat. No.	UPC	Description	Height	Length	Width	Weight
IR07	092644-69181-2	Dual Infrared and Probe Thermometer	0.95" (24.1 mm)	5.82" (147.8 mm)	1.67" (42.4 mm)	3.60 oz (106.5 g)

See our complete line of Test & Measure products
www.kleintools.com



© 2019 Klein Tools, Inc.
 Lincolnshire, IL 60069-1418
 82807 01/19 A



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Klein Tools:

IR07