


# LASER LINE BUBBLE LEVEL

LBL100

Projects a horizontal  
crisp laser line and spot  
parallel to the base of level

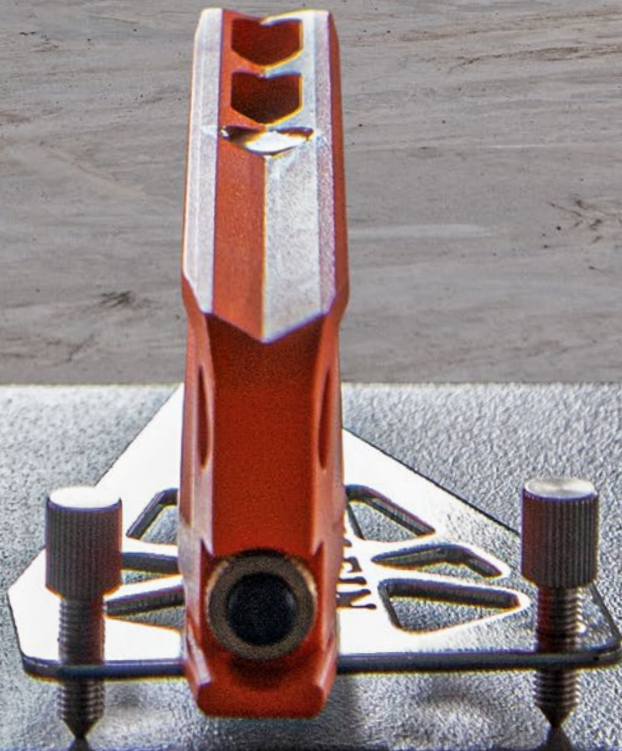

**KLEIN  
TOOLS** 



**CRISP**  
LASER LINE  
AND SPOT

**PROJECTS**  
**UP TO 75 FEET**  
INDOOR VIEWING

## LASER LINE BUBBLE LEVEL LBL100

The Klein Tools Laser Line Bubble Level projects a bright, crisp laser line and spot parallel to the base of the level up to 75 ft. (22.9 m). Three easy to read vials identify horizontal and cross at 0° level and vertical at 90°. The strong magnetic base attaches to ferromagnetic surfaces. The top features a V-groove to fit the contour of pipe and conduit. Included is a leveling base for manual leveling on uneven surfaces.




Large top view windows

**V-Groove** fits contour of pipe and conduit

### Easy-to-read vials

- Vertical
- Cross
- Horizontal

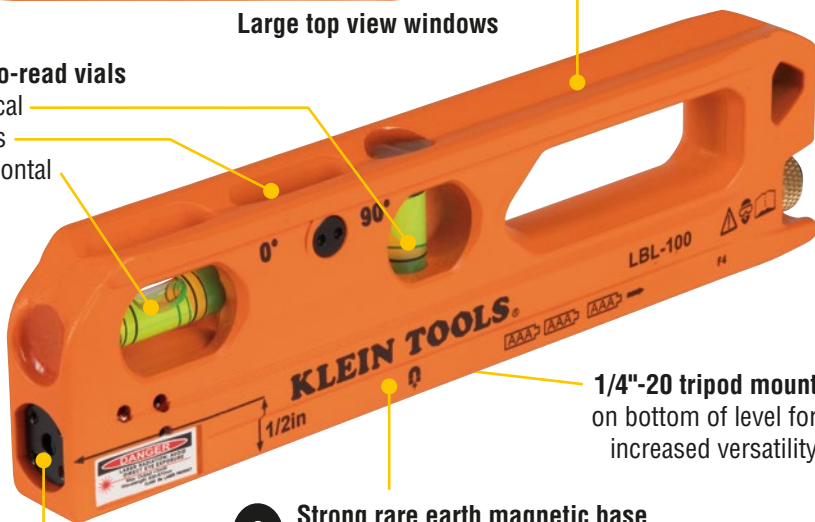

**1/4"-20 tripod mount** on bottom of level for increased versatility




**Strong rare earth magnetic base** attaches to ferromagnetic surfaces

### Crisp Laser

projects 1/2" (12.7 mm) above base

**High-visibility orange** cast aluminum body is easy to see on conduit and jobsites

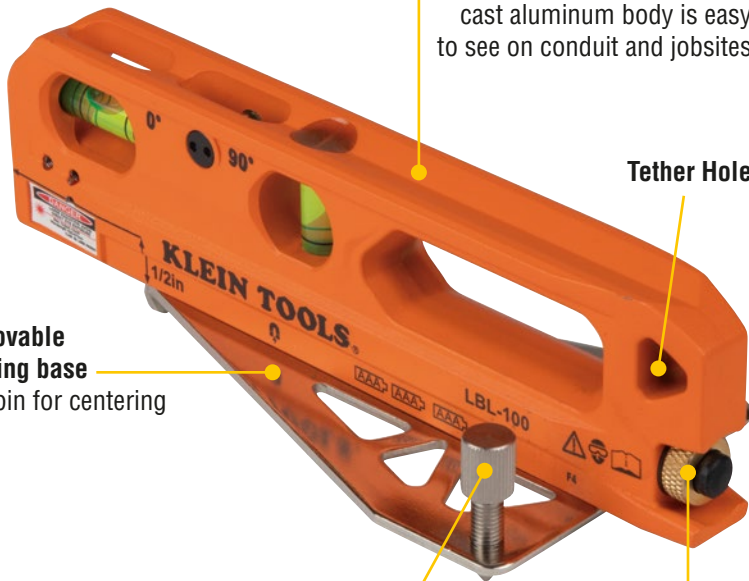

**Tether Hole**

**Removable leveling base** with pin for centering



**3x AAA INCLUDED**



**IP54**

**Thumb screws** for adjusting the base

**Laser Power Button** and Battery Cap

Cat. No.	UPC# 0-92644+	Description	Number of Vials	Type of Vials	Overall Length
LBL100	69209-3	Laser Line Bubble Level	3	0° Horizontal and Cross, 90° Vertical	7.3" (158 mm)

**Warning statement:** Visit [www.kleintools.com](http://www.kleintools.com) for safety warnings. Failure to follow all instructions and warnings may result in personal injury.



See our complete line of **Levels & Measuring Tools**

[www.kleintools.com](http://www.kleintools.com)



© 2019 Klein Tools, Inc.  
Lincolnshire, IL 60069-1418  
82857 Rev. 09/19 A



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Klein Tools:](#)

[LBL100](#)