

SAFETY HELMETS


SAFETY • COMFORT • FIT



**KLEIN
TOOLS®**



PROTECTION FROM IMPACT, PENETRATION, AND LATERAL DEFORMATION

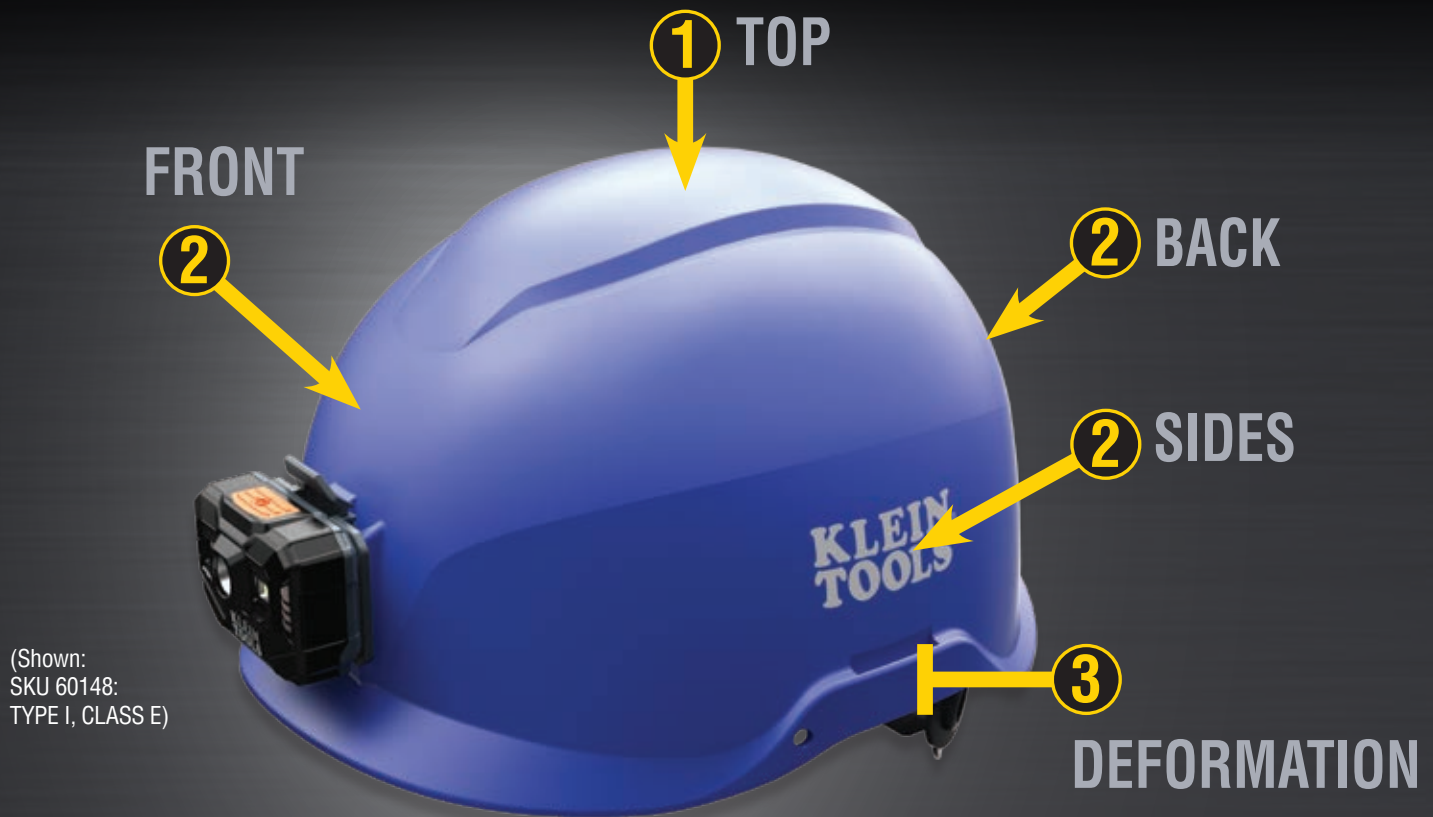

KLEIN SAFETY HELMETS ARE TESTED TO THE LATEST STANDARDS

TYPE I, CLASS E
ELECTRICAL PROTECTION
UP TO 20KV

TYPE I, CLASS C
ADJUSTABLE SIDE VENTS HELP
MANAGE AIR CIRCULATION

① **ANSI/SEA Z89.1-2014**
CSA Z94.1-15

② **EN12492:2012***
4.2.1.2, 4.2.1.3, 4.2.1.4,
4.2.2, 4.2.3, 4.2.4

③ **EN397:2012+A1:2012:**
5.2.1, 5.2.4, 5.2.5

*This helmet provides LIMITED protection from small objects striking the top, front, back, left and right sides of the helmet. This is NOT an ANSI/CSA Type II helmet.

BUILDING ON A TRADITION OF SAFETY, COMFORT & FIT



Chin Strap
4-point attachment
to maintain stability
and secure fit.
(Cat. # CLMBRSTRP)



Sweatband and Top Comfort Pad
Sweat-wicking and breathable padding
materials, provide extra coverage and
prevent straps from digging into your
head. Replaceable and machine washable.
(Cat. #KHHTOPPAD, and KHHSWTBND)



Pivot Adjustment
Allows user to position the
ratchet mechanism to clear
bandana knots and
pony-tails.



Ratchet Adjustment
Large knob mechanism
allows for easy one-hand
adjustment, even with
gloves on.

Klein Tools Safety Helmets build on the same innovative features and attributes of the Klein® Hard Hats with an unwavering focus on **safety, comfort and fit**. With fall protection safety in mind, these helmets with integrated chin straps, have been tested for top, side, front/back impact and penetration. The helmet's compact and lightweight design allows easy access to confined spaces and makes it ideal for at-height applications.

NON-VENTED CLASS E

Specifically designed for electricians, telecom tower technicians, windmill technicians and linemen working at height, these non-vented safety helmets are tested up to 20kV of protection.

ACCESSORY MOUNTS

Patent-pending accessory mounts ensure Klein Headlamps are always positioned properly with **NO STRAP** needed!

VENTED CLASS C

Designed for maximum comfort. These compact vented helmets are built for plumbers, carpenters, arborists, and general construction who work in tight spaces or at-height job sites that don't need electrical protection. Adjustable vents allow to control air flow in both hot and cold weather.



UNIVERSAL ACCESSORY SLOTS

on both sides for hearing protection, face shield, and more.

SIX-POINT SUSPENSION

for enhanced stability and secure fit

OPEN-FRAME DESIGN

for maximum air circulation

REAR NECK PAD


made of soft material to conform and grip to maintain ratchet location



VISOR MOUNTING POINT

CHIN STRAP

Detachable, leather-bound and adjustable 4-point attachment for secure fit.

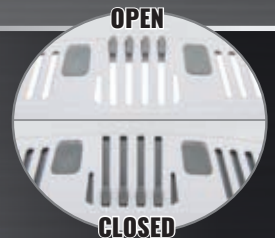

LARGER VENTS = BETTER VENTILATION

The adjustable vents can be opened or closed for maximum air circulation.

KLEIN® HEADLAMPS/WORK LIGHTS

offer a range of model options to suit most jobsite demands—and will easily mount to every Klein Safety Helmet (or Klein Hard Hat) with **NO STRAP NEEDED!**

(#56062 shown)



DETACHABLE VISOR

with up/down lock positions.



VISORS

Clear and Gray visors designed specifically for Klein Safety Helmets. Anti-fog, scratch-resistant, 99.9% UV blocking, lightweight with high optical clarity. Locks up and down to stay in place (Cat. #VISORCLR and VISORGRAY)



VISORCLR



VISORGRAY



60145



60146



60147



60148



60149



60150



VISORCLR







VISORGRAY

KLEIN SAFETY HELMETS

Cat. No.	UPC 0-92644+	Safety Helmet description	Headlamp Model	Class	Type	Shell Color
60145	60145-3	Non-vented	n/a	E	I	White
60146	60146-0	Non-vented with rechargeable headlamp	56062			White
60147	60147-7	Non-vented	n/a			Blue
60148	60148-4	Non-vented with rechargeable headlamp	56062			Blue
60149	60149-1	Vented	n/a	C	I	White
60150	60150-7	Vented with rechargeable headlamp	56062			White

HEADLAMPS & ACCESSORIES

Cat. No.	UPC 0-92644+	Description	Lumens	Batteries	Battery Life	
56062	56062-0	Rechargeable Headlamp/ Magnetic Worklight	Boost: 300 Spot/High: 215 Flood/Low: 100	Rechargeable, Lithium-ion	Boost: 4 hrs Spot/High: 9 hrs Flood/Low: 14 hrs	
56048	56048-4	Rechargeable Auto-Off Headlamp	Boost: 400 Spot/High: 200 Flood/Low: 100	Rechargeable, Lithium-ion	Boost: 4 hrs Spot/High: 12 hrs Flood/Low: 22 hrs	
56049	56049-1	Rechargeable Light Array Headlamp/ Magnetic Worklight	High: 260 Low: 125	Rechargeable, Lithium-ion	High: 9 hrs Low: 14 hrs	
KHH56220	56043-9	Alkaline Headlamp/ Magnetic Worklight	Spotlight: 150 Floodlight: 50	3 x AAA	Spotlight: 6 hrs Floodlight: 10 hrs	

Cat. No.	UPC 0-92644+	Description	Pkg Qty	
CLMBRSPN*	60167-5	Safety Helmet Suspension	1	*Does NOT include top pad and sweatband. All sold separately.
CLMBRSTRP	60168-2	Safety Helmet Chin Strap	1	
KHHSWTBND	60088-3	Suspension Sweatband	3	
KHHTOPPAD	60089-0	Suspension Top Pad	3	



CLMBRSPN*

*Shown with top pad and sweatband, all sold separately.



CLMBRSTRP



KHHTOPPAD



KHHSWTBND

VISORS


CAT No.	UPC 0-92644+	Description	Optical Clarity	UV Protection	Anti-fog	Scratch Resistant	ANSI (US)	CSA (Canada)	Military Impact Standards
VISORCLR	60169-9	Clear, detachable half-face visor	Class 1	99.9% UV-A, UV-B, and UV-C per ANSI Z87.1 U6	Yes	Yes	Z87.1+ 2020 (High Impact rated)	Z94.3-20	MIL-PRF-32432A-Class 1 (Clause 3.8.4.1) -Ballistics fragmentation
VISORGRAY	60170-5	Tinted Gray, detachable half-face visor							

For Professionals
SINCE 1857™

Warning statement: Visit www.kleintools.com for safety warnings.



 See our complete line of Personal Protective Equipment
www.kleintools.com



© 2020 Klein Tools, Inc.
Lincolnshire, IL 60069
82900 Rev. 06/20 A

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Klein Tools:

[60145](#) [60146](#) [60147](#) [60148](#) [60149](#) [60150](#) [VISORCLR](#) [VISORGRAY](#)