


# Adjustable Wrenches

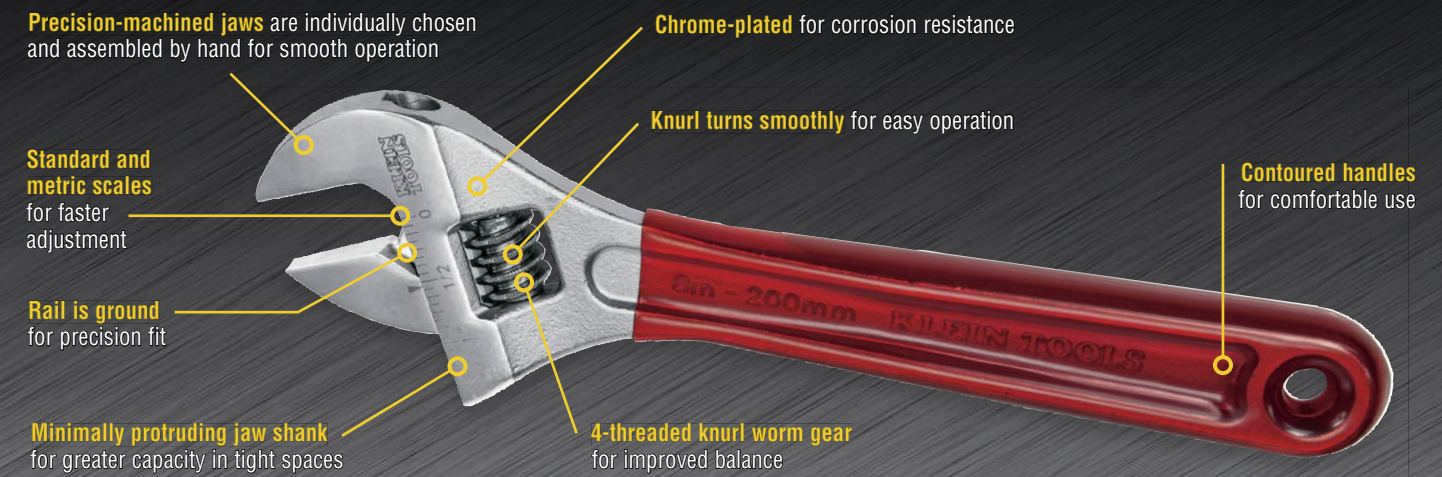

## Adjustable Wrenches

Includes core adjustable wrench features plus:

- High capacity smaller wrenches handle bigger jobs, especially in confined spaces
- Extra-wide 1/2" (12.7 mm) jaw that provides the same capacity as a standard 12" (304.8 mm) adjustable wrench (Cat. No. D509-8)



Cat. No.	Jaw Capacity	Overall Length	Handle Color	Handle Finish
<b>High Capacity</b>				
507-6	15/16" (23.8 mm)	6.375" (161.9 mm)	Chrome	High-Polish Chrome
507-8	1-1/8" (28.6 mm)	8.125" (206.4 mm)	Chrome	High-Polish Chrome
507-10	1-5/16" (33.3 mm)	10.125" (257.2 mm)	Chrome	High-Polish Chrome
507-12	1-1/2" (38.1 mm)	12.25" (311.2 mm)	Chrome	High-Polish Chrome
D507-6	15/16" (23.8 mm)	6.5" (165.1 mm)	Transparent Red	Plastic-Dipped
D507-8	1-1/8" (28.6 mm)	8.25" (209.6 mm)	Transparent Red	Plastic-Dipped
D507-10	1-5/16" (33.3 mm)	10.25" (260.4 mm)	Transparent Red	Plastic-Dipped
D507-12	1-1/2" (38.1 mm)	12.375" (314.3 mm)	Transparent Red	Plastic-Dipped
<b>Standard Capacity — Extra-Wide Jaw</b>				
D509-8	1-1/2" (38.1 mm)	8.5" (215.9 mm)	Blue	Plastic-Dipped
<b>Standard Capacity</b>				
500-18	2-1/16" (52.4 mm)	18.25" (463.6 mm)	Chrome	High-Polish Chrome
500-24	2-1/2" (63.5 mm)	24" (609.6 mm)	Chrome	High-Polish Chrome
506-15	1-11/16" (42.9 mm)	15.875" (403.2 mm)	Chrome	High-Polish Chrome
D506-4	1/2" (12.7 mm)	4.5" (114.3 mm)	Transparent Red	Plastic-Dipped



Blue



Transparent Red



Chrome

## Adjustable Wrenches — Slim Jaw

Includes core adjustable wrench features plus:

- Designed for tight wrench-over-wrench applications
- Jaws meet ASME 107.11-2010 testing standards for adjustable wrenches while being 40% slimmer than most standard adjustable wrench jaws
- Cat. No. D86936 has 1-1/2" (38.1 mm) extra wide jaw capacity that is 5/16" (7.93 mm) larger than other wide-capacity 8" (203.2 mm) wrenches
- Standard and metric size markings for fast adjustment
- Manufactured for strength and durability



40% Slimmer Jaw



D86936

Cat. No.	Jaw Capacity	Overall Length	Handle Color	Handle Finish
D86932	1/2" (12.7 mm)	4.563" (115.9 mm)	Blue	Plastic Dipped
D86934	1" (25.4 mm)	6.406" (162.7 mm)	Blue	Plastic Dipped
D86936	1-1/2" (38.1 mm)	8.375" (212.7 mm)	Blue	Plastic Dipped

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Klein Tools:

[500-18](#) [D507-8](#) [506-15](#) [D507-6](#) [507-6](#) [D507-12](#) [D507-10](#) [D506-4](#) [500-24](#) [507-10](#) [507-8](#) [507-12](#) [D509-8](#)