

HOLE MAKING

Fast, Superior Cutting



**KLEIN
TOOLS®**



For Professionals... Since 1857™

HOLE SAWS

Bi-Metal Hole Saws

Optimized for fast cutting of steel – even stainless!



- **Cuts precise holes** in stainless steel and mild steel, drywall, ceiling tile, laminates, wood and plastic
- **Thick back plates** and walls stand up to heavy use and abuse
- **Long-lasting**, consistent cutting performance

Multiple slots provide different leverage points to easily remove material

Cat. No.	UPC# 0-92644+	Saw Diameter	For use with Arbor No.
31914	31914-3	7/8" (22 mm)	31905
31918	31918-1	1-1/8" (29 mm)	
31922	31922-8	1-3/8" (35 mm)	31905 with adapter or 31906
31928	31928-0	1-3/4" (44 mm)	
31932	31932-7	2" (51 mm)	31906
31940	31940-2	2-1/2" (64 mm)	
31944	31944-0	2-3/4" (70 mm)	
31948	31948-8	3" (76 mm)	
31958	31958-7	3-5/8" (92 mm)	
31972	31972-3	4-1/2" (114 mm)	
31900	31900-6	6-3/8" (162 mm)	
32905	69113-3	3-Piece Kit includes 7/8", 1-1/8" and 1-3/8" (22, 29 and 35 mm) saws, an arbor, spare bit and case.	
Arbors and Replacement Bits			
31905	31905-1	Threaded Arbor with adapter, 3/8" (10 mm)	
31906	31906-8	Threaded Arbor, 3/8" (10 mm) with Pins	
31907	31907-5	Replacement Pilot Bit, 1/4" x 3-1/4"	

STEP BITS

Double-Fluted Step Drill Bits

Faster drilling than single flute bits!

- **Easy-to-read step rings** save time when drilling common holes
- **Fast-starting**, non-walking drill tip
- **Thick, extra-long 3/8"** hex shank provides a firm, positive grip in the drill and won't spin out



Cat. No.	UPC# 0-92644+	Quick Reference	No. of Holes	Increment	Hole Size Range
KTSB01	59101-3	#1	13	1/32"	1/8" – 1/2" (3 mm – 13 mm)
KTSB03	59103-7	#3	9	1/16"	1/4" – 3/4" (6 mm – 19 mm)
KTSB11	59111-2	#11	2	–	7/8" – 1-1/8" (22 mm – 29 mm)
KTSB14	59114-3	#14	12	1/16"	3/16" – 7/8" (5 mm – 22 mm)
KTSB15	59115-0	#15	3	–	7/8", 1-1/8", 1-3/8" (22, 29, 35 mm)

SAW BLADES


Reciprocating Saw Blades

Smooth, accurate cutting in a long-lasting blade!

- **Bi-metal construction** gives heat and wear resistance for a long cutting life
- **1/2" (13 mm) universal tang** to fit all popular reciprocating saw tools
- **Fast and smooth** cutting action

SKU	UPC 0-92644+	Blade Length	TPI	Blade Width	Blade Thickness
Blades for cutting wood, wood composites, and nail embedded wood*					
31751	69103-4	9" (229 mm)	6	3/4" (20 mm)	.05" (1.3 mm)
31761	69107-2	12" (305 mm)	6	3/4" (20 mm)	.05" (1.3 mm)
31716	64044-5	6" (152.4 mm)	6	3/4" (19.1 mm)	0.050" (1.27 mm)
Blades for cutting various materials ranging from wood, plastic, ferrous and non-ferrous metals					
31731	69111-9	6" (152 mm)	10/14	3/4" (20 mm)	.05" (1.3 mm)
31741	69108-9	8" (203 mm)	10/14	3/4" (20 mm)	.05" (1.3 mm)
Blades for cutting any machinable metal up to 1/4" (6.4 mm) thick					
31727	69104-1	6" (152 mm)	14	3/4" (20 mm)	.035" (.9 mm)
31739	69106-5	8" (203 mm)	18	3/4" (20 mm)	.035" (.9 mm)
31728	64009-4	6" (152.4 mm)	18	3/4" (19.1 mm)	0.035" (0.89 mm)
31734	64047-6	6" (152.4 mm)	24	3/4" (19.1 mm)	0.035" (0.89 mm)
Heavy-duty blade for cutting machinable metal, wood, wood composite, plastic, or rubber					
31755	69109-6	9" (229 mm)	14	1" (25 mm)	.042" (1 mm)

* Cutting through nail embedded wood may prematurely wear blade.

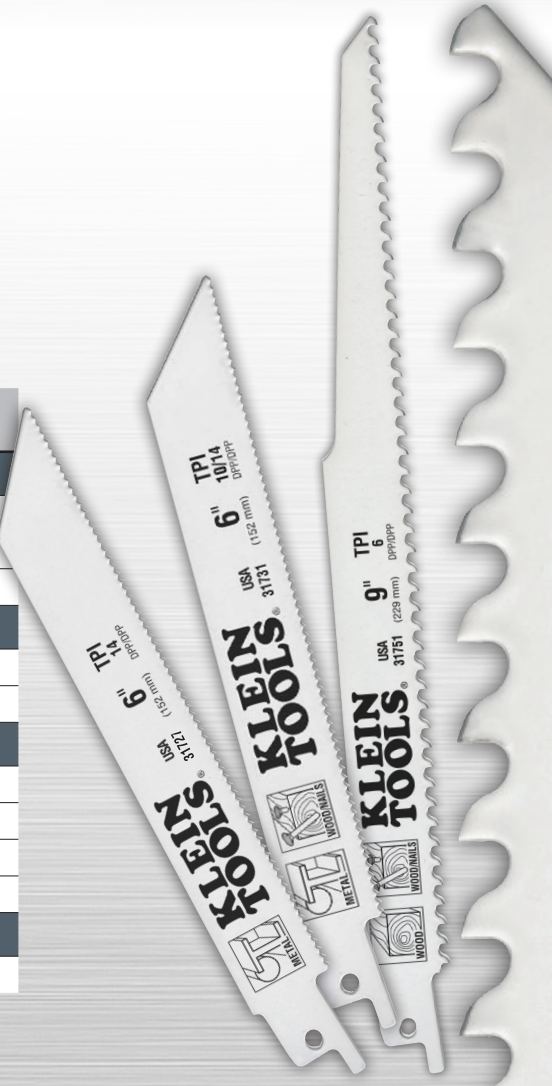

HOLEMAKING

Klein also makes durable, long-lasting products for cutting holes in heavy-gauge steel panels and cutting holes in wood for cabling applications!

Carbide Hole Cutters

Cat. No.	UPC 0-92644+	Description
31850	31850-4	3/4" (19 mm) Carbide Hole Cutter
31852	31852-8	7/8" (22 mm) Carbide Hole Cutter
31856	31856-6	1-1/8" (29 mm) Carbide Hole Cutter
31860	31860-3	1-3/8" (35 mm) Carbide Hole Cutter
31866	31866-5	1-3/4" (44 mm) Carbide Hole Cutter
31868	31868-9	2" (51 mm) Carbide Hole Cutter
31870	31870-2	2-1/2" (64 mm) Carbide Hole Cutter
31874	31874-0	Replacement Pilot Bit
31872	31872-6	4-Piece Carbide Hole Cutter Set
31873	31873-3	8-Piece Master Electrician's Hole Cutter Kit



Knockout Punches

Cat. No.	UPC 0-92644+	Description
53727SEN	53745-5	Knockout Punch Set, 3/4" (19 mm)
53728SEN	53746-2	Knockout Punch Set, 1/2" (12.5 mm)
53732SEN	53750-9	Knockout Punch Set with Wrench




Ship-Auger Bits

Cat. No.	UPC 0-92644+	Description
6" (152 mm) Bits		
53402	53402-7	3/4" (19 mm) Ship-Auger Bits
53404	53404-1	7/8" (22 mm) Ship-Auger Bits
53406	53406-5	1" (25 mm) Ship-Auger Bits
53408	53408-9	1-1/8" (29 mm) Ship-Auger Bits
18" (457 mm) Bits		
53437	53437-9	3/4" (19 mm) Ship-Auger Bits
53439	53439-3	7/8" (22 mm) Ship-Auger Bits
53441	53441-6	1" (25 mm) Ship-Auger Bits
53443	53443-0	1-1/8" (29 mm) Ship-Auger Bits



Flex Drill Bits

Cat. No.	UPC 0-92644+	Description
53716	53716-5	3/8" x 54" (9.5 mm x 1372 mm)
53717	53717-2	3/8" x 72" (9.5 mm x 1829 mm)
53718	53718-9	9/16" x 54" (14 mm x 1372 mm)
53719	53719-6	3/4" x 54" (19 mm x 1372 mm)
53751	53751-6	3/4" x 72" (19 mm x 1829 mm)
53720	53720-2	1" x 54" (25 mm x 1829 mm)

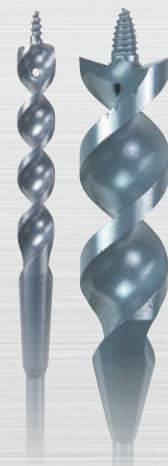

Flex Bit Kit

Cat. No.	UPC 0-92644+	Description
53721	53721-9	Flex Bit Kit



NOTE: Read and follow safety instructions in power tool owner's manual.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Klein Tools:

[31739](#) [31755](#) [31751](#) [31727](#) [31741](#) [32905](#) [31761](#) [31731](#)