




Lineman's Crimping Pliers, 9-Inch

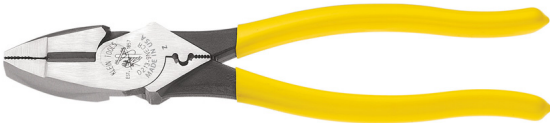

The Lineman's Crimping Pliers feature a crimping die behind the hinge. This provides superior leverage when crimping non-insulated connectors, lugs, and terminals. The rivet on these pliers are closer to the cutting edge which provides 46-Percent more cutting and gripping power than other pliers. Induction hardened cutting knives are extra durable for longer life.

Specifications

Type:	High Leverage Side Cutting/Connector Crimping Pliers	Application:	#8 AWG Copper, Aluminum and Other Soft Metals and Crimps Non-insulated Connectors, Lugs, and Terminals
Special Features:	Crimper	Overall Length:	9.35" (23.7 cm)
Overall Width:	2.06" (5.2 cm)	Material:	Induction Hardened Steel
Nose Type:	New England	Jaw Length:	1.91" (4.9 cm)
Jaw Width:	1.25" (3.2 cm)	Jaw Thickness:	0.62" (1.6 cm)
Jaw Capacity:	1.375" (3.5 cm)	Cutting Knives:	1
Knife Length:	0.781" (2 cm)	Cut Style:	Side-Cutting
Screw Shearing:	No	Joint Type:	Hot-Riveted
Handle Color:	Yellow	Handle Finish:	Plastic-Dipped
Handle Length:	5.41" (13.7 cm)	Insulated:	No
Tether Capable:	No	Weight:	1.0 lb (0.5 kg)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Klein Tools:](#)

[D213-9NE-CR](#)