




High-Leverage Ironworker's Pliers

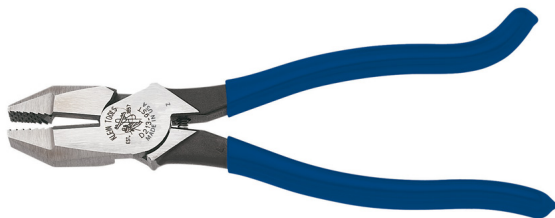

These Klein Tools High-Leverage Ironworker's Pliers have induction hardened side-cutting knives for improved durability and a longer lifespan. They have heavy duty knurled jaws and a spring-loaded self-opening on hot-riveted joint for smooth, easy, and powerful action. The high-leverage design with handform handles and the rivet being closer to the cutting edge allows for 46 percent more cutting and gripping power.

Specifications

Type:	Ironworker's Pliers	Application:	Used for Rebar, High Leverage
Special Features:	Spring Loaded	Overall Length:	9.35" (23.7 cm)
Overall Width:	2.06" (5.2 cm)	Material:	Induction Hardened Steel
Nose Type:	Square	Jaw Length:	1.91" (4.9 cm)
Jaw Width:	1.24" (3.1 cm)	Jaw Thickness:	0.62" (1.6 cm)
Jaw Capacity:	1.375" (3.5 cm)	Cutting Knives:	1
Knife Length:	0.781" (2 cm)	Cut Style:	Side-Cutting
Screw Shearing:	No	Joint Type:	Hot-Riveted
Handle Color:	Blue	Handle Finish:	Plastic-Dipped
Handle Length:	5.41" (13.7 cm)	Insulated:	No
Tether Capable:	No	Weight:	1.0 lb (0.5 kg)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Klein Tools:](#)

[D213-9ST](#)