




Lineman's Pliers Bolt Thread-Holding, 9-Inch

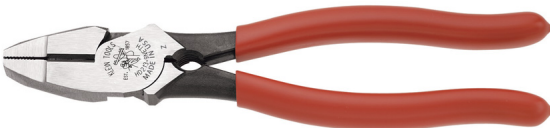

The hinge opening on these Lineman's Pliers holds and cleans 5/8-Inch (16 mm) pole line and hardware bolts or threaded rods. Thicker, dipped handles are more comfortable and easier to grab with gloved hands. They are forged, precision machined, hardened, and carefully tempered for maximum strength. Klein pliers provide exceptional performance and durability.

Specifications

Type:	Side Cutting Pliers	Application:	Core High Leverage Side Cutting Features Plus: 5/8" (15.9 mm) Pole Line and Hardware Bolts, Threaded Rods
Special Features:	Oversized	Overall Length:	9.35" (23.7 cm)
Overall Width:	2.06" (5.2 cm)	Material:	Induction Hardened Steel
Nose Type:	New England	Jaw Length:	1.91" (4.9 cm)
Jaw Width:	1.25" (3.2 cm)	Jaw Thickness:	0.62" (1.6 cm)
Jaw Capacity:	1.375" (3.5 cm)	Cutting Knives:	1
Knife Length:	0.781" (2 cm)	Cut Style:	Side-Cutting
Joint Type:	Hot-Riveted	Handle Color:	Light Red
Handle Finish:	Heavy Plastic-Dipped	Handle Length:	5.41" (13.7 cm)
Insulated:	No	Tether Capable:	Yes
Weight:	1.2 lb (0.5 kg)		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Klein Tools:](#)

[HD213-9NETH](#)