




DESIGNER'S KIT K1-RCAT+

Fixed Attenuators

50Ω DC to 20 GHz

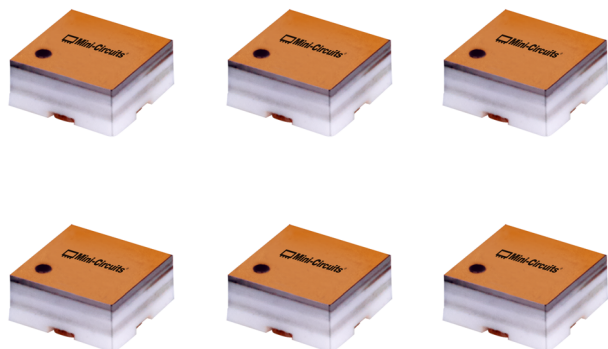

FEATURES

- Hi Rel, Hermetic Ceramic Case
- Ultra Wideband, 50Ω
- 0, 3, 6, 10, 15, 20 dB attenuation
- Input power 2 W max.
- Low profile 1.1mm
- Thermally optimized design

MINI-CIRCUITS DESIGNER'S KITS
SPEED UP
THE SOLUTION



K1-RCAT+ ELECTRICAL SPECIFICATIONS

(6 models, 10 of each, 6 total)

Model	Frequency (GHz) f_L - f_U	Attenuation (dB) Typ.			Return Loss (dB) Typ.			Input Power ¹ (W) Max.
		1 GHz	10 GHz	20 GHz	1 GHz	10 GHz	20 GHz	
RCAT-00+	DC- 20	0.0	0.2	0.5	30	19	12	2.0
RCAT-03+	DC- 20	3.0	3.4	3.9	31	20	14	2.0
RCAT-06+	DC- 20	6.1	6.5	7.5	30	21	15	2.0
RCAT-10+	DC- 20	10.1	10.7	12.3	30	20	15	2.0
RCAT-15+	DC- 20	15.1	16.0	19.0	30	20	15	1.6
RCAT-20+	DC- 20	20.1	21.4	27.0	30	21	14	1.5

1. RF power at 25°C case temperature. Derate linearly to 0.33 W at 125°C.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mini-Circuits:](#)

[K1-RCAT+](#) [RCAT-10+](#)