




Mini-Circuits®

DESIGNER'S KIT KHFC3-141+

Coaxial Cables

HAND
FLEX™

DC to 18 GHz, SMA-Male Connectors

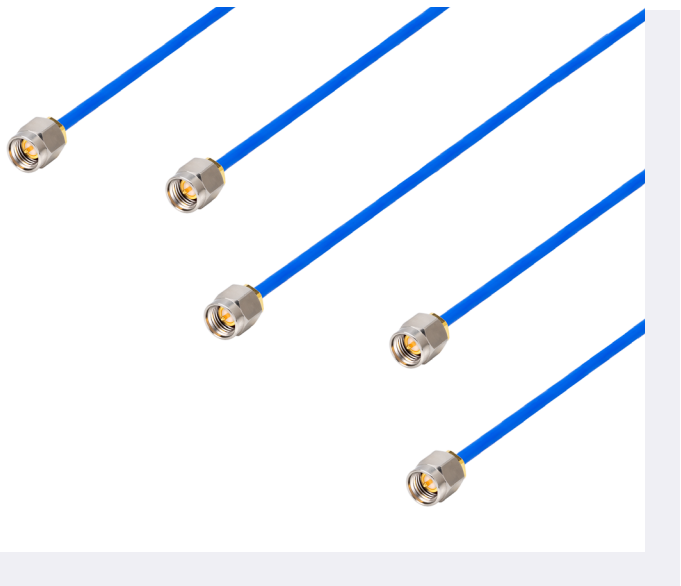

FEATURES

- Hand Formable
- Choice of cable lengths
- Robust
- Tight Bend Radius, 8mm Radius Min.
- Excellent Return Loss
- Excellent Insertion Loss
- Very Low Cost

MINI-CIRCUITS DESIGNER'S KITS
SPEED UP
THE SOLUTION

KHFC3-141+ ELECTRICAL SPECIFICATIONS

(kit includes 5 of each model, total 25 pieces)

Model No. ¹	Freq. (GHz) f_L - f_U	Length ² (Inches)	Insertion loss (dB)				Return Loss (dB)			
			DC - 2 GHz Typ.	2 - 6 GHz Typ.	6 - 10 GHz Typ.	10 - 18 GHz Typ.	DC - 2 GHz Typ.	2 - 6 GHz Typ.	6 - 10 GHz Typ.	10 - 18 GHz Typ.
141-3SM+	DC-18	3	0.07	0.08	0.23	0.21	56	41	36	37
141-6SM+	DC-18	6	0.04	0.16	0.25	0.39	50	44	39	34
141-12SM+	DC-18	12	0.13	0.27	0.46	0.66	48	43	38	31
141-18SM+	DC-18	18	0.17	0.36	0.62	0.89	45	38	37	31
141-24SM+	DC-18	24	0.21	0.45	0.77	1.12	47	43	37	33

1. Unjacketed cable also available upon request.

2. Custom sizes available upon request.

www.minicircuits.com P.O. Box 350166, Brooklyn, NY 11235-0003 (718) 934-4500 sales@minicircuits.com

REV. A
ECO-009165
KHFC3-141+
MCL NY
210810

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mini-Circuits:](#)

[KHFC3-141+](#)