


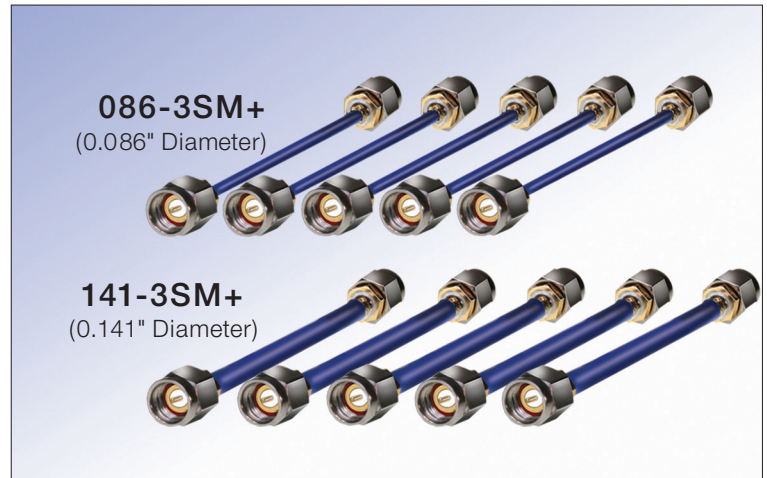

Features

- Hand Formable
- Robust
- Tight Bend Radius
 - 086-3SM+ 30 mm radius Min.
 - 141-3SM+ 40 mm radius Min.
- Excellent Return Loss
- Excellent Insertion Loss
- Very Low Cost

DC to 18 GHz

Typical Bending Capability



Kit KHFC-1+ Electrical specifications of each model (Kit includes 5 of each model, total 10 pieces)

Model ¹ No.	Freq. (GHz)	Length ² (inch)	Insertion Loss (dB)								Return Loss (dB)							
			DC-2 GHz		2-6 GHz		6-10 GHz		10-18 GHz		DC-2 GHz		2-6 GHz		6-10 GHz		10-18 GHz	
			Typ.	Max.	Typ.	Max.	Typ.	Max.	Typ.	Max.	Typ.	Min.	Typ.	Min.	Typ.	Min.	Typ.	Min.
086-3SM+	DC-18	3	0.04	0.22	0.14	0.40	0.20	0.52	0.31	0.71	49	23	37	23	33	17	27	16
141-3SM+	DC-18	3	0.07	0.15	0.08	0.27	0.23	0.36	0.21	0.49	56	23	41	23	38	17	37	17

1. Unjacketed cable also available upon request.
2. Custom sizes available, consult factory.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mini-Circuits:](#)

[KHFC-1+](#)