

Electromechanical Hours Meter Type E2HM35

CARLO GAVAZZI



E2HM35

- 6 digits hour meter
- High shock resistance
- Low power consumption
- Water proof IP65
- Magnified figures

Product Description

This hour meter is particularly designed to fit applications on moving devices and harsh environments such as: utility vehicles, construction machines, generators, fork lift trucks, car washes, etc...

Ordering Key

E2HM35 2 302

Type

Mounting type

Voltages

Stock items: E2HM352301
E2HM352302
E2HM352373

Approvals



Voltage Code

373	10÷80VDC
301	115VAC
302	230VAC

Measuring Specifications

Time range	999 99.9h
ON time	100%
Counting system	Adding
Reset	No
Accuracy	<0.02% over full range



Dimensions mm/inches

Mounting Type

1	Fig. 1
2	Fig. 2

General data

Dimensions of digits	3.5mm/0.138"
Colour of digit figures	White on Black
Power consumption	
AC	0.4VA max.
DC 12V	0.08W max.
DC 24V	0.7W max.
Rated voltages	115/230VAC ±10% 50/60Hz 10...80VDC
Operating temperature	-30...+65°C/-22°F...149°F
Mounting position	Any
Housing	Plastic
Weight	55g/1.94oz
Degree of protection	IP65

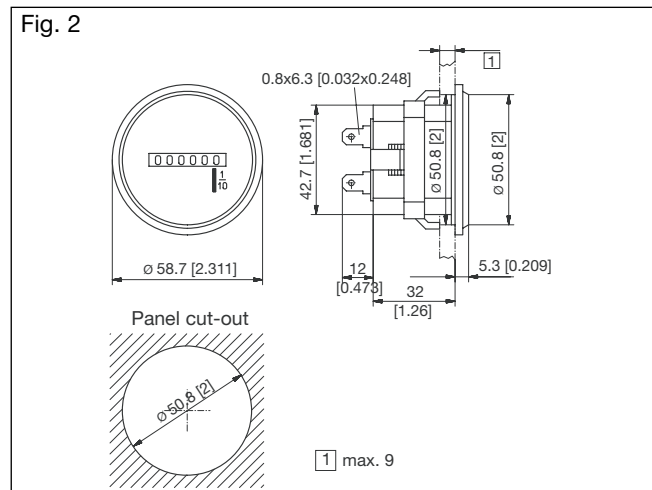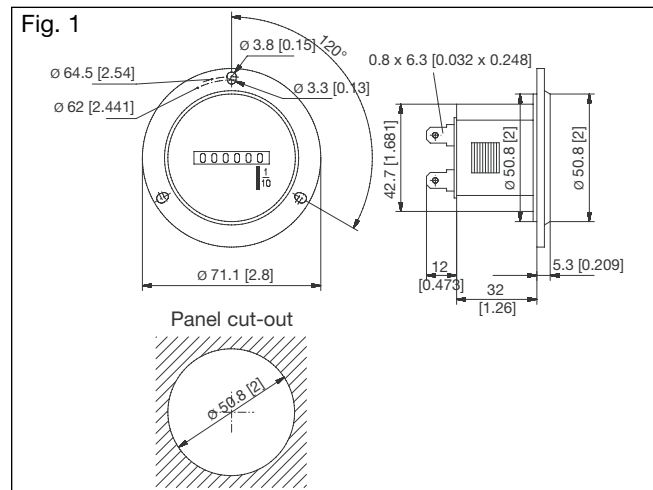

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Carlo Gavazzi:](#)

[E2HM352301](#) [E2HM352373](#) [E2HM352302](#)