

MMS Enclosure

■ Service condition

Case cover of MMS enclosure is specifically designed with dust-proof and corrosive-proof structure.

Therefore, it is the optimum product to use in dusty areas such as cement plants, cotton mills as well as in the presence of corrosive gas or liquid (excl. explosive, flammable gas) such as fertilizer, refinery, and plating plant


- Application Model: GMS-32H/HL
- Available range -20°C ~ + 60°C
- Compact and Simple design
- CE certification and UL listing
- Material of Case Cover: Plastic




Ratings

Name	GEP32A65S
Type	Molded-Plastic enclosure with rotary operating mechanism
Degree of protection	IP 65
Locking device	none
Motor starter size	GMS-32H
Mounting	Surface
Material of insulation	ABS

Assembly Method

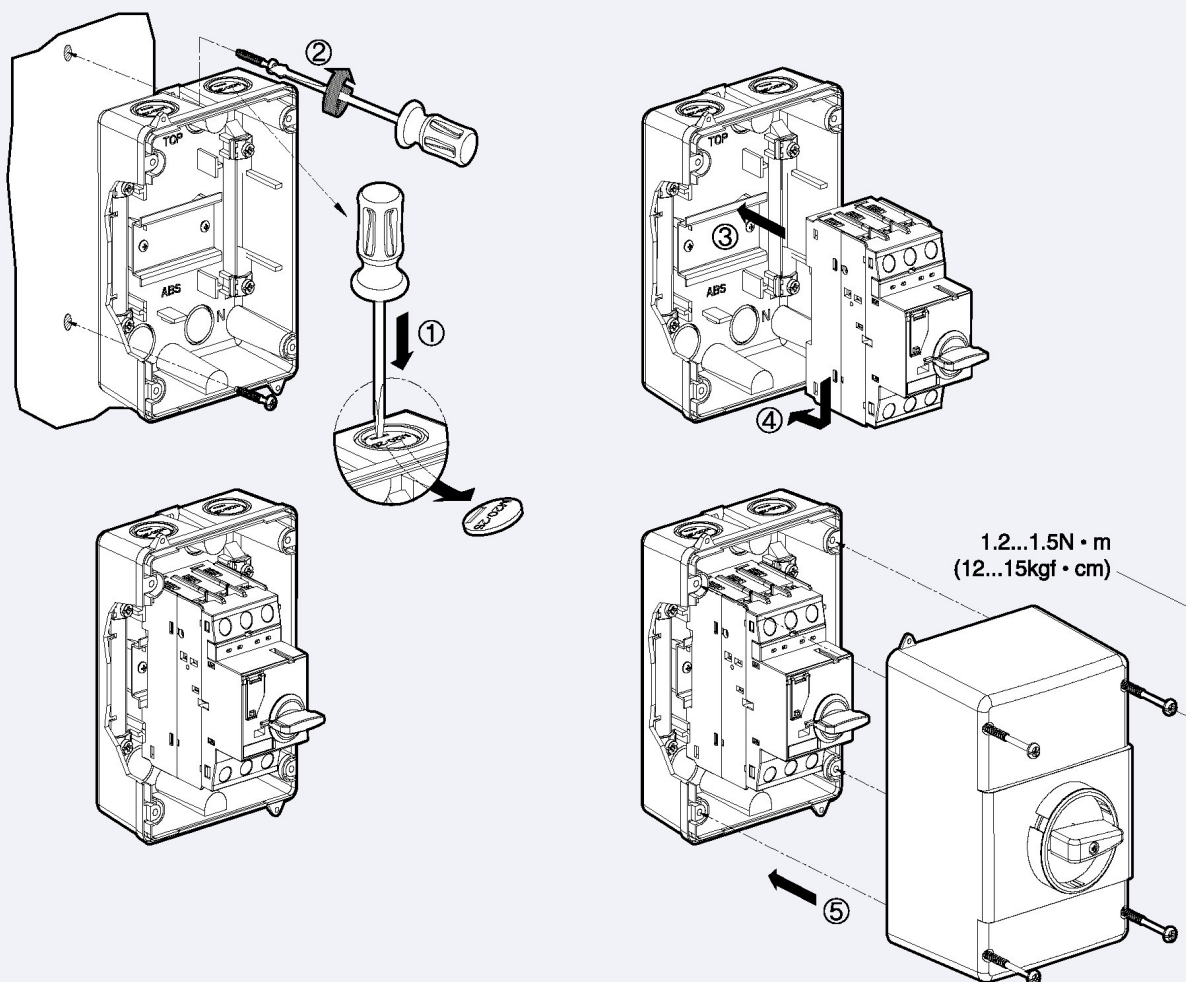

Dimension

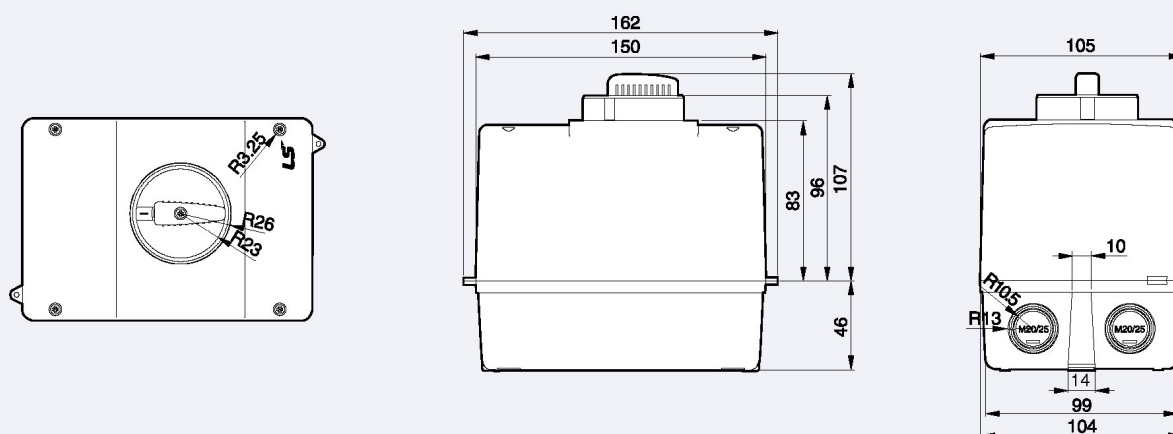

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Carlo Gavazzi:](#)

[GEP32A65S](#)