
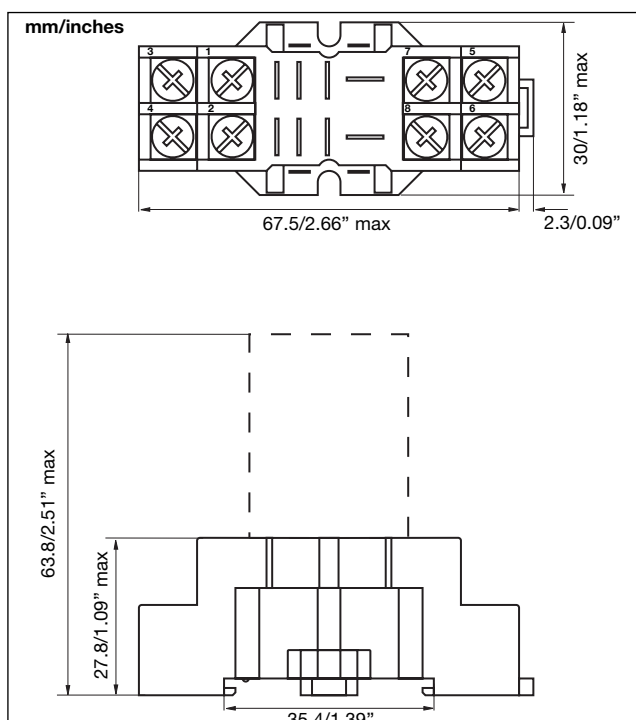


Sockets for RPY Relays


ZPY8A

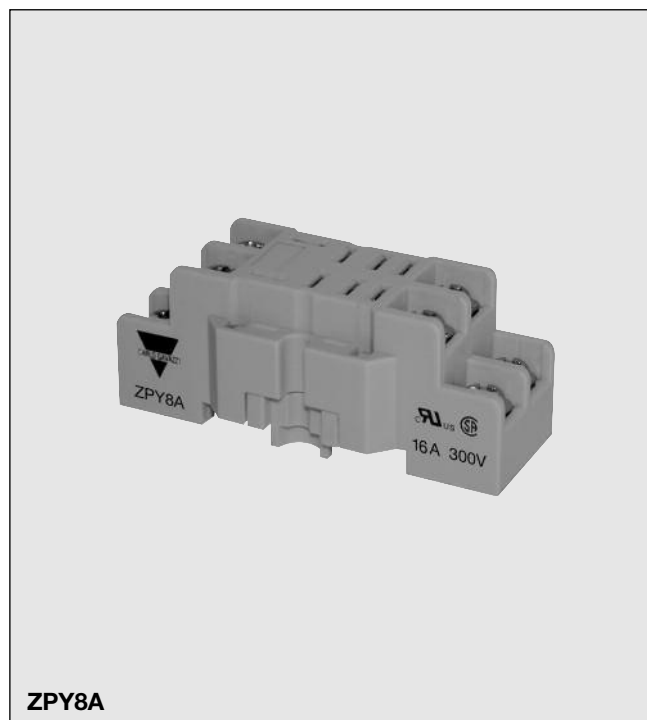


General data

Rated voltage	300VAC
Rated current	16A
Insulation voltage	>2kV
Socket material	PA66 + GF (V0)
Socket colour	RAL 7035 / Pantone 1C
Contact material	Nickel Plated - Cu Zn 33
Terminal type	Screw cage
Screw type	M3 with combi head (slotted, Philips Gr.1, Pozzi)
Max. screw torque	1.0N/m
Max wire section	0.5-2.5mm ² (20AWG 14AWG)
Operating temperature	-25° to +85°C (-13° to +185°F)
UL rating	10A 300VAC
UL temperature	0° to +60°C (+32° to +140°F)

Drilling pattern

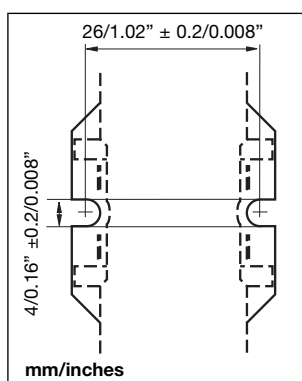

Wiring diagram

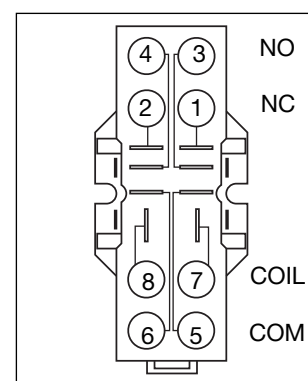

Approvals




Box content: 10 sockets
 Box size: (W 71 x D 57 x H 150) mm Weight: 480g
 (W 2.80 x D 2.25 x H 5.90) inches Weight: 16.93oz

Optional Accessories (to be ordered separately if required)

Hold-down spring steel SZPY 35M (see on page 101)

Optional Springs for ZPY series

SZPY 35M

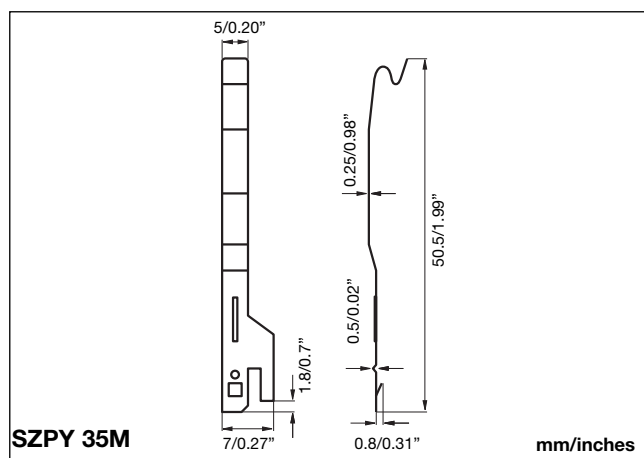

General data

Spring material

Stainless steel

Packaging

Box content: 1 plastic bag, 10pcs.

Weight: ~10g (0.36oz)

Note:

For each relay/socket are required at least 2 springs.

Up to 4 springs can be mounted.

RoHS
COMPLIANT

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Carlo Gavazzi:](#)

[ZPY08A](#) [SZPY35M](#) [T200000040](#) [T200000020](#) [T-GON810-A1-RZ](#)