




FCI 3-Way APEX 2.8 mm Connection System


FEMALE

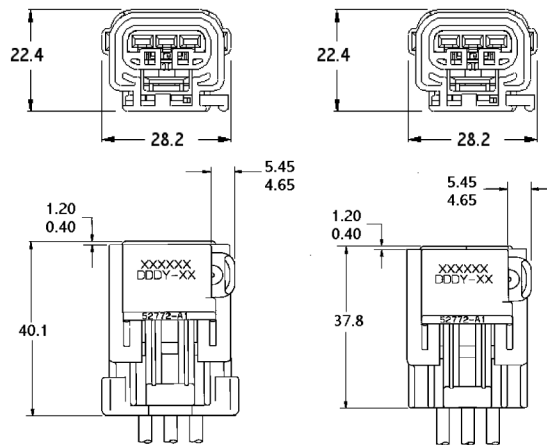

Sealed Assembly

Unsealed Assembly

MALE

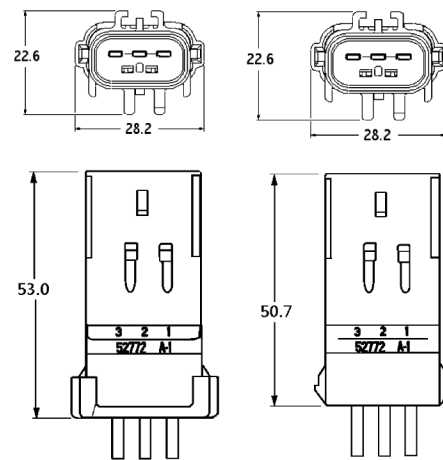

Sealed Assembly

Unsealed Assembly

INDEX TYPE	HOUSING COLOR	SEALED/ UNSEALED	FEMALE ASSEMBLY PART NUMBER	MALE ASSEMBLY PART NUMBER	TEMPERATURE RATING OF MATERIAL	WIRE INSULATION RANGE PER CAVITY (mm)
A	DK GRN	SEALED	54200346	54200354	-40°C to +150°C	1.70 – 2.77
A	BLK	SEALED	54200308	54200312	-40°C to +125°C	1.70 – 2.77
A	BLK	UNSEALED	54200300	54200304	-40°C to +125°C	1.50 – 4.09
B	LT GREY	SEALED	54200309	54200313	-40°C to +125°C	1.70 – 2.77
B	LT GREY	UNSEALED	54200301	54200305	-40°C to +125°C	1.50 – 4.09
C	DK GREY	SEALED	54200310	54200314	-40°C to +125°C	1.70 – 2.77
D	NATURAL	SEALED	54200311	54200315	-40°C to +125°C	1.70 – 2.77
D	NATURAL	UNSEALED	54200303	54200307	-40°C to +125°C	1.50 – 4.09
C	DK GREY	UNSEALED	54200302	54200306	-40°C to +125°C	1.50 – 4.09
A	BLACK	SEALED	54200335N*	—	SEAL W/O HOLES	USED AS CAP
A	BLACK	SEALED	—	54200337*	SEAL W/O HOLES	USED AS CAP

* Plug for same index (A) mating part.

Note: Female part numbers with the N suffix are without CPA latch.

3.35mm wire diameter sealing is available in select configurations. Consult sales drawing.

Additional configurations available. Please consult sales drawing.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aptiv:](#)

[54200308](#) [54200309](#) [54200312](#) [54200308N](#) [54200308N-B](#) [54200309-B](#) [54200312-B](#) [54200313](#) [54200313-B](#)
[54200335N-B](#) [54200308-B](#) [54200303-B](#) [54200307-B](#) [54200346-B](#) [54200310N](#)