

# SICMA SensoMate™ SERIES



SICMA SensoMate™ 6W  
Female & Male

## BENEFITS

- High performance connector featuring T4 / V3 performance
- Back shell covers available

## FEATURES

- Suitable for harsh environment
- CPA is pre-mounted
- Compatible with Mini-Sealed family



## AVAILABLE CONFIGURATIONS

Cavity Count (ways)	4, 5, 6
Cavity Configurations (mm)	1.5
Material	PBT
Genders	Female, Male
Sealing Type	Mat Sealed




## APPLICATIONS


Sensors and actuators on engine mount  
Air filter and pressure devices



## TEMPERATURE

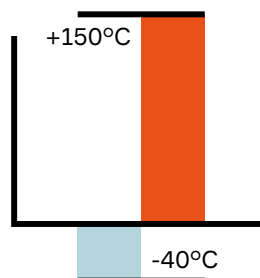

## VIBRATION

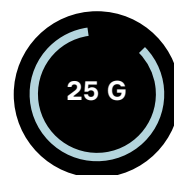

## CONNECTOR MATING FORCE



## SEALING PROTECTION



See back page for representative part numbers and packaging dimensions.

## About Aptiv

Aptiv is a global technology company that develops safer, greener and more connected solutions enabling the future of mobility. Headquartered in Dublin, Aptiv has approximately 150,000 employees and operates 14 technical centers, as well as manufacturing sites and customer support centers in 45 countries.

Visit [aptiv.com](http://aptiv.com)




• **APTIV** •

Cavity count	Blade size (mm)	Gender	Dimensions L x W x H (mm)	Part number	Color	Indexes offered
4	1.5	F	24.50 x 20.30 x 36.55	13876521	Black	5
		M	24.50 x 15.30 x 58.05	33502133		
5	1.5	F	27.80 x 20.30 x 36.55	13893671	Black	5
		M	27.80 x 15.30 x 58.05	13855072		
6	1.5	F	35.01 x 21.10 x 32.80	13885362	Yellow	5
		M	35.01 x 16.10 x 58.05	13967810		



## DIMENSION MEASUREMENT SAMPLE

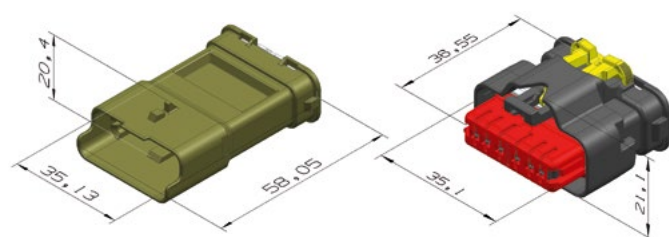


33511739

33511993



## EXPLODED VIEW

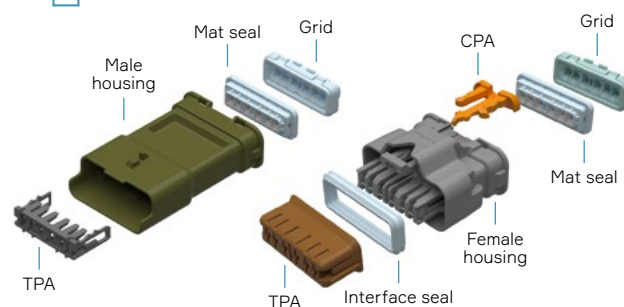

33511739

33511993



## COMPATIBLE WITH



Part numbers, specifications, dimensions and performance data in this document are for general references only and are subject to change without notice. To verify product information, please contact an Aptiv representative.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aptiv:](#)

[33511738](#) [33502175](#) [33511734](#) [33502275](#) [33502277](#) [33511732](#) [33511729](#) [33511735](#) [33511736](#)