


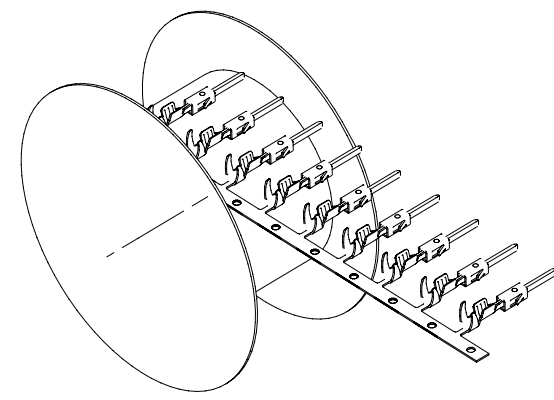


UNWIND DIRECTION  
SPULRICHTUNG

| CROSS<br>SECTION<br>QUERSCH.<br>MM² | CABLE<br>LEITUNG<br>Ø | SEAL<br>DICHTUNG<br>CAVITY Ø 3.60 | SEAL<br>DICHTUNG<br>CAVITY Ø 4.00 |
|-------------------------------------|-----------------------|-----------------------------------|-----------------------------------|
| 0.35                                | 1.20 - 1.40           | 15327913                          | 15344938                          |
| 0.50                                | 1.40 - 1.60           | 15327913                          | 15344938                          |
| 0.75                                | 1.70 - 1.90           | 15327918                          | 15339560                          |
| 1.00                                | 1.90 - 2.10           | 15339412                          | 15339560                          |
| 1.50                                | 2.20 - 2.40           |                                   | 10720807                          |

| X <sub>2</sub><br>±0.1 | L <sub>4</sub><br>±0.2 | L <sub>1</sub><br>±0.1 | L <sub>2</sub><br>±0.1 | L <sub>1</sub><br>±0.1 | H <sub>2</sub><br>±0.2 | H <sub>3</sub><br>±0.2 | H <sub>4</sub><br>±0.2 | H <sub>1</sub><br>±0.2 | B <sub>2</sub><br>±0.2 | B <sub>3</sub><br>±0.2 | B <sub>4</sub><br>±0.2 | B <sub>1</sub><br>±0.2 | CROSS<br>SECTION<br>QUERSCH.<br>MM² | VERSION  |
|------------------------|------------------------|------------------------|------------------------|------------------------|------------------------|------------------------|------------------------|------------------------|------------------------|------------------------|------------------------|------------------------|-------------------------------------|----------|
| 0.20                   | 22.40                  | 6.25                   | 1.50                   | 3.25                   | 1.75                   | 1.50                   | 1.60                   |                        | 1.80                   | 1.50                   | 1.60                   |                        | 0.08-0.18                           | UNSEALED |
| 0.20                   | 22.75                  | 6.35                   | 2.00                   | 2.50                   | 2.55                   |                        |                        | 1.70                   | 2.30                   |                        |                        | 1.80                   | 0.22-0.35                           |          |
| 0.20                   | 22.75                  | 6.60                   | 2.20                   | 3.00                   | 3.40                   |                        |                        | 2.55                   | 3.10                   |                        |                        | 2.40                   | 0.50-0.75                           |          |
| 0.20                   | 22.75                  | 6.60                   | 2.20                   | 3.00                   | 4.00                   |                        |                        | 3.35                   | 3.75                   |                        |                        | 3.10                   | 1.00-1.50                           |          |
| 0.20                   | 22.75                  | 6.60                   | 1.60                   | 3.00                   | 3.70                   |                        |                        | 2.55                   | 3.45                   |                        |                        | 2.15                   | 0.08-0.18                           | SEALED   |
| 0.80                   | 22.75                  | 6.60                   | 1.95                   | 3.25                   | 4.80                   | 1.50                   | 1.60                   | 5.45                   | 1.50                   | 1.60                   |                        |                        | 0.08-0.18                           |          |
| 0.80                   | 22.75                  | 6.10                   | 2.10                   | 2.60                   | 4.70                   |                        |                        | 1.75                   | 5.45                   |                        |                        | 1.80                   | 0.22-0.35                           |          |
| 0.80                   | 22.75                  | 6.60                   | 2.10                   | 3.00                   | 4.70                   |                        |                        | 2.55                   | 5.45                   |                        |                        | 2.40                   | 0.50-0.75                           |          |
| 0.80                   | 22.75                  | 6.50                   | 2.10                   | 3.00                   | 4.70                   |                        |                        | 3.30                   | 5.45                   |                        |                        | 3.10                   | 1.00-1.50                           |          |

WIRE-SECTION RANGE/ DRAHT-BEREICH 0.08 - 0.18 MM²

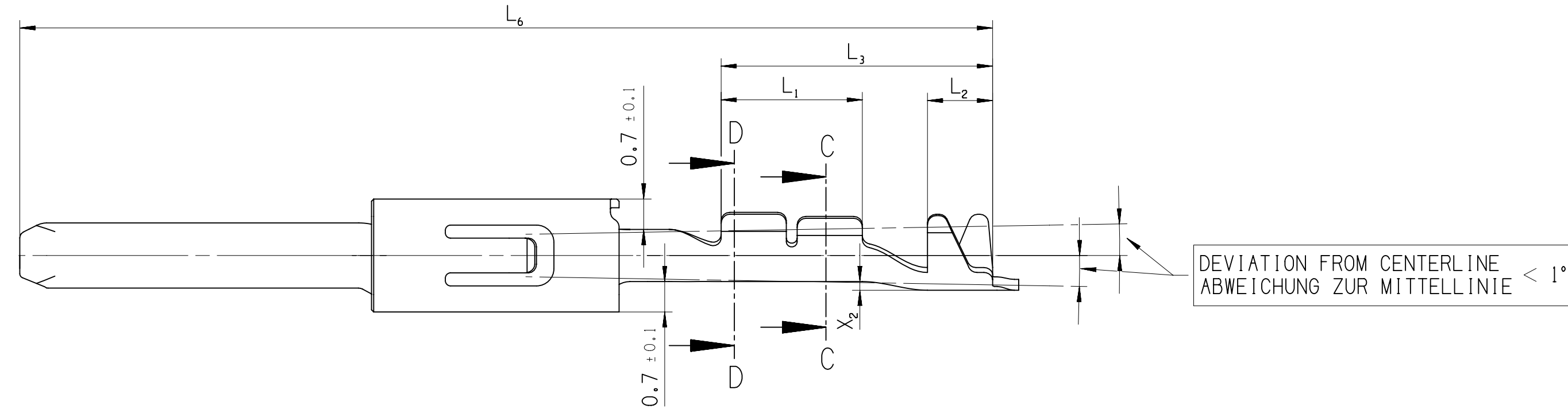



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aptiv:](#)  
[15396713](#)