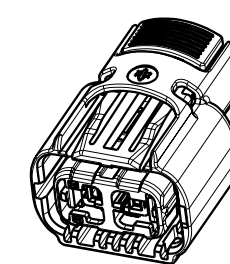
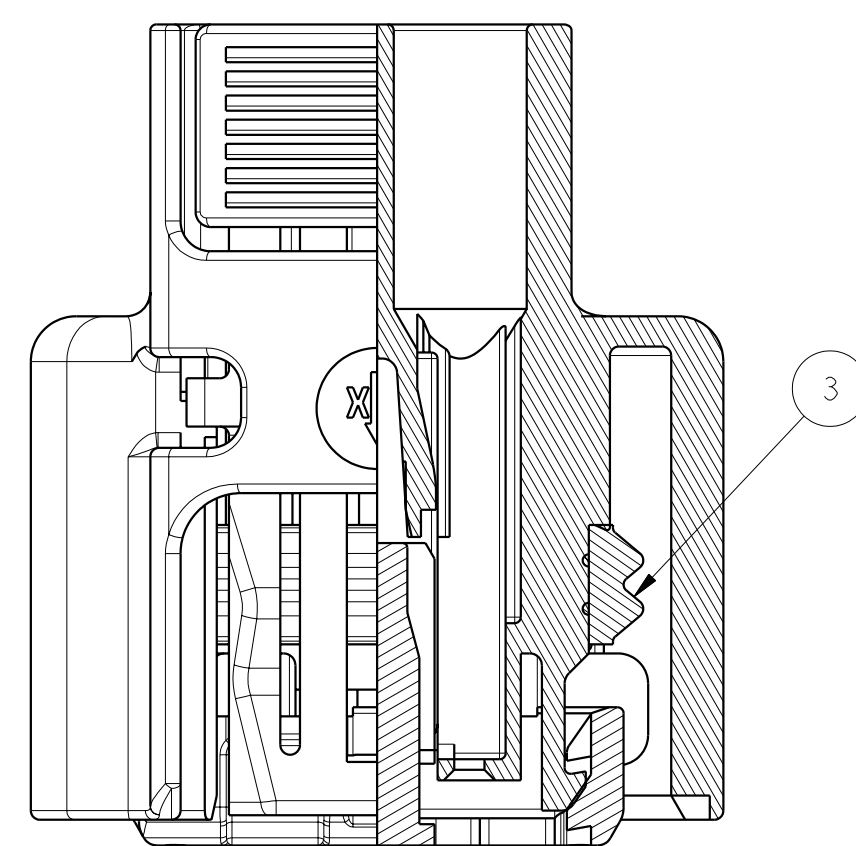
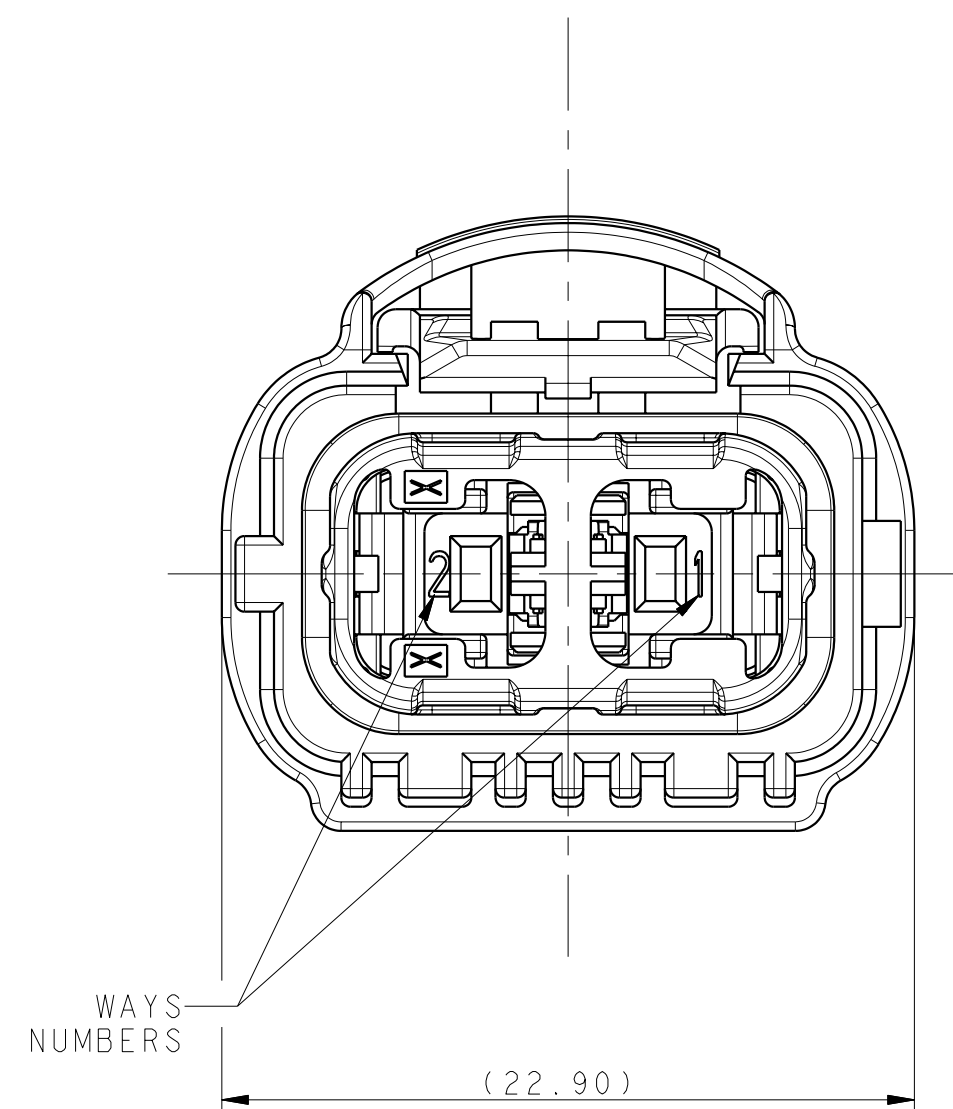
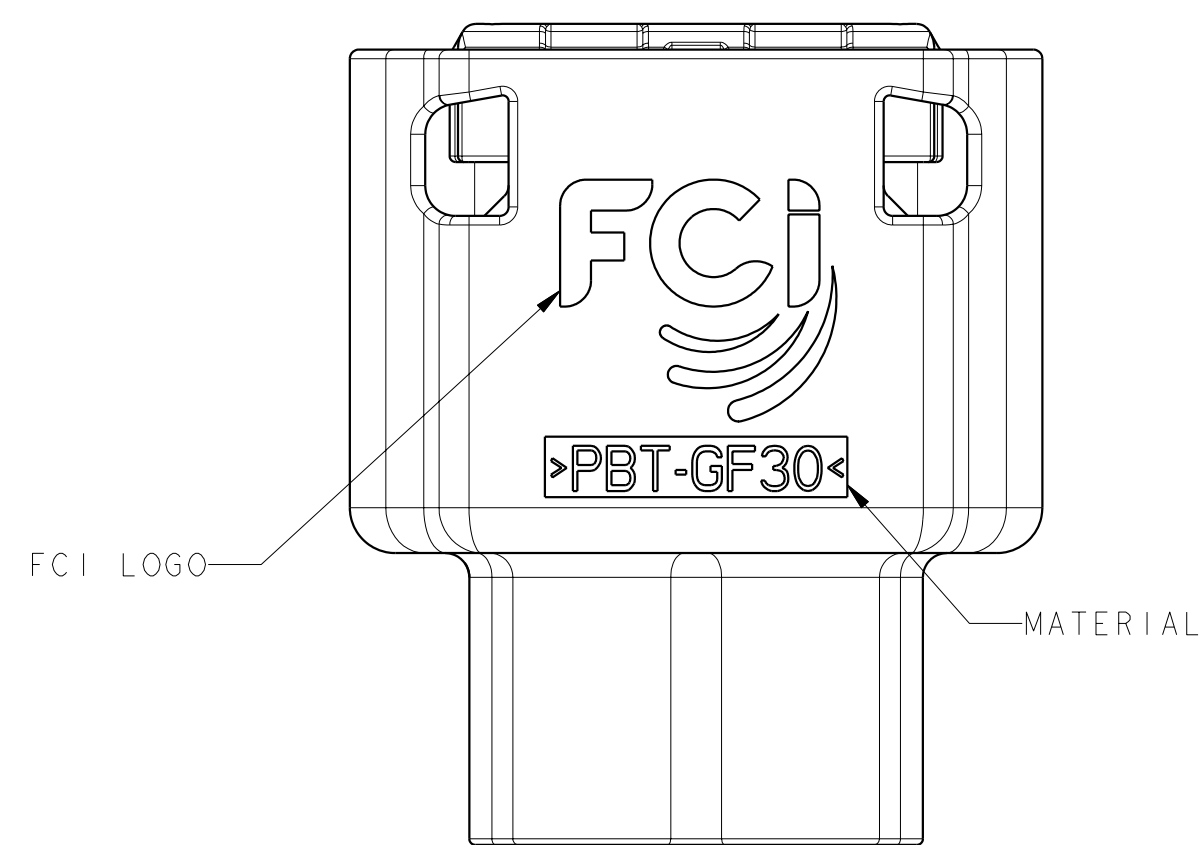
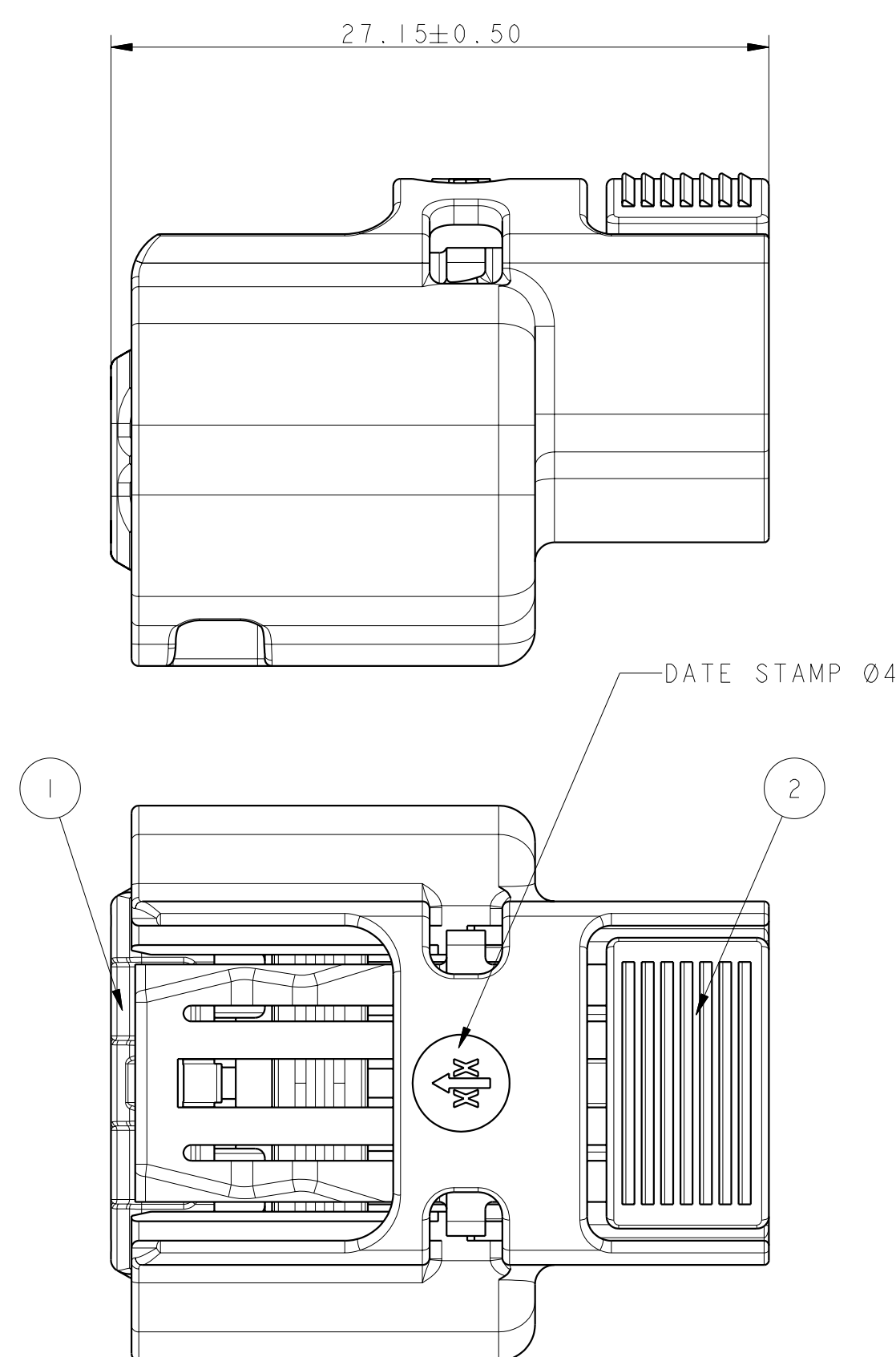
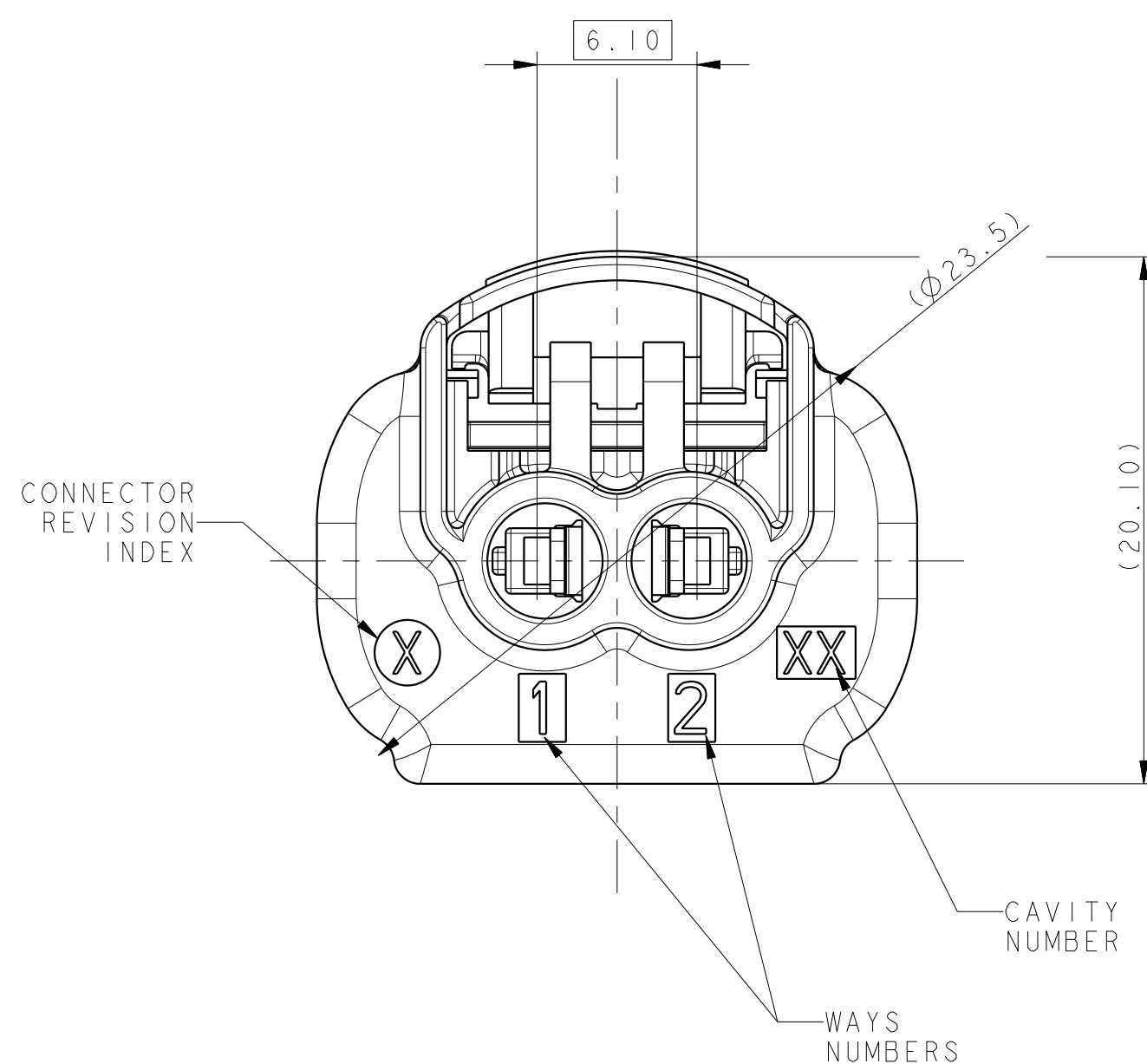


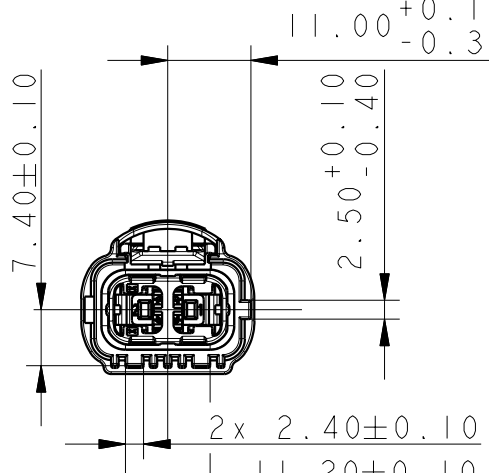
 
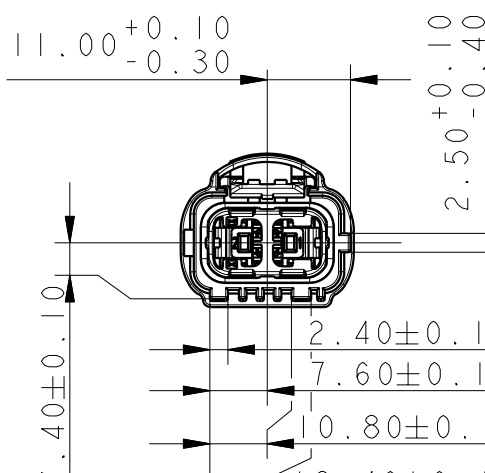
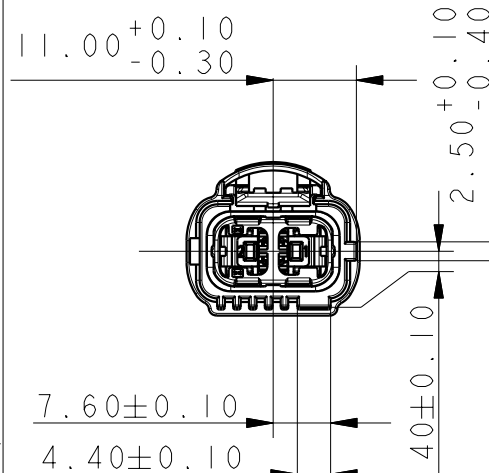
 
 
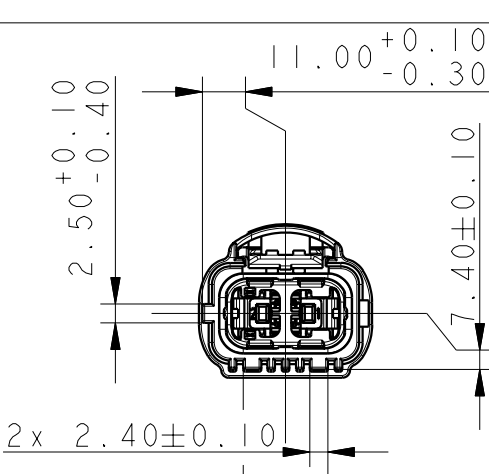
 
 
 
 
 
		16	15	14	13	12	11	10
	N°	NOTE		DESIGNATION				
	A	SPECIFICATION		FOLLOWING FCI PRODUCT SPECIFICATION				
	B	INTERFACE "CULOT PG20"		FOLLOWING IEC 34B/1225/FDIS project number: IEC 60061-1, A37, Ed.3DB (page 1/4)				
	C	INTERFACE "DOUILLES & CONNECTEURS"		FOLLOWING IEC 24B/1226/FDIS project number: IEC 60061-2, A34, ED.3DB (page 3/4)				
M	D	TERMINALS	GTS2-1.5 ref. F112300 gauge 0.5 to 0.85 ²					
			GTS2-1.5 ref. F343100 gauge 1 to 1.3 ²					
			GTS2-1.5 refs F443100 gauge 1.4 to 2 ²					
	E	SWS		211M0007 (YELLOW) WIRE 0.5 ² TO 0.75 ² / 211M0008 (GREEN) WIRE 1 ² TO 2 ²				
	F	USER'S MANUAL		FOLLOWING PUI20				
	G	CONNECTOR'S WEIGHT		5,70g				



SCALE 1 : 1



Rep	DESIGNATION	MATERIAL	COLOR
1	GRID TPA	PBT-GF15	YELLOW
2	2W FEMALE HOUSING	PBT-GF30	SEE TABLE
3	INTERFACIAL SEAL	LSR 50Sh 4% OIL IN THE MATERIAL AND VISIBLE ON ALL SURFACES	BLUE

PG20-1	PG20-2	PG20-3	PG20-4	PG20-5	PG20-6	IEC REFERENCE
F450200	-	F550200	F650200	-	-	FCI REFERENCE
BROWN	-	GREY	BLACK	-	-	HOUSING COLOR
B	-	B	B	-	-	REVISION INDEX
						VIEW
PG20-7	PG20-8	PG20-9	PG20-10	PG20-11	PG20-12	IEC REFERENCE
F750200	-	-	-	-	-	FCI REFERENCE
NATURAL	-	-	-	-	-	HOUSING COLOR
B	-	-	-	-	-	REVISION INDEX
						VIEW

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aptiv:](#)

[F550200](#) [F450200](#) [F550200-B](#)