
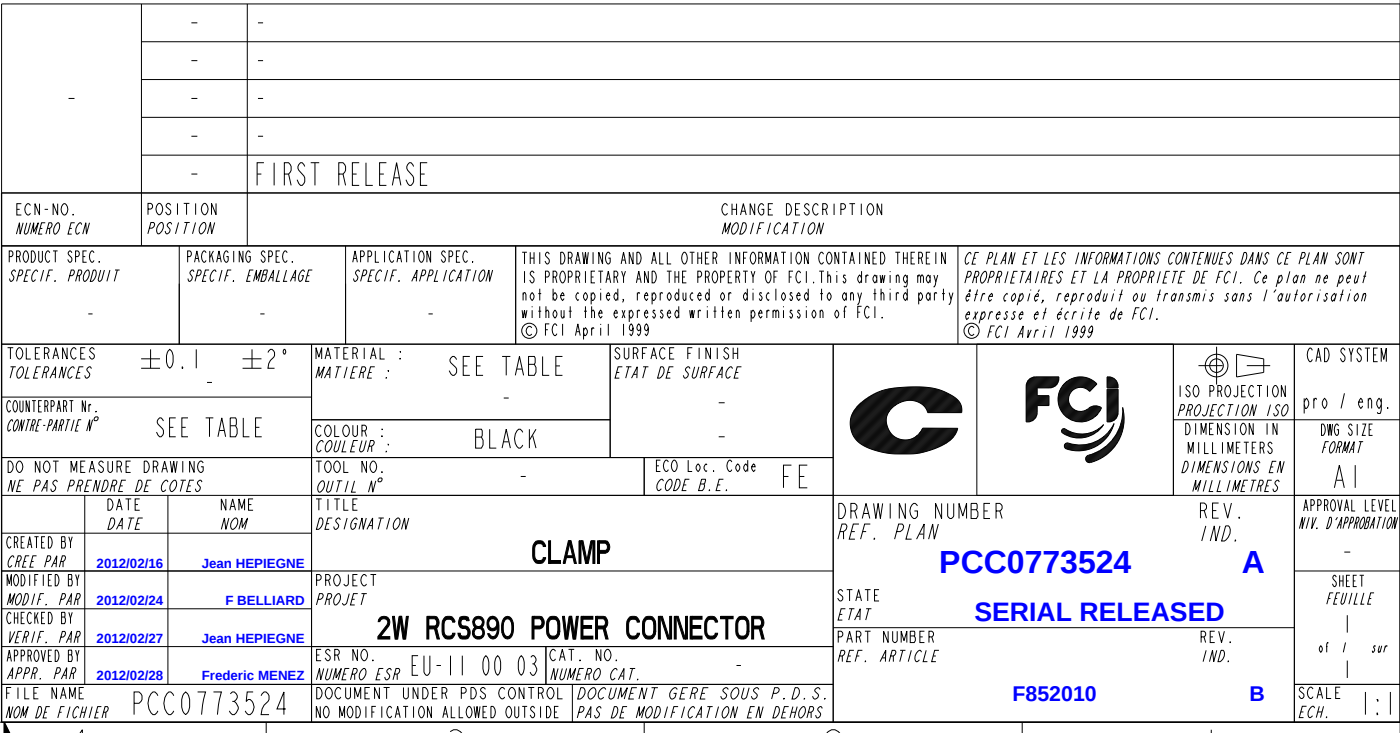


A

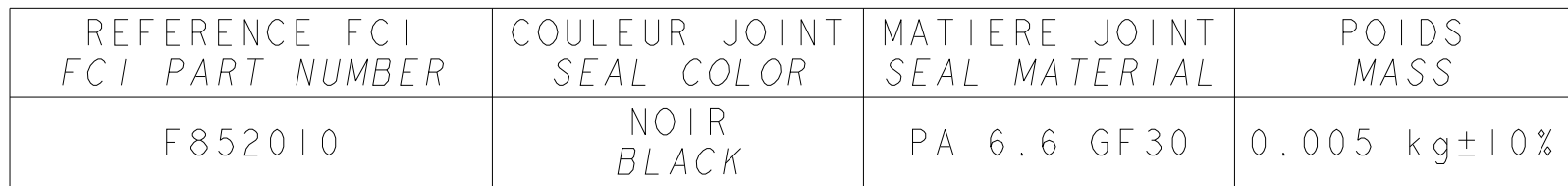

1 - FCI PRODUCT SPECIFICATIONS : FE PS 12 006  
 2 - TEMPERATURE CLASS OF THE CONNECTOR : -40°C ; +125°C  
 3 - VIBRATION CLASS : BODY PROFIL (3.9G RMS / FROM 5 TO 1000HZ)  
 4 - PACKAGING : FE PA 12-007  
 5 - HANDLING MANUAL : PUI58  
 6 - THIS DRAWING IS AN EXTRACT OF THE DETAILS DRAWINGS  
 7 - IN CASE OF CONFLICT REFERED TO IT  
 8 - EFFORT NECESSARY FOR CLIPPING : 20N MINI TO 50N MAXI  
 9 - CLAMP RETENTION FORCE (ON 1 HINGE ONLY) 20N MINI

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aptiv:](#)

[F032210](#) [F032210-B](#) [F852010-B](#) [F852010](#)