

Component-to-wire connectors


DuoTwin



40 way female housing for 0.64 mm terminals

Features

- Double row 2.54 mm pitch female modules
- Module holder accommodates two terminals modules
- Easy locking cam
- Mechanical polarization
- Several colour codings available

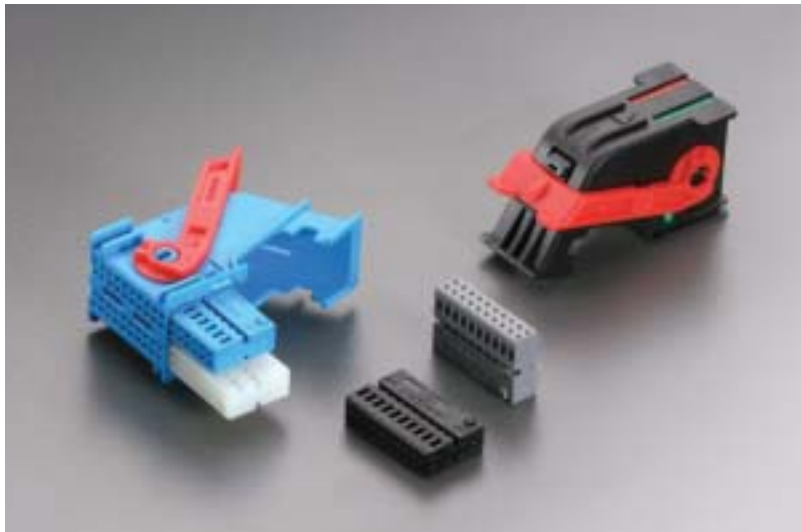

Performance characteristics

- Temperature range:
from -30°C to +105°C
- Contact retention force: > 30 N
- Contact insertion force: < 10 N
- Connector mating force: < 75 N

Construction

- Housing material: PA

Connector compatibility

- Usable terminals:
0.64 mm DuoTwin female terminals



Part Numbers	No. of position	Terminal size	Colour
100840BLK	40	0.64 mm	Blue/White
100840BKK	40	0.64 mm	Black/Grey
100840BKS	40	0.64 mm	Red/Green

Component-to-wire connectors **FCI**

DuoTwin

40 way female housing for 0.64 mm terminals

Dimensional characteristics

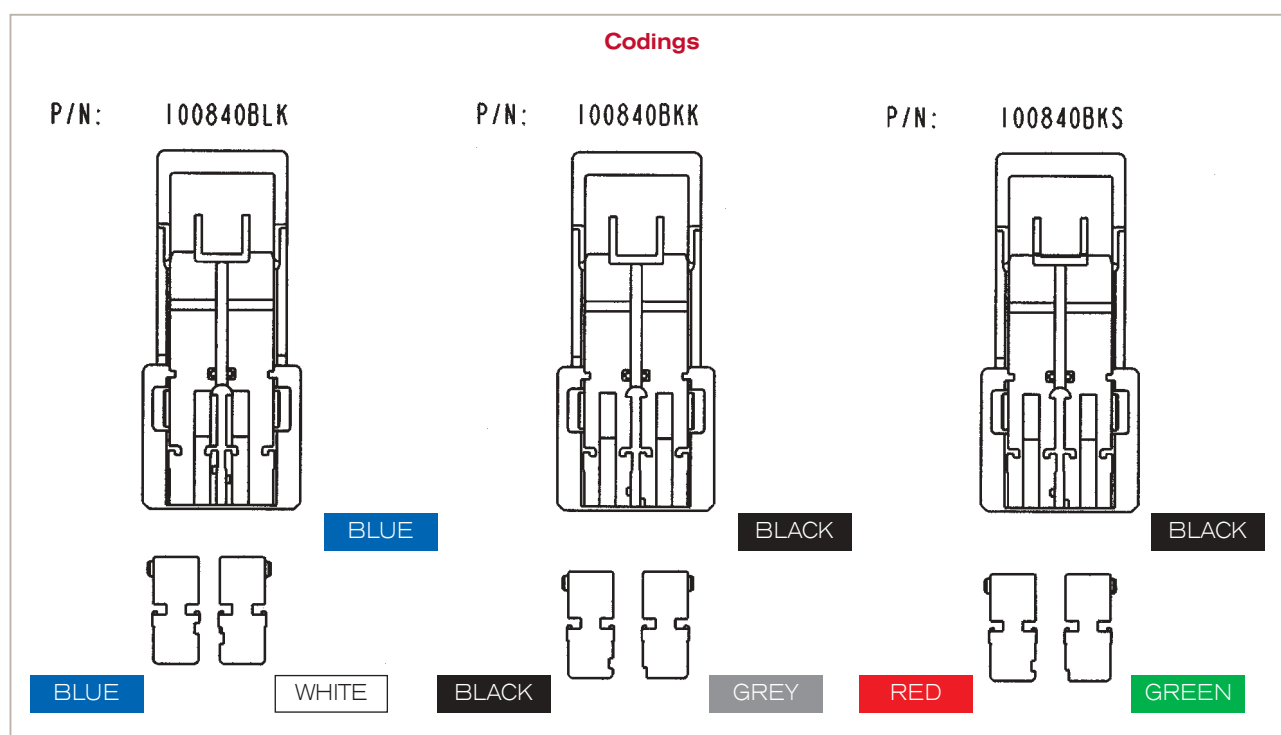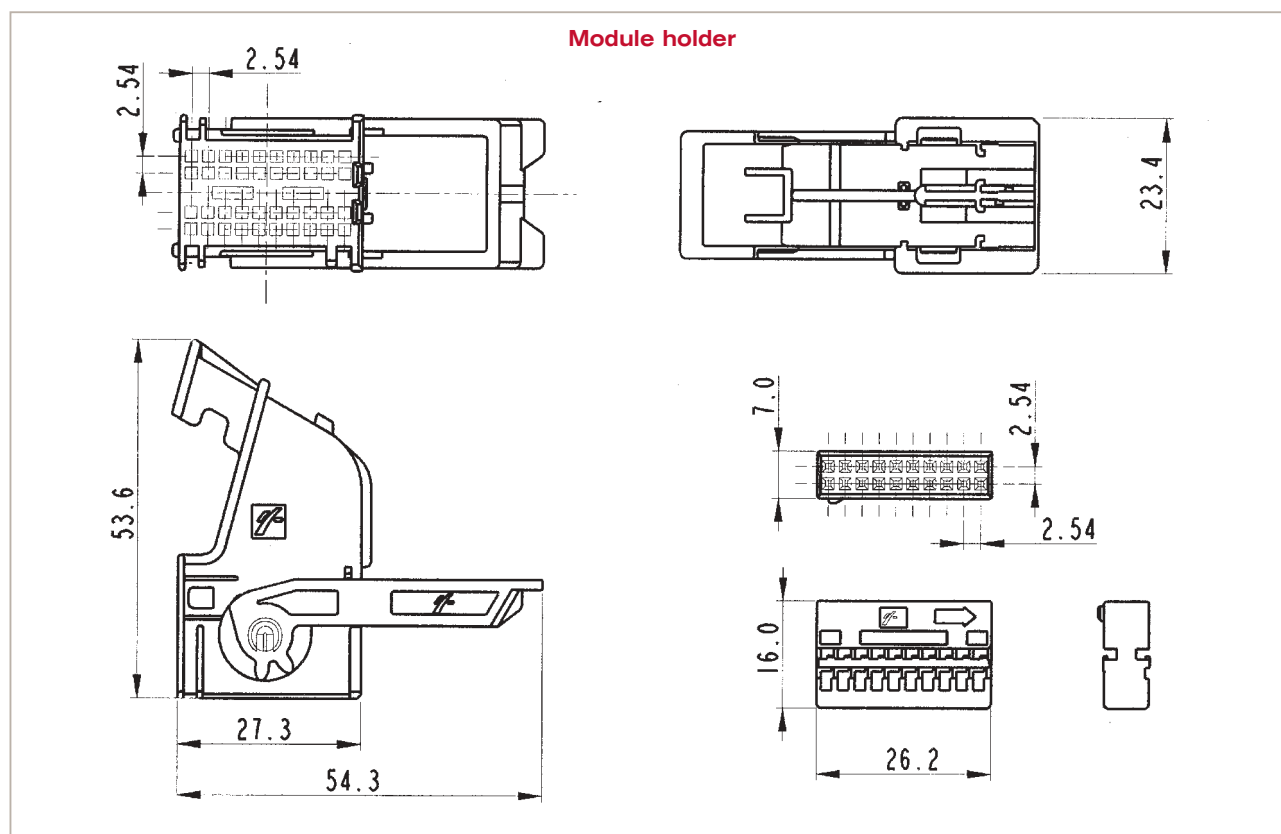

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aptiv:](#)

[100840BLK](#) [100840BKK](#) [100840BLK-B](#)