

product: DELPHI PN 13553177

material: CUNI3SI1MG

surface: AU

material thickness: 0,25 mm

cross section [mm²]: 0,22 + 0,35

strip length: 4,50 mm

cable type: FLRY-A

insulation ø [mm]:

seal:

**Uncontrolled
Copy**
For Information only!

conductor dimension					crimp dimension [mm]				
cable arr.	cable type	cross sect. [mm ²]	struct. n x d [mm]	tear-out force [N]	core height ± 0,05	core width ± 0,10	insulation height ± 0,10	insulation width ± 0,10	
top	FLRY-A	0,22 + 0,35	7 x 0,21 + 7 x 0,26	30	1,25	1,70	2,60	2,10	<u>core:</u> C-1.60-3.0-10 DPN 10713736 <u>insulation:</u> IS-2.00-3.0-12-A DPN 10882043 <u>anvil:</u> <u>two piece anvil:</u> AC-1.60-3.25 DPN 10764051 AI-2.00-3.2-0.4-A DPN 10882044


The tear-out force is validated for the small cable.

Notice to cable arrangement:


side: cables side by side

top: one cable on top of the other

n. d.: not defined

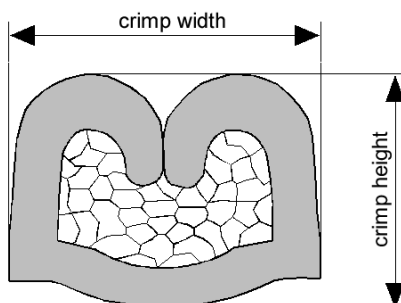

DELPHI PN 13553177

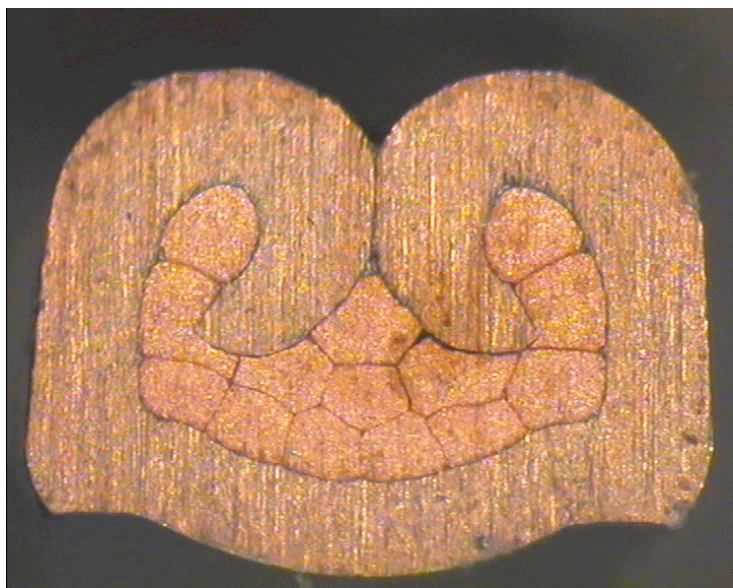

cable:

$$0,22 \text{ mm}^2 + 0,35 \text{ mm}^2 =$$
$$7 \times 0,21 \text{ mm} + 7 \times 0,26 \text{ mm}$$

crimp height:

1,25 mm

crimp width:

1,70 mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aptiv:](#)
[13553177](#)