
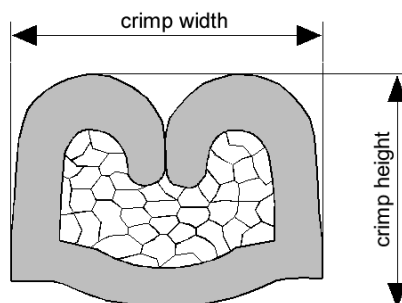


Strip length:	4,50 mm
cable type:	FLU7Y-A
insulation Ø [mm]:	2,00 - 2,10
seal:	DPN 15327863

two piece anvil:
AC-2.50-3.75
DPN 10769936
AI-4.00-3.2-1.0
DPN 10807103

[illegible]

DELPHI PN 13601170

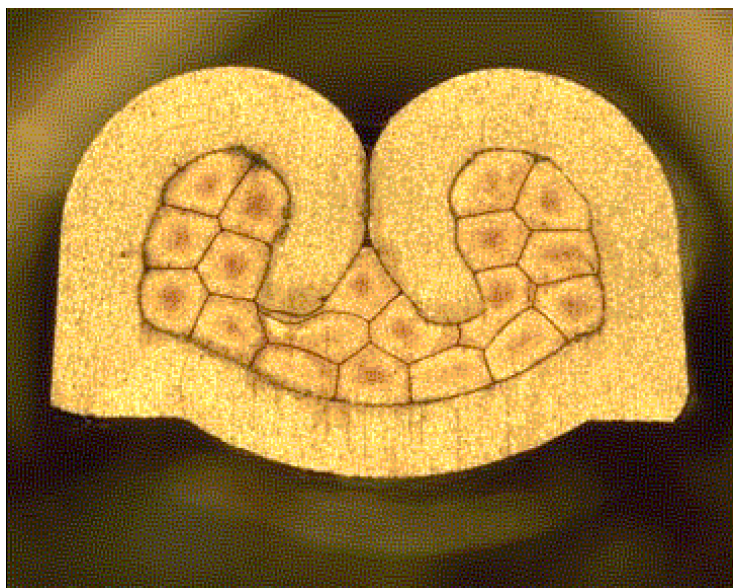

cable:

1,50 mm² = 19 x 0,32 mm

crimp height:

1,70 mm

crimp width:

2,60 mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aptiv:](#)
[13601170](#)