


Strip length:	5,80 mm
cable type:	FLU142Y
insulation Ø [mm]:	1,30 - 1,75
seal:	

core:
C-004
DPN 10714427


insulation:
IO-3.00-3.5-12-X
DPN 10713899

anvil:
AS-2.15-3.00-9.0-3.7-0
DPN 10714130

two piece anvil:
AC-2.15-4.75
DPN 10769983
AI-3.00-4.2-0
DPN 10769982

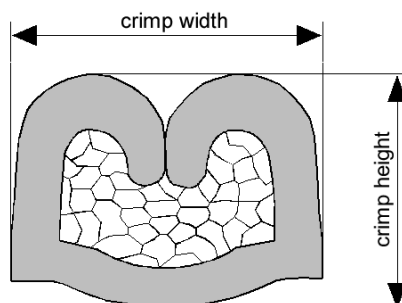[illegible]

DELPHI PN 15344998

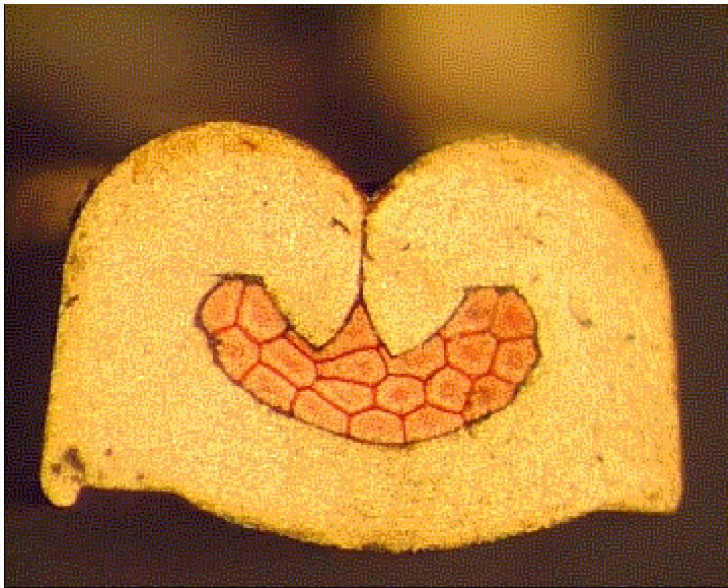

cable:


0,50 mm² = 19 x 0,19 mm

crimp height:

1,40 mm

crimp width:

2,30 mm

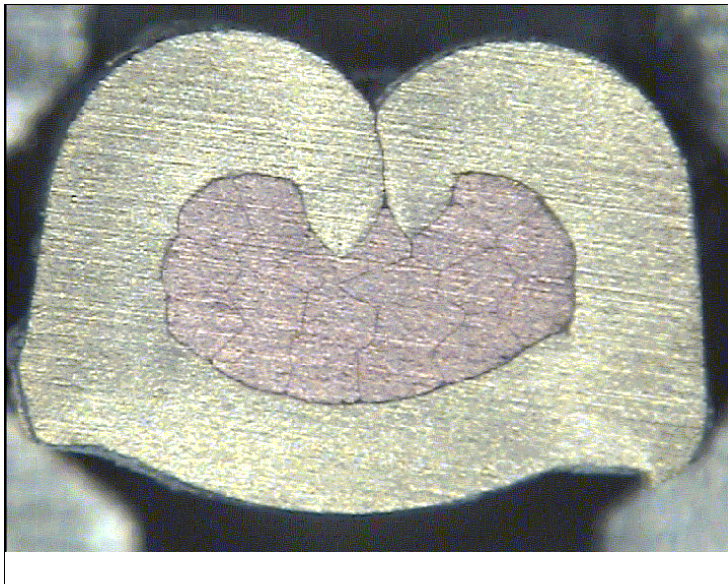

cable:

1,00 mm² = 19 x 0,27 mm

crimp height:

1,60 mm

crimp width:

2,30 mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aptiv:](#)
[15344998](#)